


2'-0" THRU 4'-0"

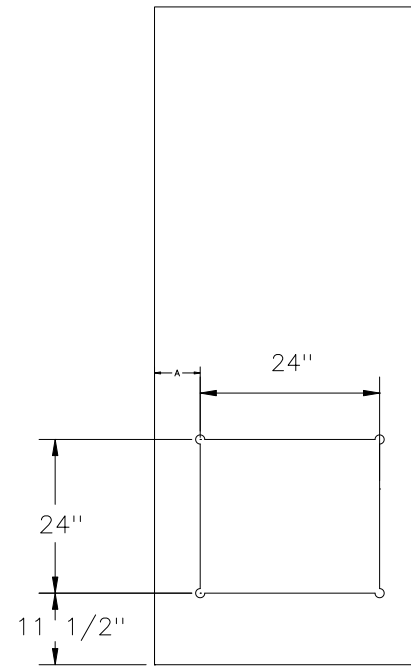

OPTIONAL AT
3'-0" THRU 4'-0"

DOOR WIDTH	2'-0"	2'-4"	2'-6"	2'-8"	2'-10"	3'-0"	3'-4"	3'-6"	3'-8"	3'-10"	4'-0"
A	5 7/8"	7 7/8"	5 7/8"	6 7/8"	7 7/8"	5 7/8"	7 7/8"	8 7/8"	9 7/8"	10 7/8"	11 7/8"
B	12	12	18	18	18	24	24	24	24	24	24

NOTE: DIMENSIONS SHOW CUTOUT SIZE IN DOOR
(ORDER SIZE IS DOOR CUTOUT SIZE)