



ASSA ABLOY

ASSA ABLOY Entrance Systems
1900 Airport Road
Monroe, NC 28110
Phone: 1-866-237-2687
specdesk.no.besam@assaabloy.com

BESAM VERSAMAX™ ICU SWING DOORS
SMOKE CERTIFIED
UNEQUAL PANEL

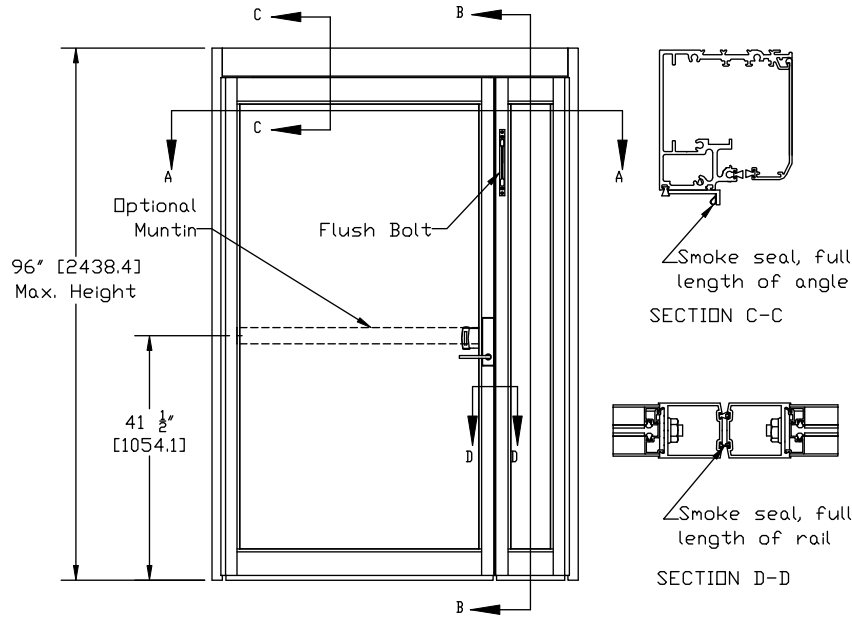


RH Unequal Panel Shown
(LH Opposite)

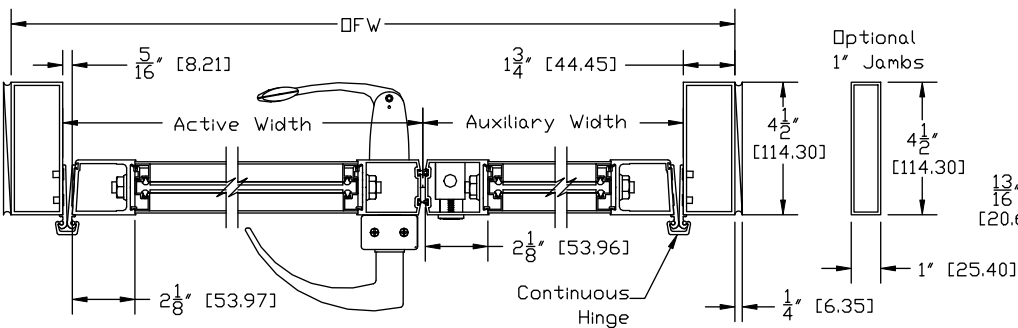

Breakout
Side

SECTION A-A

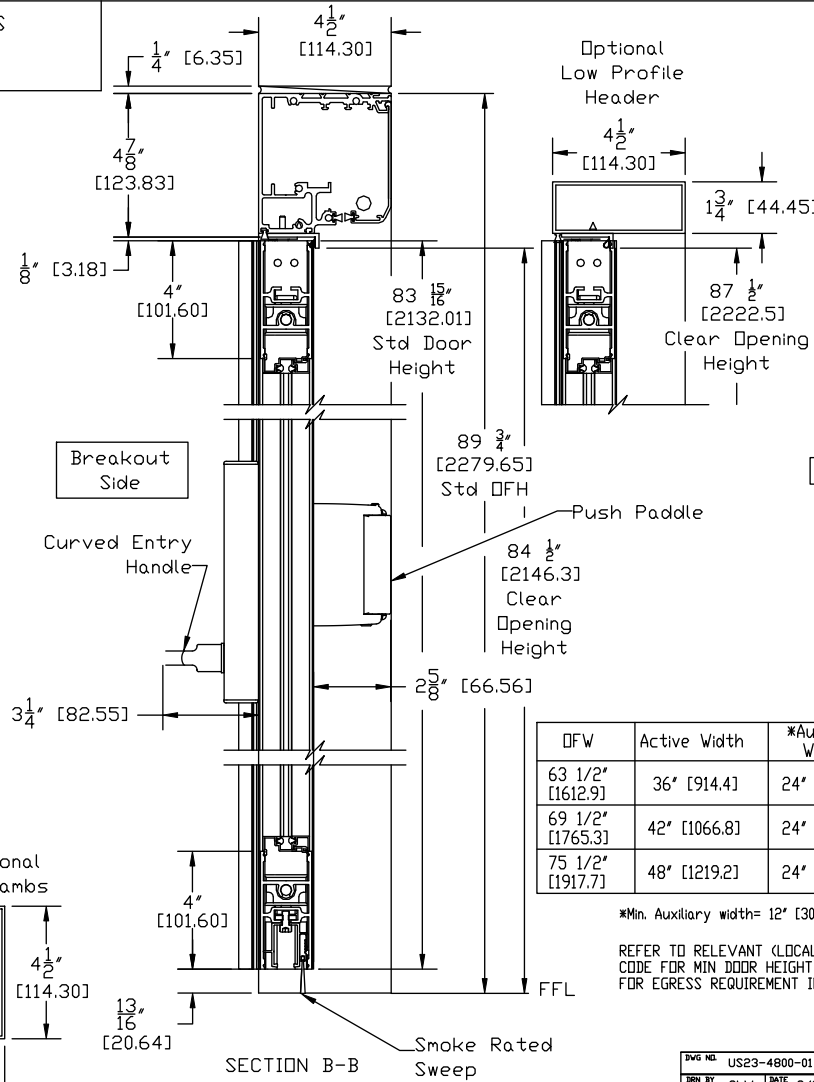


NOTE: THE STANDARD PACKAGE IS CERTIFIED TO UL 1784 AND CONSISTS OF:

- ICU HEADER
- FRAMES
- 1" GLAZING SYSTEM
- AN ACTIVE DOOR PANEL WITH A CURVED HANDLE TO THE EXTERIOR AND PUSH PADDLE TO THE INTERIOR
- AN AUXILIARY DOOR WITH A FLUSH BOLT TO THE EXTERIOR
- CONTINUOUS HINGES
- SMOKE RATED SEALS AND SWEEPS

STANDARD FINISH: CLEAR- AA-M12C22A44,
CLASS 1, .018 MM
SPECIAL FINISHES ARE AVAILABLE.

OPTIONS INCLUDE:

- MUNTINS
- LOW PROFILE HEADER
- OVERHEAD DOOR STOPS
- 1" JAMBS
- MEDIUM STYLE VERTICAL RAILS
- 7" AND 10" BOTTOM RAILS
- 5/8", 1", AND 1 1/4" GLAZING SYSTEMS
- MANUAL DOOR CLOSERS

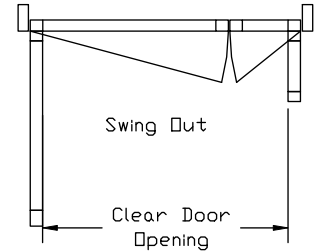

DFW	Active Width	*Auxiliary Width	Clear Door Opening	Masonry Opening Width
63 1/2" [1612.9]	36" [914.4]	24" [609.6]	55" [1397.0]	64" [1625.6]
69 1/2" [1765.3]	42" [1066.8]	24" [609.6]	61" [1549.4]	70" [1778.0]
75 1/2" [1917.7]	48" [1219.2]	24" [609.6]	67" [1701.8]	76" [1930.4]

*Min. Auxiliary width= 12" [304.8], Max. Auxiliary Width= 48" [1219.2]

REFER TO RELEVANT (LOCAL, STATE, NATIONAL OR AHJ) BUILDING CODE FOR MIN DOOR HEIGHT & MIN/MAX WIDTH ALLOWABLE FOR EGRESS REQUIREMENT IN CONJUNCTION WITH TABLE ABOVE.

*UL TESTED AND CERTIFIED TO MEET THE SMOKE REQUIREMENTS OF STANDARDS UL1784, ANSI/NFPA105 2007, UBC7-2, PART 11

DWG NO. US23-4800-01
DRN BY CLW DATE 8/23/10 CHK BY SS DATE 8/23/10 REV. B DATE 5/29/14

ASSA ABLOY