


# FLOORS, EXTERIOR Patios and Walkways

Cement Mortar, Bonded

HYD-F101-05

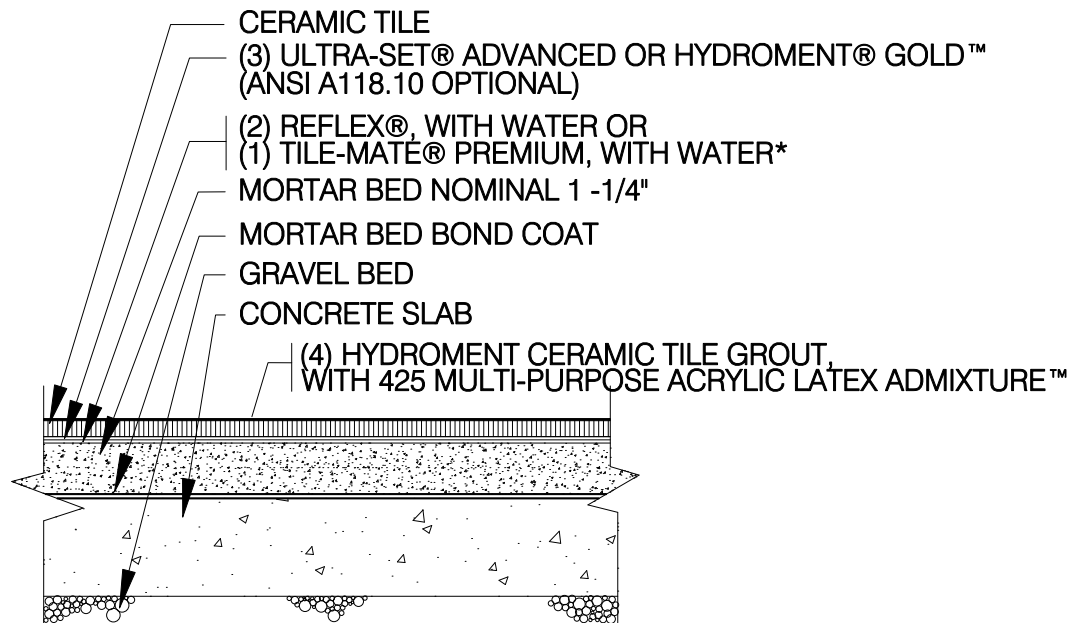

#### (4) Hydroment® Grout Options:

Hydroment Ceramic Tile Grout (sanded), with 425 Multi-Purpose Acrylic Latex Admixture™  
Hydroment Ceramic Tile Grout (sanded), with water  
Hydroment Ceramic Tile Grout (sanded), with 1900™ Modified Epoxy Admixture  
Hydroment Dry Tile Grout (unsanded), with 425 Multi-Purpose Acrylic Latex Admixture  
Hydroment Dry Tile Grout (unsanded), with water

#### (3) Hydroment Waterproof Membrane Options:

Ultra-Set® Advanced  
Hydroment Gold™  
Black-Top 90210™

#### (2) Hydroment Latex Portland Cement Mortar Options:

ReFlex®, with water  
Single-Flex FS™, with 425 Multi-Purpose Acrylic Latex Admixture  
Single-Flex FS, with water  
Single-Flex™, with water  
Big Tile & Stone™ Mortar, with water  
Hydroment PM™, with water  
Tile-Mate® Premium, with 447 Flex-A-Lastic® Admixture  
Tile-Mate Premium, with 425 Multi-Purpose Acrylic Latex Admixture  
Tile-Mate Floor & Wall, with 447 Flex-A-Lastic Admixture  
Tile-Mate Floor & Wall, with 425 Multi-Purpose Acrylic Latex Admixture

#### (1) Hydroment Dry-Set Mortar Options\*:

Tile-Mate Premium, with water  
Tile-Mate Floor & Wall, with water  
(\*Dry Set Mortar is not suitable for bonding to ANSI A118.10 Membrane.  
Use Latex Portland Cement Mortar.)