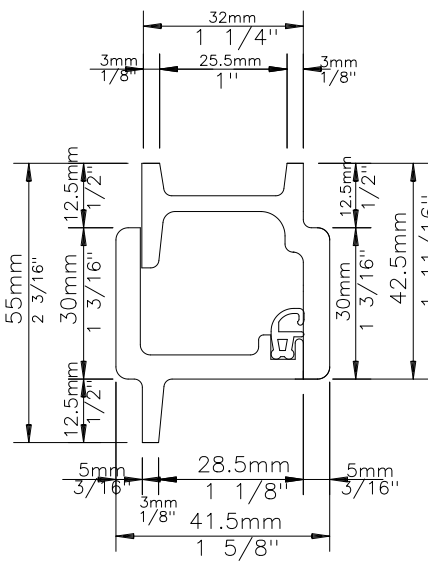
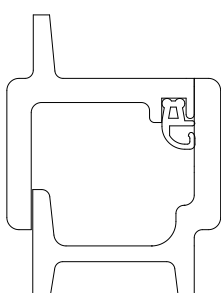
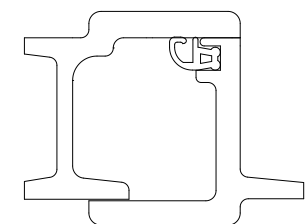
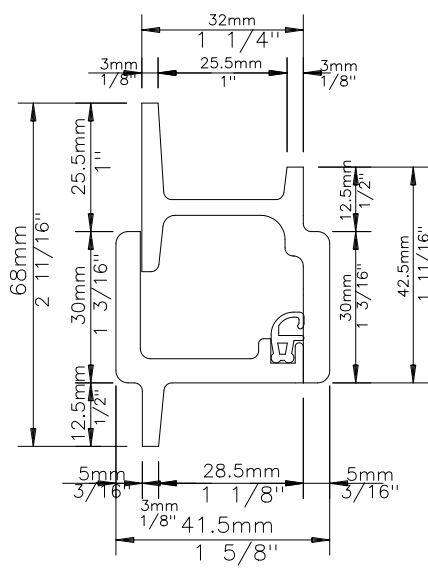
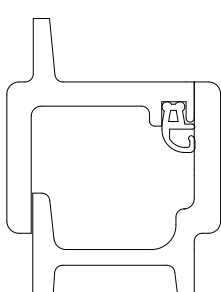
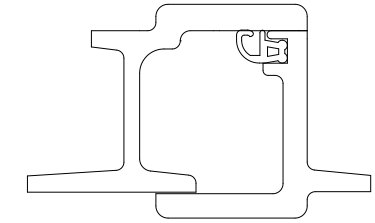


	HEAD	SILL	JAMB	
EQUAL LEG	 <p>Technical drawing of the Equal Leg window head profile. Dimensions are provided in millimeters (mm) and inches (").</p> <ul style="list-style-type: none"> Top width: 32mm (1 1/4") Top edge thickness: 3mm (1/8") Top edge width: 25.5mm (1") Top edge thickness: 3mm (1/8") Vertical distance from top edge to top of main frame: 55mm (2 3/16") Vertical distance from top edge to top of main frame: 12.5mm (1/2") Vertical distance from top edge to top of main frame: 30mm (1 3/16") Vertical distance from top edge to top of main frame: 12.5mm (1/2") Vertical distance from top edge to top of main frame: 42.5mm (1 11/16") Bottom width: 28.5mm (1 1/8") Bottom edge thickness: 5mm (3/16") Bottom edge width: 41.5mm (1 5/8") Bottom edge thickness: 5mm (3/16") Vertical distance from bottom edge to bottom of main frame: 12.5mm (1/2") Vertical distance from bottom edge to bottom of main frame: 30mm (1 3/16") Vertical distance from bottom edge to bottom of main frame: 12.5mm (1/2") 			<h2 data-bbox="1583 170 2096 341">Corporate W20 Window Range</h2> <p data-bbox="1583 392 2096 614">The Corporate range of windows is purpose made from W20 steel sections. The range offers versatility in application, from size and shape, to joining to form extensive composite windows. The large opening casements and the slim frame members ensure maximum daylight.</p> <p data-bbox="1583 631 2096 819">An effective weatherstripping system and the option of double glazing up to 14mm in thickness, add good thermal insulation properties. A popular choice with conservationists, planners and clients such as English Heritage.</p>
UNEQUAL LEG	 <p>Technical drawing of the Unequal Leg window head profile. Dimensions are provided in millimeters (mm) and inches (").</p> <ul style="list-style-type: none"> Top width: 32mm (1 1/4") Top edge thickness: 3mm (1/8") Top edge width: 25.5mm (1") Top edge thickness: 3mm (1/8") Vertical distance from top edge to top of main frame: 68mm (2 11/16") Vertical distance from top edge to top of main frame: 12.5mm (1/2") Vertical distance from top edge to top of main frame: 25.5mm (1") Vertical distance from top edge to top of main frame: 30mm (1 3/16") Vertical distance from top edge to top of main frame: 12.5mm (1/2") Vertical distance from top edge to top of main frame: 42.5mm (1 11/16") Bottom width: 28.5mm (1 1/8") Bottom edge thickness: 5mm (3/16") Bottom edge width: 41.5mm (1 5/8") Bottom edge thickness: 5mm (3/16") Vertical distance from bottom edge to bottom of main frame: 12.5mm (1/2") Vertical distance from bottom edge to bottom of main frame: 30mm (1 3/16") Vertical distance from bottom edge to bottom of main frame: 12.5mm (1/2") 			
	OPEN OUT		GLAZED IN SHOWN	Ref: W20200