


I-SYS IK-125/126 F50 Hammer Swage fitted on both ends

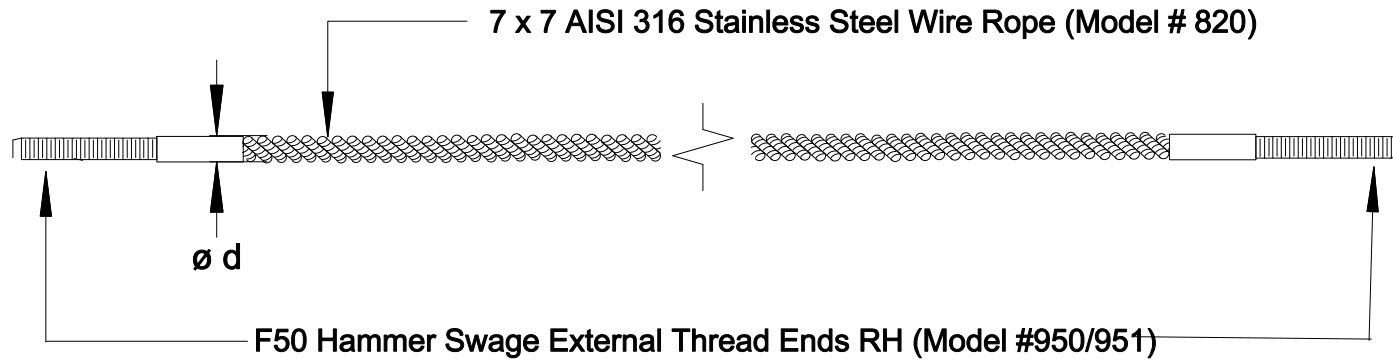

I-SYS
IK 125/126
Stainless
Steel wire
rope
assembly

Part Number	ø Rope	Thread size/length	ø d
IK 125-0400	4 mm	M4 x 30 mm	4,4 mm
IK 125-0401	4 mm	M4 x 60 mm	4,4 mm
IK 125-0500	5 mm	M5 x 30 mm	5,5 mm
IK 125-0501	5 mm	M5 x 60 mm	5,5 mm
IK 125-0600	6 mm	M6 x 30 mm	6,6 mm
IK 125-0601	6 mm	M6 x 60 mm	6,6 mm
IK 125-0800	8 mm	M8 x 30 mm	8,8 mm
IK 125-0801	8 mm	M8 x 60 mm	8,8 mm

I-SYS IK-125/126 F50 Hammer Swage fitted on both ends.
Each assembly consists of;

(variable)-7 x 7 AISI 316 Stainless Steel Wire Rope (Model # 820)
(2 qty.) -F50 Hammer Swage External Thread Ends RH (Model #950/951)
Available in a RH/LH combination (IK126)

Metric Fittings.
Measurements given
in Millimeters.

