


I-SYS IK-130 F30 Hammer Swage & External Thread Turnbuckle Fitted each end

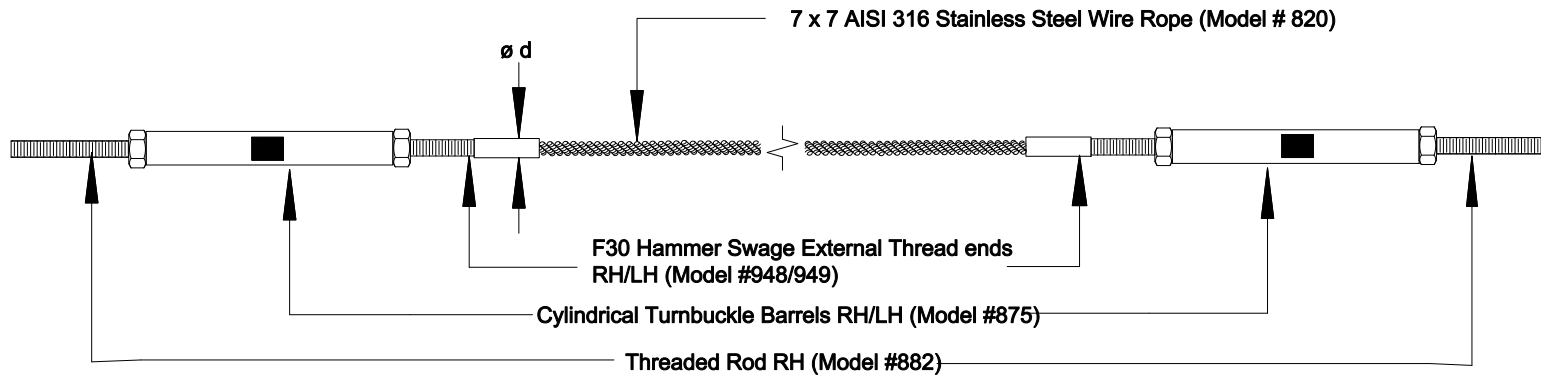

I-SYS
IK 130 Stainless
Steel wire
rope
assembly

Part Number	\varnothing Rope	Thread size/length	Adjustment in mm	$\varnothing d$
IK 130-0400	4 mm	M5 x 60mm	+60/-90	4,9 mm
IK 130-0500	5 mm	M6 x 60mm	+74/-110	5,9 mm
IK 130-0600	6 mm	M8 x 60mm	+74/-110	7,9 mm

I-SYS IK-130 F30 Hammer Swage & External Thread Turnbuckle Fitted each end

Each assembly consists of;

- (variable)-7 x 7 AISI 316 Stainless Steel Wire Rope (Model # 820)
- (2 qty.) -F30 Hammer Swage External Thread Ends RH/LH (Model # 948/949)
- (2 qty.) -Cylindrical Turnbuckle RH/LH (Model # 875)
- (4 qty.) -Hexagon Nuts RH/LH (Model # 892/893)
- (2 qty.) -Threaded Rod RH (882)

Metric Fittings.
Measurements given
in Millimeters.

