
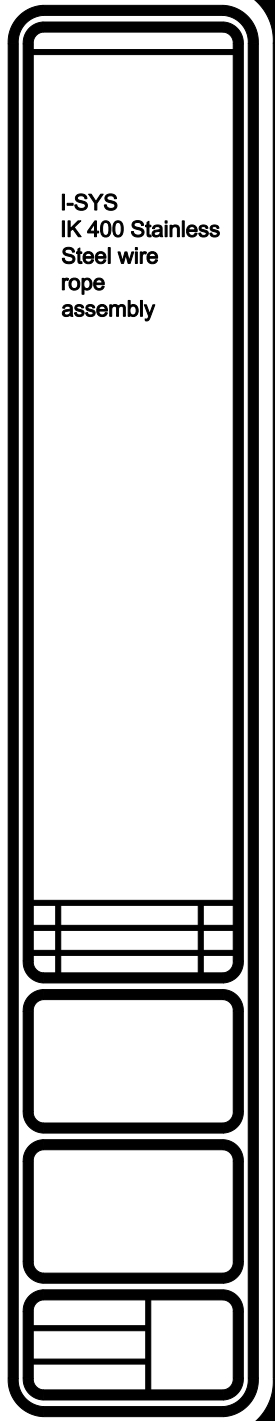


I-SYS IK-400 Internally Threaded Swage with Eye fitted at each end RH/LH

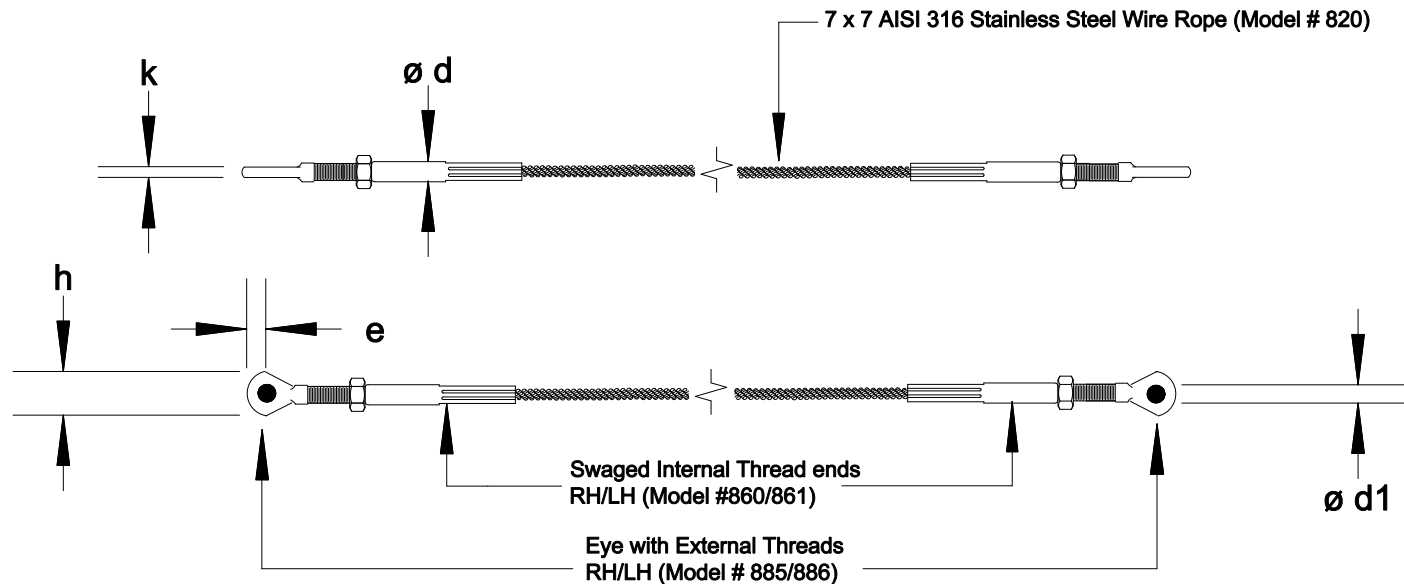

Part Number	\varnothing Rope	Thread size/length	Adjustment in mm	$\varnothing d$	$\varnothing d1$	e	h	k
IK 400-0300	3 mm	M5	+10/-20	7 mm	5,5 mm	6 mm	12 mm	3 mm
IK 400-0301	3 mm	M5	+24/-34	7 mm	5,5 mm	6 mm	12 mm	3 mm
IK 400-0400	4 mm	M6	+8/-20	8 mm	6,5 mm	7 mm	14 mm	4 mm
IK 400-0401	4 mm	M6	+22/-34	8 mm	6,5 mm	7 mm	14 mm	4 mm
IK 400-0500	5 mm	M6	+8/-20	8 mm	6,5 mm	7 mm	14 mm	4 mm
IK 400-0501	5 mm	M6	+22/-34	8 mm	6,5 mm	7 mm	14 mm	4 mm
IK 400-0600	6 mm	M8	+8/-24	10 mm	8,5 mm	9,5 mm	17 mm	5 mm
IK 400-0601	6 mm	M8	+34/-50	10 mm	8,5 mm	9,5 mm	17 mm	5 mm
IK 400-0800	8 mm	M10	+34/-54	13 mm	10,5 mm	12 mm	22 mm	6 mm
IK 400-1000	10 mm	M14	+52/-80	20 mm	13 mm	14 mm	27 mm	9 mm
IK 400-1200	12 mm	M16	+52/-84	25 mm	14,5 mm	15 mm	30 mm	10 mm
IK 400-1600	16 mm	M20	+60/-100	32 mm	19,3 mm	19,5 mm	38 mm	15 mm

I-SYS IK-400 Internally Threaded Swage with Eye fitted at each end RH/LH

- Each assembly consists of;
- (variable)-7 x 7 AISI 316 Stainless Steel Wire Rope (Model # 820)
 - (2 qty.) -Swaged internal Thread Ends RH/LH (Model # 860/861)
 - (2 qty.) -Eye with External Threads RH/LH (Model # 885/886)
 - (2 qty.) -Hexagon Nuts RH/LH (Model # 892/893)

Metric Fittings.
Measurements given
in Millimeters.