


Omega - double swing gate

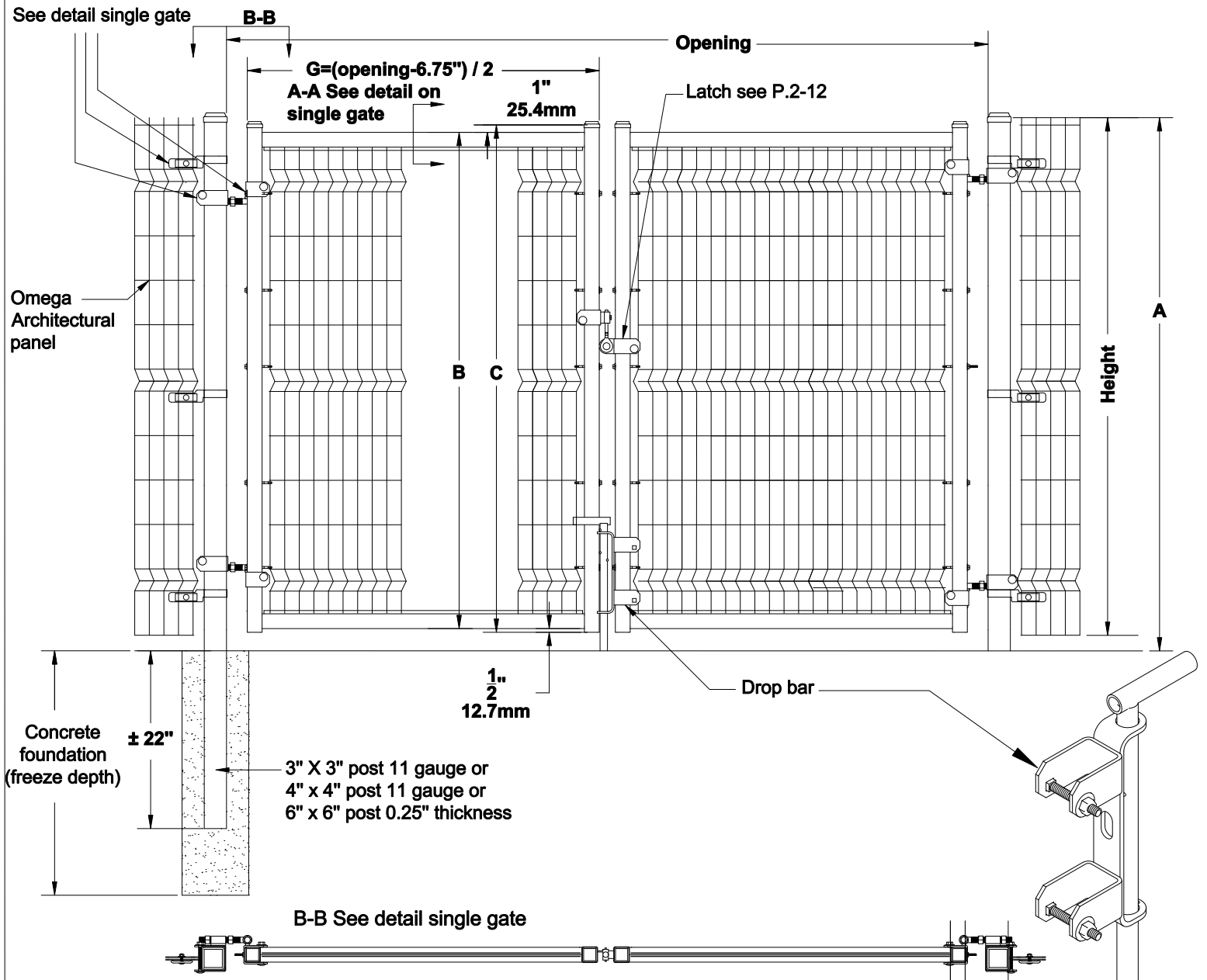

Double swing gate: Custom openings available

Horizontal dimensions		Gate posts	
Opening	G	Omega	Elite or Secur
6'-0"	32 5/8"	3" x 3"	3" x 3"
7'-0"	38 5/8"	3" x 3"	3" x 3"
8'-0"	44 5/8"	3" x 3"	3" x 3"
10'-0"	56 5/8"	3" x 3"	3" x 3"
12'-0"	68 5/8"	3" x 3"	3" x 3"
14'-0"	80 5/8"	3" x 3"	3" x 3"
16'-0"	92 5/8"	3" x 3"	4" x 4"
18'-0"	104 5/8"	4" x 4"	4" x 4"
Custom	Custom	Custom	Custom

Vertical dimensions			
Height	A	B	C
4'-1"	4'-3 1/2"	45-1/2"	47"
5'-1"	5'-3 1/2"	57-1/2"	59"
5'-10"	6'-1/2"	66-1/2"	68"
8'-1"	8'-3 1/2"	93-1/2"	95"
Custom	H + 2 1/2"	C - 1 1/2"	A - 4 1/2"

All double gates have identical frames
 Model 20 complete with Omega panels
 Model 30 complete with Elite panels
 Model 40 complete with Secur panels