




PERFORATION PATTERN - 75 mm (3") COLLAPSED GEOWEB® GW40V SECTIONS

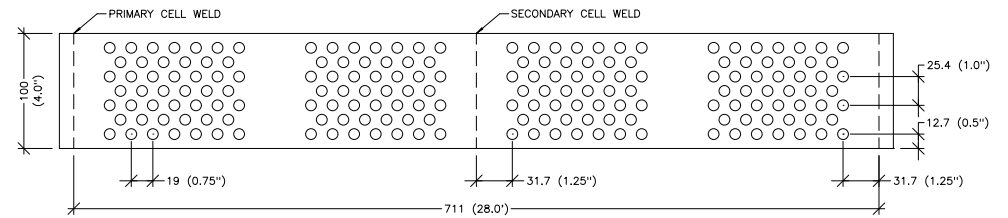

PERFORATION PATTERN - 100 mm (4") COLLAPSED GEOWEB® GW40V SECTIONS

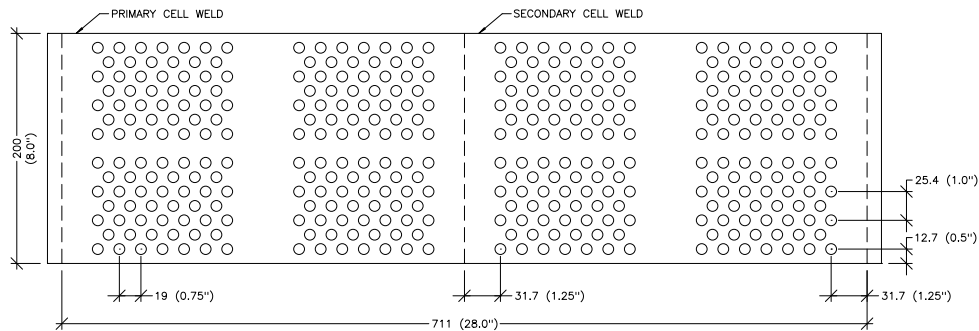

PERFORATION PATTERN - 200 mm (8") COLLAPSED GEOWEB® GW40V SECTIONS

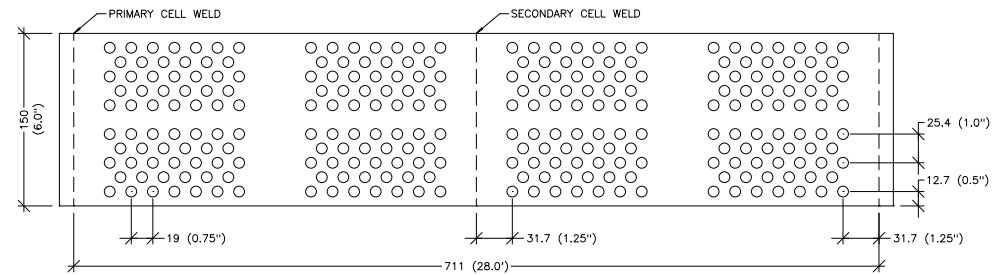

PERFORATION PATTERN - 150 mm (6") COLLAPSED GEOWEB® GW40V SECTIONS

ALL DIMENSIONS IN mm (inches in brackets)

NOTES:

ALL PERFORATIONS ARE 10 mm (0.4 in) DIAMETER
 GEOWEB CELL PERCENT OPEN AREA = 20.75% + 0.5%
 ALL DIMENSIONS ARE SUBJECT TO MANUFACTURING TOLERANCES

GEOWEB CELL DEPTH	NUMBER OF PERFORATIONS IN A SINGLE GW40V CELL	WEIGHT OF A ONE CELL LONG SECTION	
200 mm (8 in)	736	13.9 N	3,119 lb
150 mm (6 in)	528	10.5 N	2,364 lb
100 mm (4 in)	368	6.9 N	1,560 lb
75 mm (3 in)	264	5.3 N	1,182 lb

PRESTO® PRODUCTS COMPANY

THE GEOWEB®
 CELLULAR CONFINEMENT SYSTEM
 PERFORATIONS

PRESTO®, GEOWEB®, AND ATR® ARE REGISTERED TRADEMARKS OF PRESTO PRODUCTS COMPANY.

DATE	FEB, 2003 (REVISED)	FILE NAME	GWGEN6CE.DWG
SCALE	NTS	SHEET	6C