


TEMPORARY STAKING METHOD FOR INSTALLATION OF GW30V GEOWEB® SECTIONS

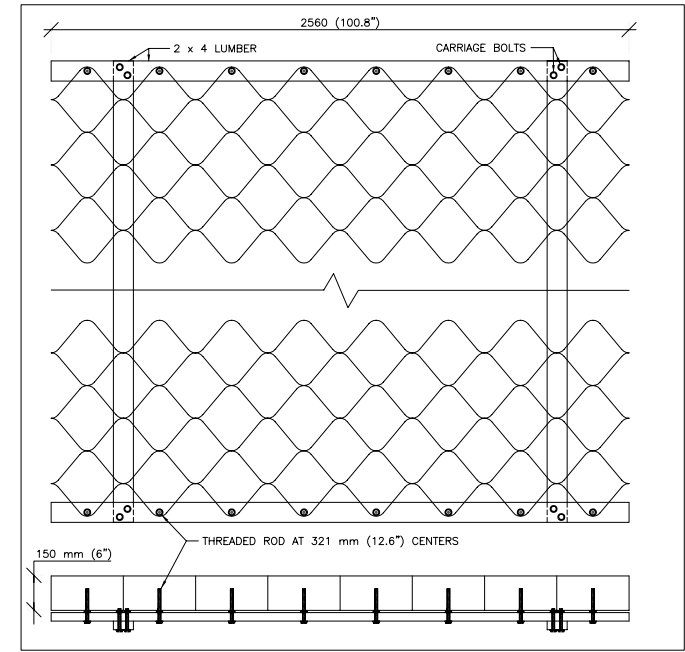

TYPICAL WOOD STRETCHER FRAME FOR GW30V GEOWEB® SECTIONS

PARTS LIST - WOOD STRETCHER FRAME

- 16 13 mm (1/2") X 203 mm (8") THREADED ROD
- 8 375 mm (3/8") X 102 mm (4") CARRIAGE BOLTS
- 48 375 mm (3/8") FLAT WASHERS
- 48 375 mm (3/8") HEX NUTS
- 3 2" X 4" X 8" LUMBER

PARTS LIST - TEMPORARY STAKING METHOD

- 16 13 mm (1/2") X 610 mm (24") STEEL STAKES/GEOWEB SECTION
- 1 END TEMPLATE CONSTRUCTED FROM 25 mm x 100 mm (1" x 2") TIMBER
- 1 EDGE TEMPLATE CONSTRUCTED FROM 25 mm x 100 mm (1" x 2") TIMBER



PRESTO GEOSYSTEMS®

THE GEOWEB®
CELLULAR CONFINEMENT SYSTEM
INSTALLATION TOOLS

GEOSYSTEMS®, GEOWEB®, AND ATRA® ARE REGISTERED TRADEMARKS OF PRESTO PRODUCTS COMPANY.

DATE	APRIL, 2008	FILE NAME	GWGEN5F.DWG
SCALE	NTS	SHEET	5