



**VISIBLY BETTER**


ECOGLO INC.  
241 MAIN STREET, SUITE 100  
BUFFALO, NY 14203  
TOLL FREE: 1-888-679-4022  
www.ecoglo.us

SELECT DESIRED LENGTH:

- 8' (STANDARD)
- 10' (STANDARD)

SELECT DESIRED ALUMINUM FINISH (STAIR NOSING):

- CLEAR ANODIZED (STANDARD)
- BLACK ANODIZED
- LIGHT BRONZE ANODIZED
- DARK BRONZE ANODIZED

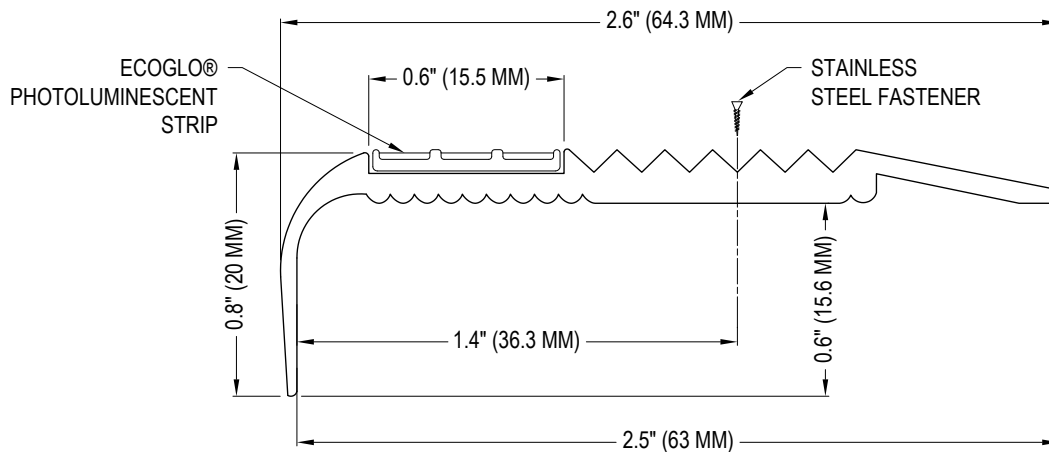

ECOGLO-PROFILE  
F5101 STAIR NOSING


**SPECIFICATIONS:**

**WEIGHT:** 0.44 LBS/FT

- INSTALL WITH POLYURETHANE ADHESIVE AND MECHANICAL FASTENERS, OR ADHESIVE ONLY.
- SUPPLIED WITH PRE-DRILLED COUNTERSUNK HOLES. INCLUDES STAINLESS STEEL FASTENERS AND CONCRETE NYLON ANCHORS. STANDARD LOCATION IS 2" FROM EACH END AND APPROX. 12" APART.
- INSERTS ATTACHED OR UNATTACHED - UNATTACHED IS RECOMMENDED FOR ON-SITE CUTTING. INSERTS ARE INSTALLED WITH A PREMIUM POLYURETHANE ADHESIVE.
- AVAILABLE IN CUT TO LENGTH SIZES (TOLERANCE  $\pm 1/8"$ )

**NOTES:**

1. INSTALLATION TO BE COMPLETED IN ACCORDANCE WITH MANUFACTURER'S SPECIFICATIONS.
2. DO NOT SCALE DRAWING.
3. THIS DRAWING IS INTENDED FOR USE BY ARCHITECTS, ENGINEERS, CONTRACTORS, CONSULTANTS AND DESIGN PROFESSIONALS FOR PLANNING PURPOSES ONLY. THIS DRAWING MAY NOT BE USED FOR CONSTRUCTION.
4. ALL INFORMATION CONTAINED HEREIN WAS CURRENT AT THE TIME OF DEVELOPMENT BUT MUST BE REVIEWED AND APPROVED BY THE PRODUCT MANUFACTURER TO BE CONSIDERED ACCURATE.
5. CONTRACTOR'S NOTE: FOR PRODUCT AND COMPANY INFORMATION VISIT [www.CADdetails.com/info](http://www.CADdetails.com/info) AND ENTER REFERENCE NUMBER 4776-053.

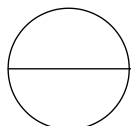

**FLAT STAIR NOSINGS - LUMINOUS AND NON-SLIP**

F5101 SERIES LUMINOUS FLAT STAIR NOSINGS