


Approval

Confirmation

Making

## ■ PRODUCT DRAWING

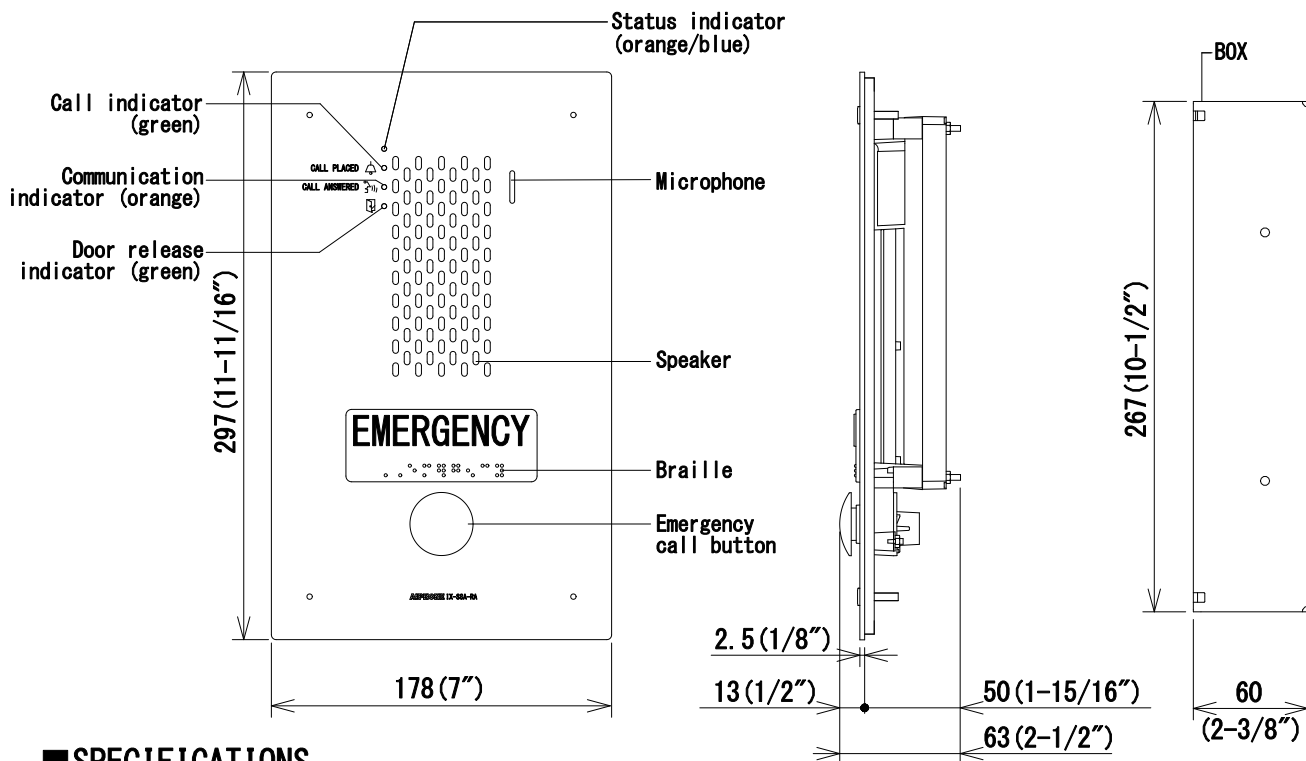

## ■ SPECIFICATIONS

Power source	Power-over-Ethernet (IEEE 802.3af/at Class 0) / 24V DC External power supply
Current consumption	Power-over-Ethernet Standby: 51mA Maximum: 120mA 24V DC External power supply Standby: 87mA Maximum: 240mA
Type of communication	Hands-free: automatic voice switching
LAN	Ethernet (10BASE-T, 100BASE-TX) Auto MDI/MDI-X-compatible
Audio codec	G.711 ( $\mu$ -law, A-law), G.722
Protocol	IPv4, IPv6, TCP, UDP, SIP, HTTP, HTTPS, RTSP, RTP, RTCP, IGMP, MLD, SMTP, SFTP, DHCP, NTP, DNS
Encryption method	TLS1.0, TLS1.1, TLS1.2
Packet delivery	Unicast
Number of called stations	20 stations
Ambient temperature	-40~+60°C (-40 ~+140° F)
Mounting	Flush wall-mount
Material	Front panel: stainless steel, vertical alignment finished / Main unit: self-extinguishing ABS resin / Box: SPCC 1.2
Unit color	Front panel: silver / Main unit: black / Box: black (Electrodeposition Coating)
Weight	Unit: approx. 1.5kg (3.3 lbs) / Box: approx. 860g (1.9 lbs)
IP rating	IP65
IK rating	IK08

DESCRIPTION  
**DOOR STATION**

FIG. NAME  
PRODUCT DRAWING/SPECIFICATIONS

UNIT  
mm

DATE

MODEL NO.

FIG. NO.

PAGE  
1/5

REVISION  
1

**AIPHONE**