



WILLIAMSPORT COLONIAL SIDING BEADED 6 1/2"

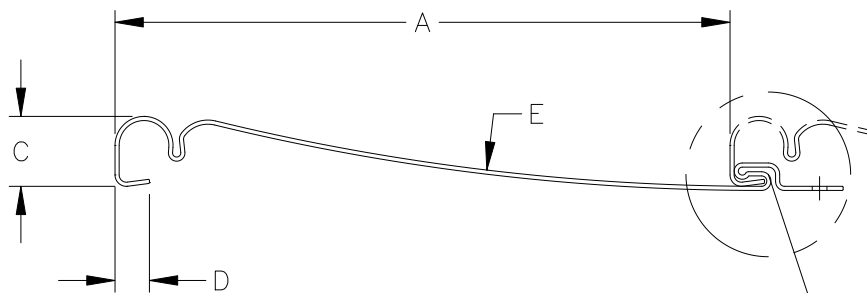

- A. INTERLOCKED PANEL WIDTH = 6.500 ± 0.030
- B. LOCK HEIGHT = 0.310 ± 0.020
- C. BUTT HEIGHT = 0.740 ± 0.010
- D. BUTT HOOK LENGTH = 0.370 ± 0.020
- E. PROFILE PANEL RADIUS = 14.00 ± 0.016
- F. NAIL STRIP EDGE TO LOCK = 0.680 ± 0.020
- G. NAIL SLOT CENTER LINE = 0.250 ± 0.030
- H. NAIL SLOT HOLES = 0.156×1.010
- J. END NOTCHING = 2.000 ± 0.125

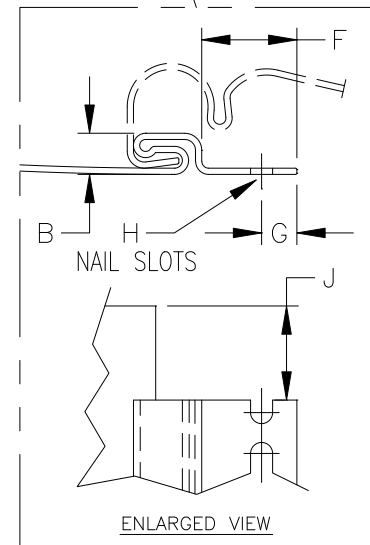

- WALL THICKNESS EXPOSED = $.044 \pm .001$
- WALL THICKNESS HANGER = $.042$ (MIN)
- WEIGHT PER FOOT - - - = $.260$ LBS.
- OVERALL LENGTH - - - = $12'-4" \pm 1/8"$
- WARP - - - - - = $.125"/$ PANEL
- WEEP HOLE - - - - - = $.125"$
- NAIL CENTER - - - - - = $16"$

