
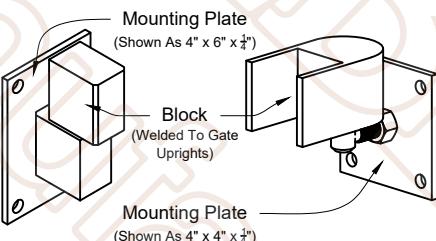


A 01 Bella Rae Double Estate Gate

Shown As Industrial Series

Scale: NTS

*Displayed As Standard

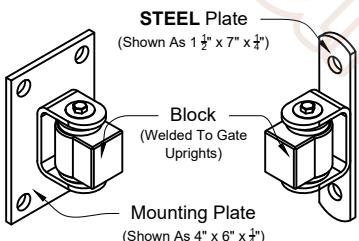

Bad Ass

Adjustable: 3.0625" to 3.25"

Bad Ass


Adjustable: Hybrid 3.0625" to 3.25"

Block

Fixed: 3.25"

J-Bolt

Adjustable: 3.25" to 6.50"

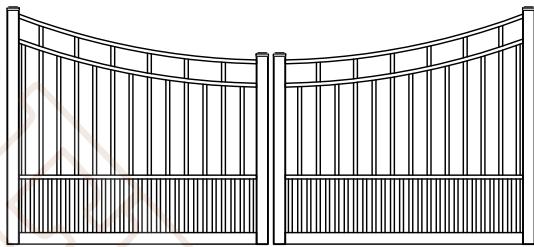

Scalloped



Bell



Sunrise

A 02 Estate Hinges Options

To Fit 4" & 6" Post

Scale: NTS

*Standard Deduction Is 3 1/4" For These Hinges

GATE OPENING	End Uprights	Bottom Member	Corner Gussets	Truss Cables
Double	Upgrades	Bottom Member	Corner Gussets	Truss Cables
*12'-1" to 23'-11"	2" x 3" x 1/8"	2" x 3" x 1/8"	NONE	NONE
24'-0" to 27'-11"	2" x 3" x 1/8"	2" x 4" x 1/8"	Yes	NONE
28'-0" to 32'-0"	2" x 3" x 1/8"	2" x 6" x 1/8"	Yes	Yes
32'-1" to 40'-0"	2" x 3" x 1/8"	Custom	NONE	NONE

*Any gate opening under 12'-1", will require a Estate Gate upcharge for listed specifications.

A 03 Material Specification Chart

Double Swing Estate Gate

A 04 Arch Options

All Considered Standard

Scale: NTS

*Arch Follows 1" Of Rise For Every Foot Of Opening

Bella Rae Double Estate Gate

4 Rail - Industrial Series - Puppy Picket
(Standard Gate With The Optional Puppy Picket)

4-Rail System Required For Gates Starting At 7'-0" High

Checked By: Antebellum

Order #:

Drawn By: J. Mixon

Drawn Date: 11-Dec-25

ANTEBELLUM
Manufacturing

DO NOT SCALE DRAWING. FOR DIMENSIONS NOT SHOWN
CONTACT PLAN COORDINATOR FOR CLARIFICATION

2399 NW 35th St, Ocala, FL 34475

Ph: 352.877.3888

Em: Info@AntebellumMFG.Com

DRAWING NOTES:

We kindly ask that you do not scale directly from the drawings. We recommend consulting our Fence and Gate Style Sheet for further options. Please be aware that while additional gate hardware is available, its use may impact the clearances for hinges and latches.

Customer Signature: