


A Ella Marie Single Estate Gate

01

Shown As Industrial Series

Scale: NTS

*Displayed As Standard

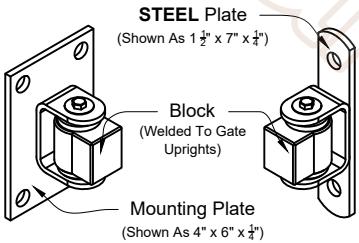

Bad Ass

Adjustable: 3.0625" to 3.25"

Bad Ass

Adjustable: Hybrid 3.0625" to 3.25"


Block

Fixed: 3.25"

Mounting Plate (Shown As 4" x 6" x 1/8")


Mounting Plate (Shown As 4" x 6" x 1/8")

Block (Welded To Gate Uprights)

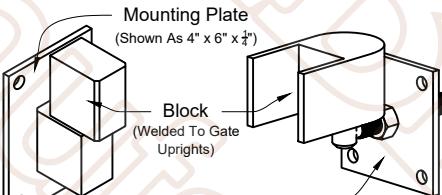


J-Bolt


Adjustable: 3.25" to 6.50"

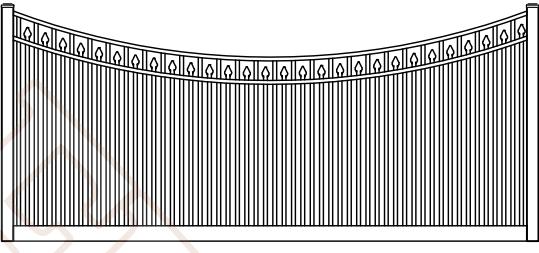

Scalloped

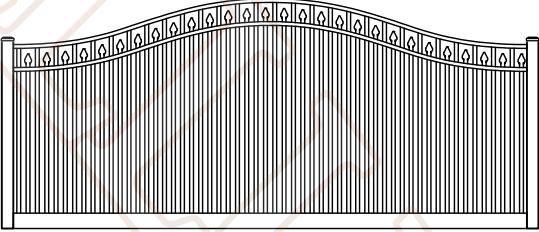

Bell

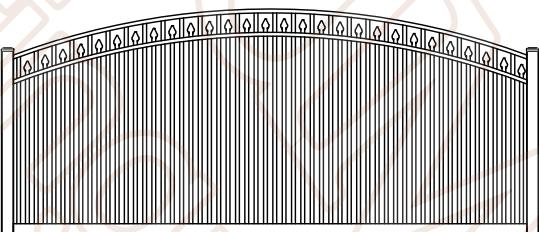

Sunrise

GATE OPENING

Single

End Uprights

Bottom Member

Corner Gussets

Truss Cables

*6'-0 1/2" to 11'-11 1/2"

2" x 3" x 1/8"

2" x 3" x 1/8"

NONE

NONE

12'-0" to 13'-11 1/2"

2" x 3" x 1/8"

2" x 4" x 1/8"

Yes

NONE

14'-0" to 16'-0"

2" x 3" x 1/8"

2" x 6" x 1/8"

Yes

Yes

16'-0 1/2" to 20'-0"

2" x 3" x 1/8"

Custom

NONE

NONE

*Any gate opening under 6'-0 1/2", will require a Estate Gate upcharge for listed specifications.

A Material Specification Chart

03

Single Swing Estate Gate

A Arch Options

All Considered Standard

Scale: NTS

*Arch Follows 1" Of Rise For Every Foot Of Opening

Ella Marie Single Estate Gate

3 Rail - Industrial Series - Double Picket

(Standard Gate With The Optional Double Picket to Top Rail)

3-Rail System Designed For Gates Up To 6'-0" High

Checked By: Antebellum

Order #:

Drawn By: J. Mixon

Drawn Date: 9-Dec-25

ANTEBELLUM
Manufacturing

DO NOT SCALE DRAWING FOR DIMENSIONS NOT SHOWN

CONTACT PLAN COORDINATOR FOR CLARIFICATION

2399 NW 35th St, Ocala, FL 34475

Ph: 352.877.3888

Em: Info@AntebellumMFG.Com

DRAWING NOTES:

We kindly ask that you do not scale directly from the drawings. We recommend consulting our Fence and Gate Style Sheet for further options. Please be aware that while additional gate hardware is available, its use may impact the clearances for hinges and latches.

Customer Signature: