


**01 Sydney Double Estate Gate**  
Shown As Residential Series      Scale: NTS  
\*Displayed As Standard

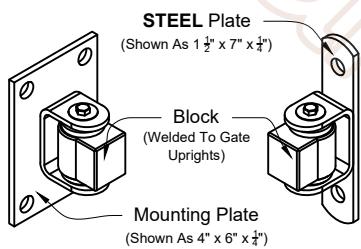

**Bad Ass**  
Adjustable:  
3.0625" to 3.25"

**Bad Ass**  
Adjustable: Hybrid  
3.0625" to 3.25"

**Block**  
Fixed: 3.25"

**J-Bolt**  
Adjustable:  
3.25" to 6.50"

**02 Estate Hinges Options**  
To Fit 4" & 6" Post      Scale: NTS  
\*Standard Deduction Is 3 1/4" For These Hinges

GATE OPENING	End Uprights	Bottom Member	Corner Gussets	Truss Cables
<b>Double</b>	<b>Uprights</b>	<b>Bottom Member</b>	<b>Corner Gussets</b>	<b>Truss Cables</b>
*12'-1" to 23'-11"	2" x 3" x 1/8"	2" x 3" x 1/8"	NONE	NONE
24'-0" to 27'-11"	2" x 3" x 1/8"	2" x 4" x 1/8"	Yes	NONE
28'-0" to 32'-0"	2" x 3" x 1/8"	2" x 6" x 1/8"	Yes	Yes
32'-1" to 40'-0"	2" x 3" x 1/8"	Custom	NONE	NONE

\*Any gate opening under 12'-1", will require a Estate Gate upcharge for listed specifications.

**03 Material Specification Chart**  
Double Swing Estate Gate

## Sydney Double Estate Gate

4 Rail - Residential Series - Puppy Picket  
(Standard Gate With The Optional Puppy Picket)

4-Rail System Required For Gates Starting At 7'-0" High

Checked By: Antebellum

Order #:

Drawn By: J. Mixon

Drawn Date: 21-Nov-25


**ANTEBELLUM**  
Manufacturing

DO NOT SCALE DRAWING. FOR DIMENSIONS NOT SHOWN  
CONTACT PLAN COORDINATOR FOR CLARIFICATION


2399 NW 35th St, Ocala, FL 34475

Ph: 352.877.3888

Em: Info@AntebellumMFG.Com

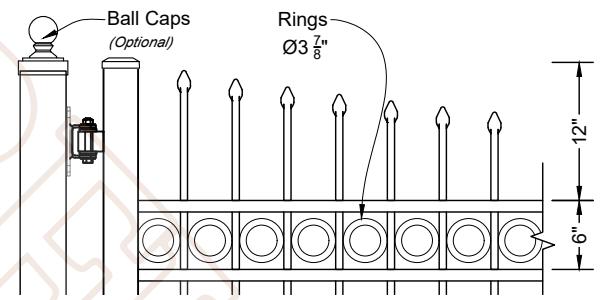

**04 Rings**  
Welded To Pickets      Scale: NTS

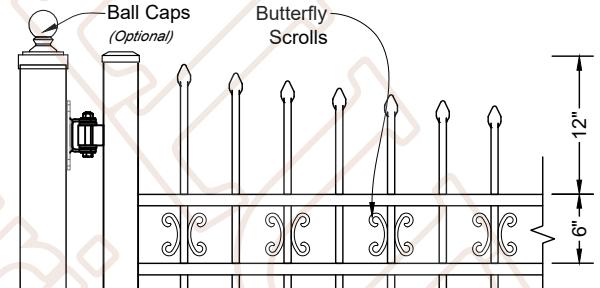

**05 Butterfly Scrolls**  
Shown Every Other Picket      Scale: NTS  
\*Optional Butterfly Scrolls On Every Picket



**06 Finials**  
Screwed To Pickets      Scale: NTS

### DRAWING NOTES:

We kindly ask that you do not scale directly from the drawings. We recommend consulting our Fence and Gate Style Sheet for further options. Please be aware that while additional gate hardware is available, its use may impact the clearances for hinges and latches.

Customer Signature: