


Grouting Floor Joints - Option 2

1. Area to be grouted
2. ¼" Injection needle
3. Saturated oakum
4. Closed cell backer rod (2.5 x joint width)

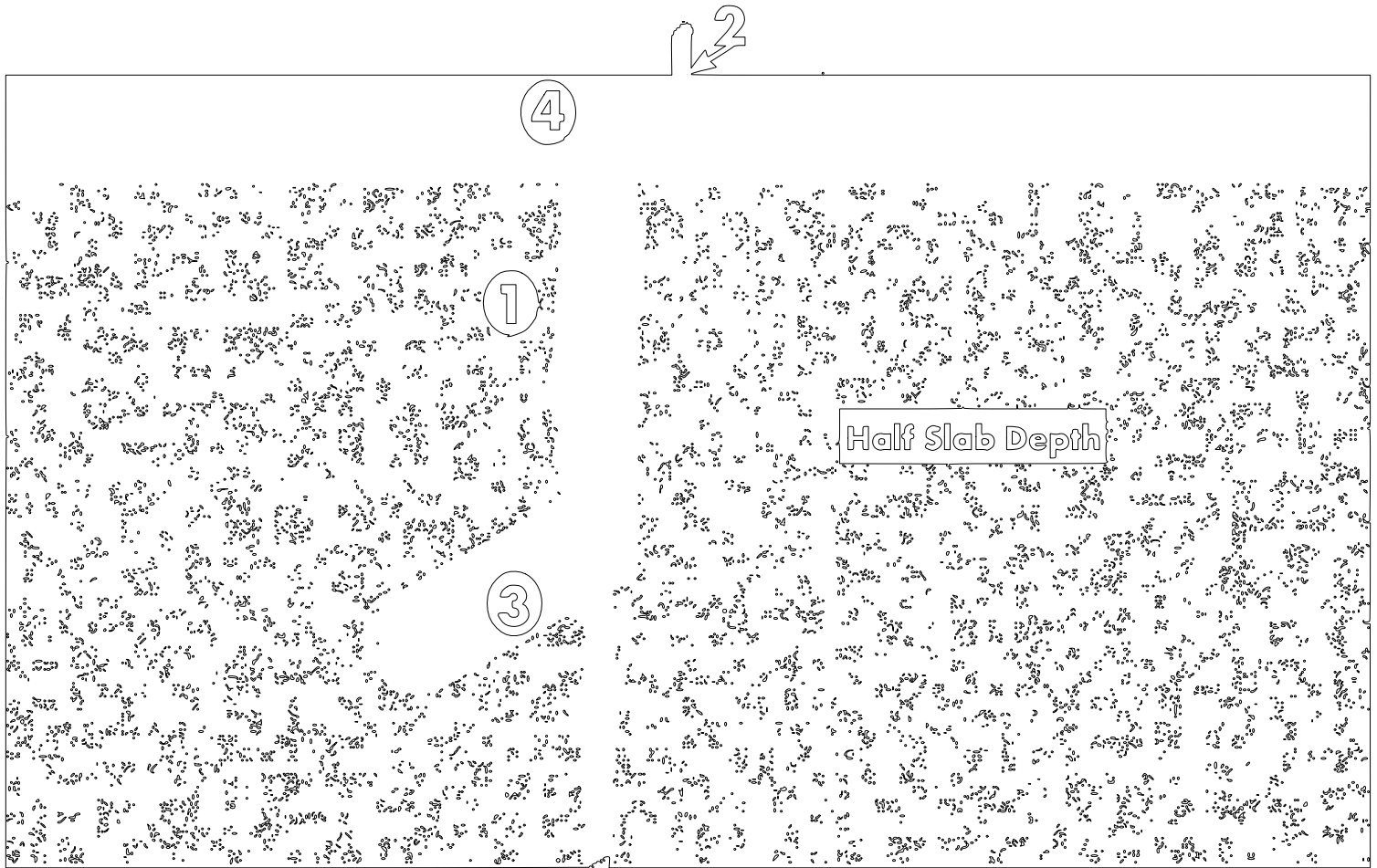

Suggested Procedure

1. Cut/rout joint to a fixed depth of ½ (half) the thickness of the concrete slab.
2. Ensure joint width is ¾" or larger.
3. Submerge Oakum Rope in InjectProECO-LV until fully saturated, then immediately submerge in water.
4. Immediately insert the saturated oakum rope into the cleaned joint at a depth of ½ (half) the thickness of the slab.
5. Allow the InjectProECO-LV to cure for 40 minutes.
6. Place open cell backer rod soaked in InjectProECO-LV in joint.
7. Insert ¼" injection needle through the upper backer rod seal.
8. Pump Aquafin InjectProECO-LV through the InjectPro-Hose system, under low pressure as required in the InjectPro Grouting Guidelines.