




ASM[®]
innovations in access flooring

PowerTraXX[™]
POWER TRAYS

SLP-10
Low-Profile Electrical Box
Starnet Modular Cable System

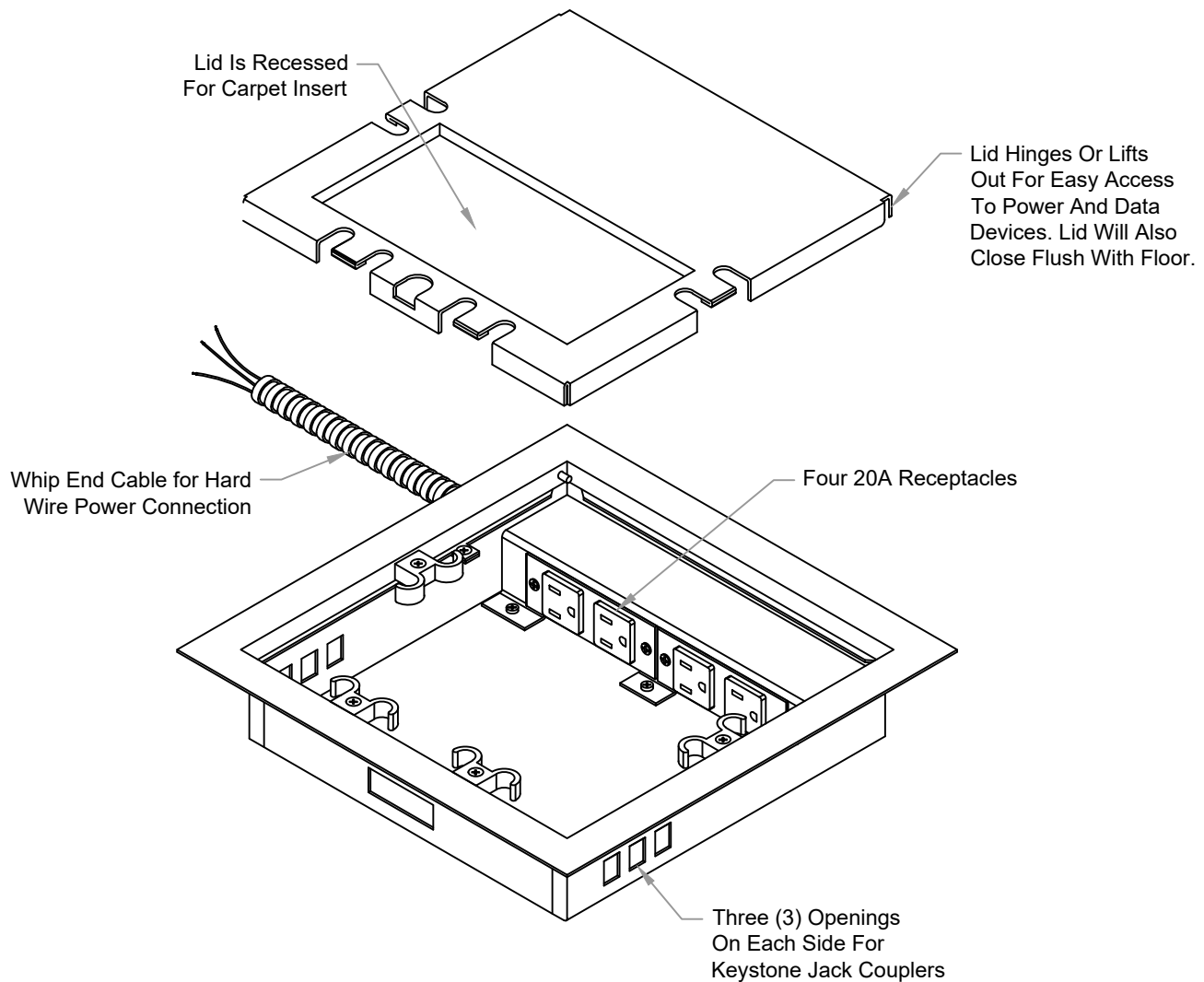

Physical Data

- Dimensions of flange - 11 1/2" sq.
- Dimension of box - 10" sq.
(Req's. min. 10 1/8" sq. cutout)
- Height of box - Fits into ASM 40 mm FFH Low-Profile Floor System
- Load rating of lid - 1,000 lbf (4448 N)

Electrical Data

- Rated at 20 amp/120V AC
- Plug-in modular simplex receptacles
- Four simplex receptacles provided
- Boxes can be "daisy-chained" together using plug-in modular power-to-power cables
- Provided with 12" long Whip End Cable for hard wire power connection

Features

- Available with up to four 20A simplex receptacles
- Lid hinges open or lifts off
- Lid is recessed to accept carpet/tile insert
- Powder coat epoxy paint finish (Available in black color only)
- Welded heavy gauge steel construction
- 3 openings on each side for Keystone jack couplers



NOTE: Cut sheet drawing and information are subject to change without prior notice.

10/20

ASM Modular Systems Inc.®

9500 Industrial Center Dr. Ladson, SC, 29456 Tel: 843-534-1110 Fax: 843-534-1111 (www.asmproducts.com)

SCS - 1010A