




ASM[®]
innovations in access flooring

PowerTra^{XX}
POWER TRAYS

Double Headed Extender Cable

Starnet Modular Cable System

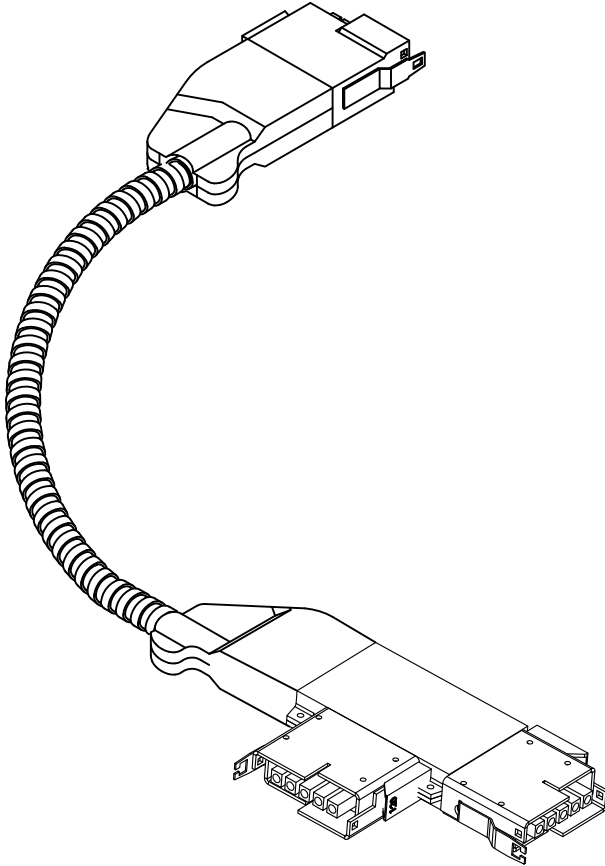

DEC-nn DOUBLE HEADED EXTENDER CABLE


Description

The DEC-nn Double Headed Extender Cable is designed with one "power in" port and two "power out" ports making it possible to split the branch circuits power into two different directions. Each Double Headed Extender Cable is manufactured from Type MC Cable and consists of 90° C insulated type THHN #12 AWG, solid copper conductors and a #12 AWG, solid copper ground.

Note: #10 AWG is available upon request. All Double Headed Extender Cables are rated for the use on 20 ampere branch circuits, and are dead fronted for safety. To eliminate inter-voltage connection, each cable is keyed and color coded to meet specific voltage requirements.

Catalog Number

1 EE A ** - SC

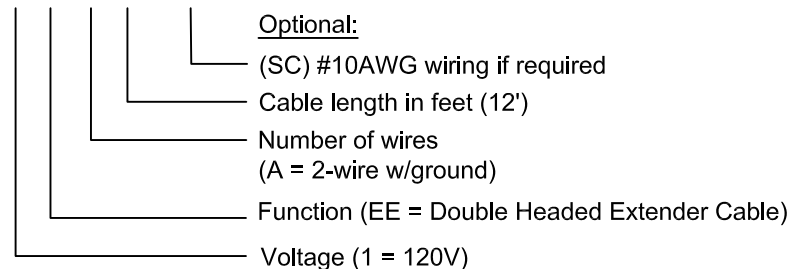

NOTE : IBEW-assembled. UL-Listed and Labeled



NOTE: Cut sheet drawing and information are subject to change without prior notice.

Rev. 1/22/18

ASM Modular Systems Inc.[®]

9500 Industrial Center Dr. Ladson, SC, 29456 Tel: 843-534-1110 Fax: 843-534-1111 (www.asmproducts.com)

SCS - 1062