




BISON Innovative Products


2395 West 4th Avenue Denver, CO 80223 USA
 Phone 303.892.0400 Toll Free 800.333.4234 Fax 303.825.5988
 EMail info@BisonIP.com Web www.BisonIP.com

Get CEU Credits, Details & Specifications online at BisonIP.com


VERSADJUST
Adjustable Deck Supports

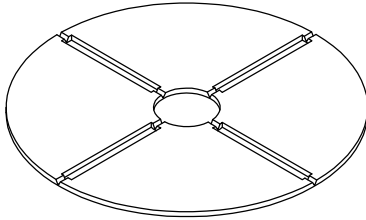


B11
 1/16" FLEXIBLE RUBBER SHIM
 5 7/8" DIAMETER
 USED FOR SOUND DAMPENING
 AND FINAL SHIM LEVELING

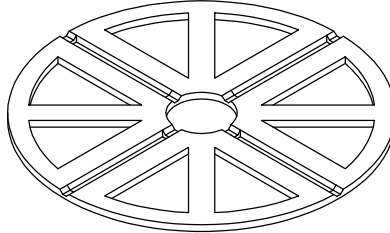


PS1
 1/8" RIGID SHIM
 5 7/8" DIAMETER
 USED FOR FINAL SHIM LEVELING.

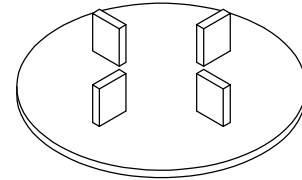


VT316 OR VT18
 1/8" FIXED HEIGHT TAB SET
 4 5/8" DIAMETER
 USED FOR LOW CAVITY HEIGHTS
 AND SPACING.

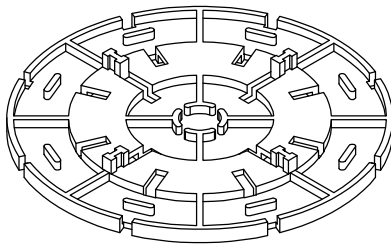

HD25
 1/4" FIXED HEIGHT STACKABLE
 PEDESTAL
 5 7/8" DIAMETER
 STANDARD 3/16" (4.5mm) TABS OR
 1/8" (3mm) TABS
 USED FOR LOW CAVITY HEIGHTS.
 STACK UP TO 4 FIXED HEIGHT
 PEDESTALS TOGETHER.

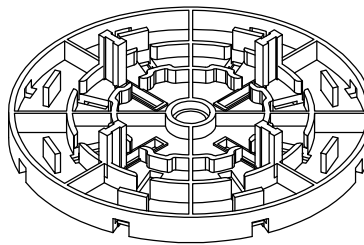


HD50
 1/2" FIXED HEIGHT STACKABLE
 PEDESTAL
 5 7/8" DIAMETER
 STANDARD 3/16" (4.5mm) TABS OR
 1/8" (3mm) TABS
 USED FOR LOW CAVITY HEIGHTS.
 STACK UP TO 4 FIXED HEIGHT
 PEDESTALS TOGETHER.

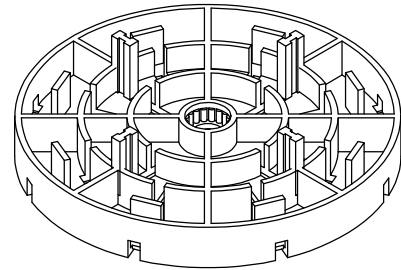

HD75
 3/4" FIXED HEIGHT STACKABLE
 PEDESTAL
 5 7/8" DIAMETER
 STANDARD 3/16" (4.5mm) TABS OR
 1/8" (3mm) TABS
 USED FOR LOW CAVITY HEIGHTS.
 STACK UP TO 4 FIXED HEIGHT
 PEDESTALS TOGETHER.

GENERAL NOTES: APPLY TO ALL OF THE ABOVE PRODUCTS

1. INSTALLATION MUST BE COMPLETED IN ACCORDANCE WITH BISON INNOVATIVE PRODUCTS SPECIFICATIONS.
2. DRAWINGS NOT TO SCALE.
3. CONTRACTOR'S NOTE: FOR PRODUCT AND COMPANY INFORMATION VISIT www.BisonIP.com

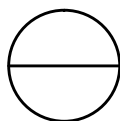

FIXED HEIGHT PEDESTALS AND SHIMS

STACKABLE PEDESTALS FROM 1/4" TO 3"