




Innovative Products


2395 West 4th Avenue Denver, CO 80223 USA  
 Phone 303.892.0400 Toll Free 800.333.4234 Fax 303.825.5988  
 EMail info@BisonIP.com Web www.BisonIP.com

Get CEU Credits, Details & Specifications online at BisonIP.com


**LEVEL.IT**  
 Adjustable Deck Supports

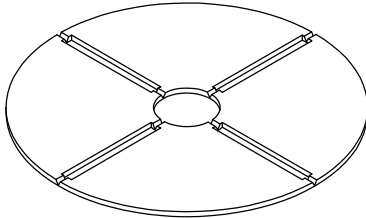


**B11**  
 1/16" FLEXIBLE SHIM  
 5 7/8" DIAMETER  
 USED FOR SOUND DAMPENING  
 AND FINAL SHIM LEVELING

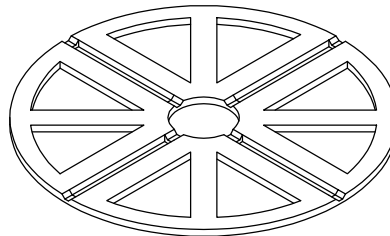


**PS1**  
 1/8" RIGID SHIM  
 5 7/8" DIAMETER  
 USED FOR FINAL SHIM LEVELING.

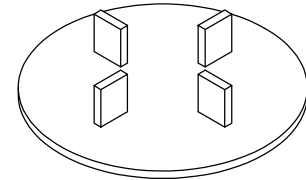


**VT316 / VT18**  
 1/8" FIXED HEIGHT TAB SET  
 4 5/8" DIAMETER  
 USED FOR LOW CAVITY HEIGHTS  
 AND SPACING.

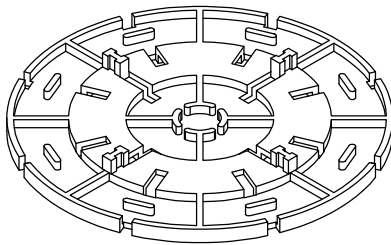

**HD25**  
 1/4" FIXED HEIGHT STACKABLE  
 PEDESTAL  
 5 7/8" DIAMETER  
 STANDARD 3/16" (4.5mm) TABS OR  
 1/8" (3mm) TABS  
 USED FOR LOW CAVITY HEIGHTS.  
 STACK UP TO 4 FIXED HEIGHT  
 PEDESTALS TOGETHER.

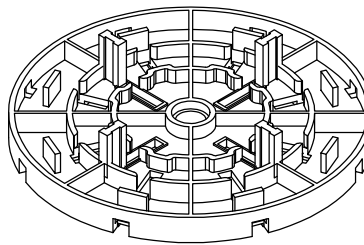


**HD50**  
 1/2" FIXED HEIGHT STACKABLE  
 PEDESTAL  
 5 7/8" DIAMETER  
 STANDARD 3/16" (4.5mm) TABS OR  
 1/8" (3mm) TABS  
 USED FOR LOW CAVITY HEIGHTS.  
 STACK UP TO 4 FIXED HEIGHT  
 PEDESTALS TOGETHER.

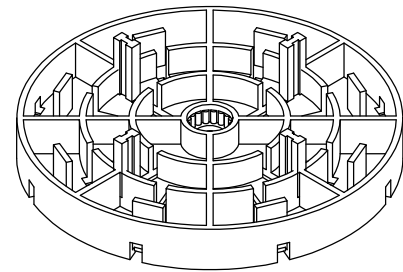

**HD75**  
 3/4" FIXED HEIGHT STACKABLE  
 PEDESTAL  
 5 7/8" DIAMETER  
 STANDARD 3/16" (4.5mm) TABS OR  
 1/8" (3mm) TABS  
 USED FOR LOW CAVITY HEIGHTS.  
 STACK UP TO 4 FIXED HEIGHT  
 PEDESTALS TOGETHER.

**GENERAL NOTES:** APPLY TO ALL OF THE ABOVE PRODUCTS

 1. INSTALLATION MUST BE COMPLETED IN ACCORDANCE WITH BISON INNOVATIVE PRODUCTS SPECIFICATIONS.
2. DRAWINGS NOT TO SCALE.
3. CONTRACTOR'S NOTE: FOR PRODUCT AND COMPANY INFORMATION VISIT [www.BisonIP.com](http://www.BisonIP.com)



## FIXED HEIGHT PEDESTALS AND SHIMS

STACKABLE PEDESTALS FROM 1/4" TO 3"