



Innovative Products


2395 West 4th Avenue Denver, CO 80223 USA
 Phone 303.892.0400 Toll Free 800.333.4234 Fax 303.825.5988
 EMail info@BisonIP.com Web www.BisonIP.com

Get CEU Credits, Details & Specifications online at BisonIP.com


SCREWJACK
 Adjustable Deck Supports



 
VT316
 FIXED HEIGHT 1/8"




HD25
 FIXED HEIGHT 1/4"

 


HD50
 FIXED HEIGHT 1/2"

 


HD75
 FIXED HEIGHT 3/4"

 


B1
 1 1/4" - 2"
 VERTICAL RANGE

 


B2
 2" - 3"
 VERTICAL RANGE

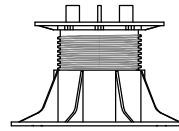


B3
 3" - 4 3/4"
 VERTICAL RANGE

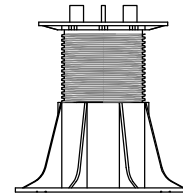


B4
 4 3/4" - 7 3/4"
 VERTICAL RANGE

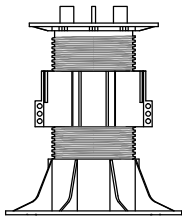

B3 + C4
 7 3/4" - 9" VERTICAL RANGE

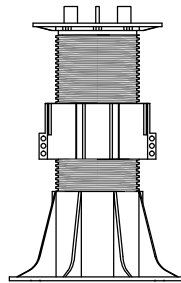

B4 + C4
 9" - 12" VERTICAL RANGE

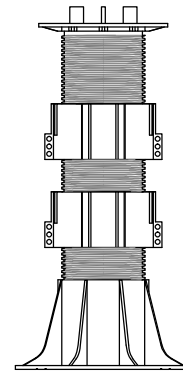


B4 + C4 + C4
 12" - 16" VERTICAL RANGE

PRODUCT CHARACTERISTICS

- MAXIMUM DESIGN CAPACITY OF 1000 LBS PER PEDESTAL, FACTOR OF SAFETY 2.
- SCREW ADJUSTABILITY WHILE PEDESTALS ARE LOADED FOR FINAL ADJUSTMENT.
- IMPERVIOUS TO FREEZE-THAW, WATER, MOLD AND SOLVENT FREE CHEMICALS.
- SCORED BASE ALLOWS SUPPORTS TO BE TRIMMED FOR TIGHT AREAS.
- WEIGHT BEARING SYSTEM DOES NOT PENETRATE ROOFING MEMBRANE OR SUBSTRATE.
- LARGE FOOTPRINT SPREADS WEIGHT OVER ROOFING MEMBRANE AND SUBSTRATE.
- MAXIMUM HEIGHT 16" OR UP TO 24" WITH ADDITIONAL BRACING.

GENERAL NOTES: APPLY TO ALL OF THE ABOVE PRODUCTS

1. INSTALLATION MUST BE COMPLETED IN ACCORDANCE WITH BISON INNOVATIVE PRODUCTS SPECIFICATIONS.
2. DRAWINGS NOT TO SCALE.
3. CONTRACTOR'S NOTE: FOR PRODUCT AND COMPANY INFORMATION VISIT www.BisonIP.com

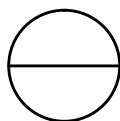

SCREWJACK PEDESTAL ELEVATIONS

ELEVATIONS FROM 1/8" TO 24"