


CAUTION

MOLDED SEALANT POCKETS MUST BE USED IN CONJUNCTION WITH RAIN HOODS FOR PROJECTS WITH 25 AND 30 YEAR WARRANTIES.

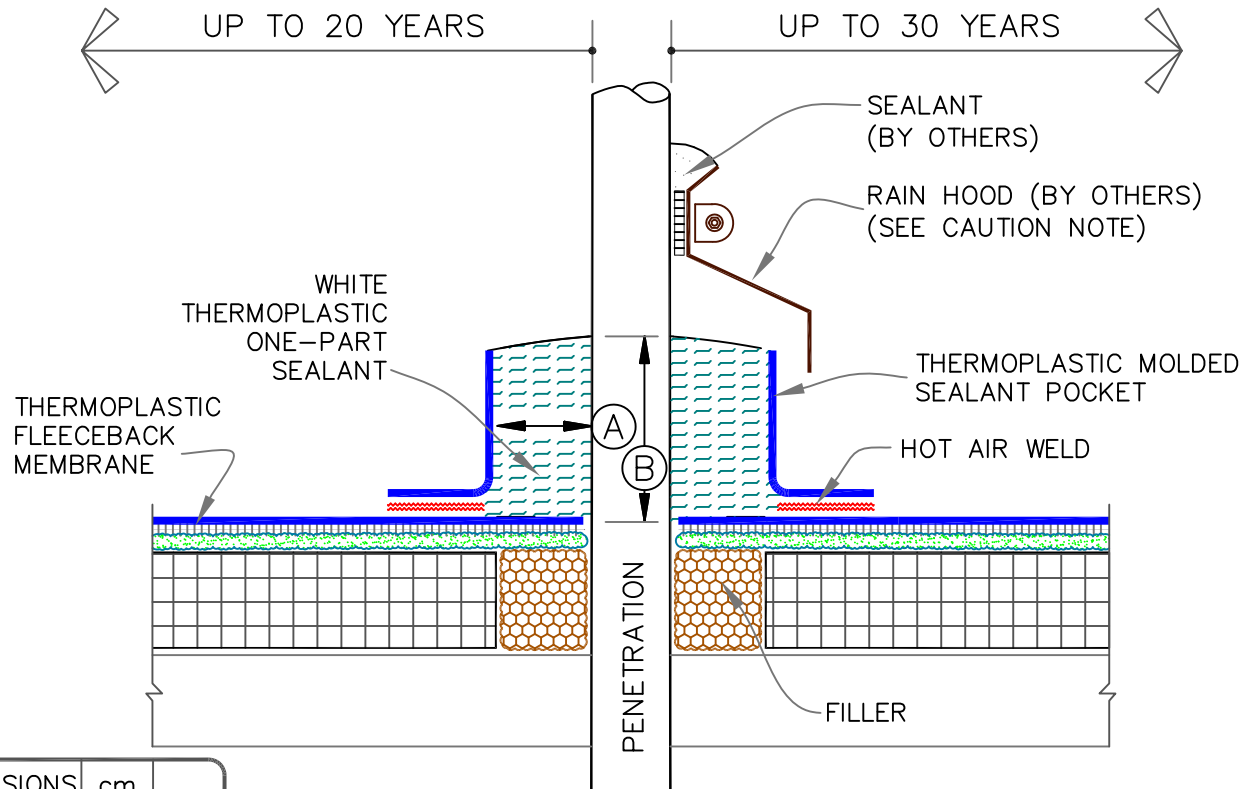


DIMENSIONS	cm	
(A)	1"	2.5 MIN.
(B)	2"	5 MIN.

NOTES:

1. TEMPERATURE OF PIPE MUST NOT EXCEED 160°F (71°C).
2. WHEN USING TPO MEMBRANE/MOLDED SEALANT POCKET, APPLY A THIN COAT OF TPO PRIMER TO THE INSIDE AND AROUND THE TOP RIM OF THE POCKET, TO THE DECK MEMBRANE ENCLOSED BY THE POCKET AND TO THE PENETRATION USING A SMALL PAINT BRUSH. WHEN USING PVC MOLDED SEALANT POCKET, CLEAN THE POCKET WITH PVC KEE HP CLEANER, APPLY TPO CLEANER TO PENETRATION(S) ONLY.
3. ONE-PART SEALANT MUST COMPLETELY FILL MOLDED SEALANT POCKET TO PREVENT PONDING OF WATER.
4. PIPE CLUSTERS MUST HAVE MINIMUM 1" (2.5cm) CLEARANCE BETWEEN PENETRATIONS.

PLACE MOLDED THERMOPLASTIC SEALANT POCKET AROUND PENETRATION AND OVERLAP THE TWO SECTIONS

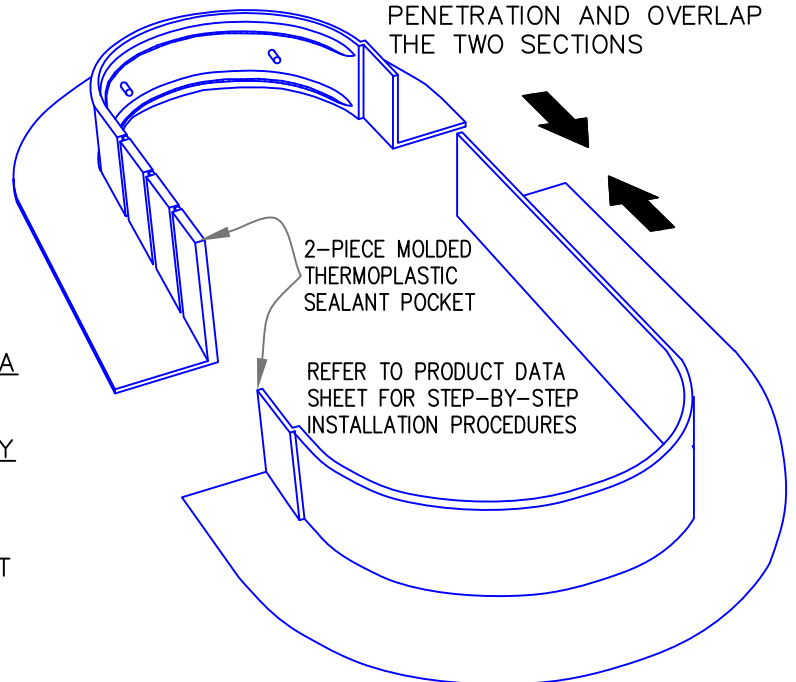

2-PIECE MOLDED THERMOPLASTIC SEALANT POCKET

REFER TO PRODUCT DATA SHEET FOR STEP-BY-STEP INSTALLATION PROCEDURES

	— FleeceBACK MEMBRANE
	— FLEX FAST/AQUABASE
	— APPROVED SUBSTRATE
	— SEE NOTE(S)

THERMOPLASTIC MOLDED SEALANT POCKET

MAXIMUM WARRANTY: 30 YEARS



DETAIL NO.

FB-16B.1

FLEECEBACK ADHERED