




60-MIL THICK PVC/TPO,  
UNIVERSAL CORNERS CAN  
BE USED FOR 3 DIFFERENT  
CORNER CONDITIONS AS  
SHOWN BELOW

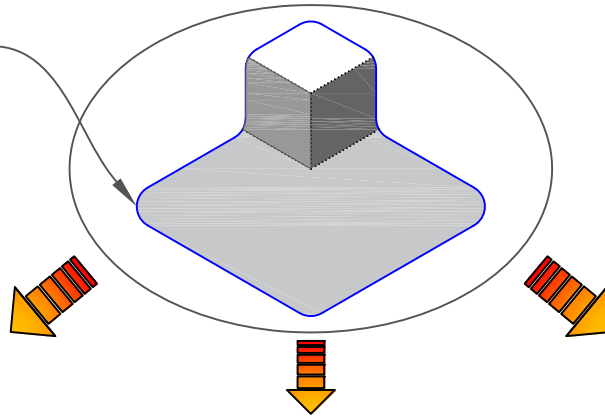


OPTION A

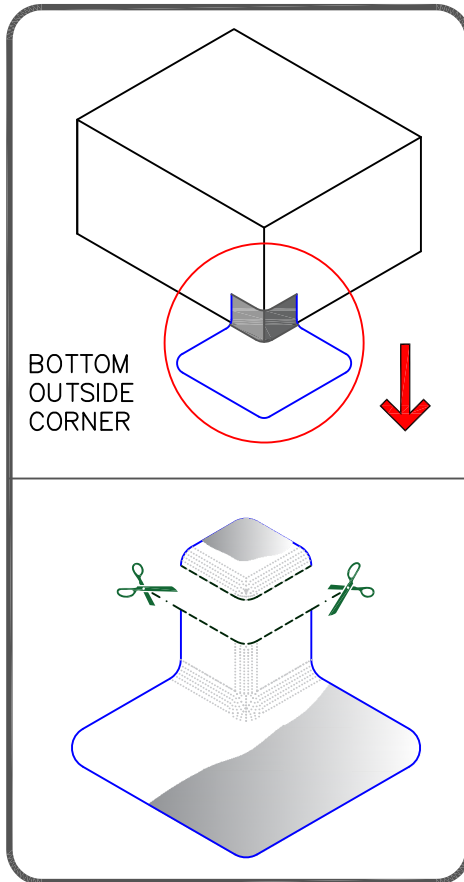

OPTION B

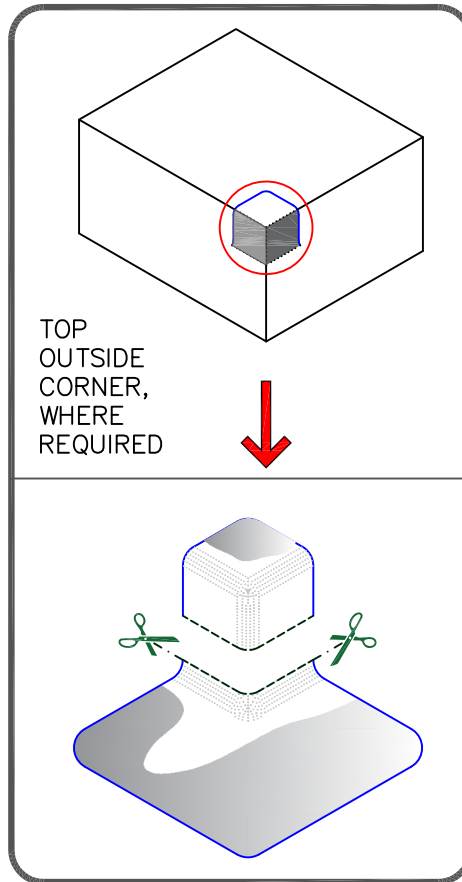


OPTION C

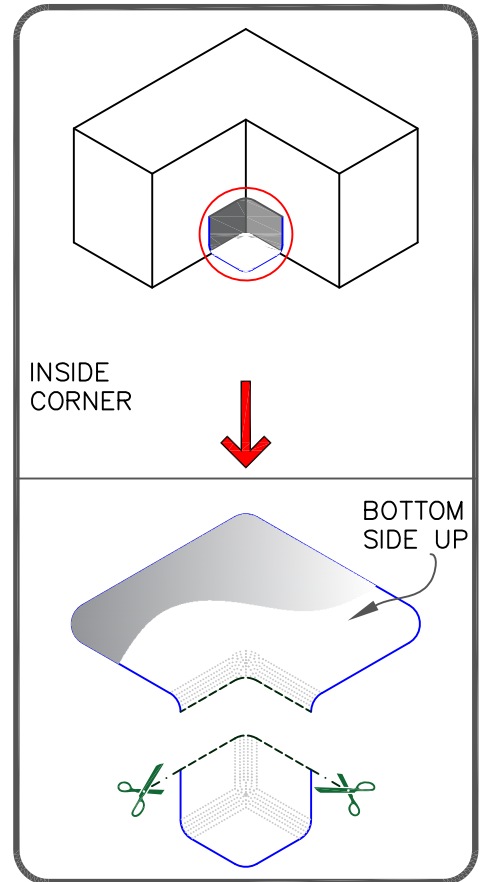


## NOTES:

1. ROOF SYSTEMS MUST NOT HAVE FIELD FABRICATED OR BUILT-IN CANT STRIP.
2. REFER TO TECHNICAL DATA BULLETINS FOR COLOR AVAILABILITY.

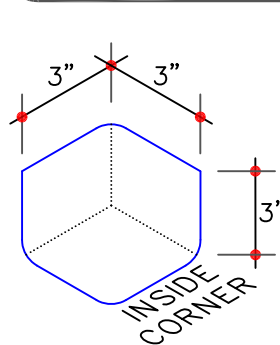

TYPICAL DIMENSIONS

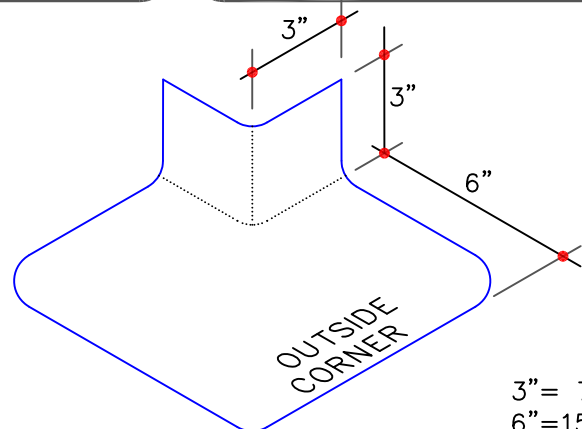

3" = 7.5cm  
6" = 15cm



PVC OR TPO:  
UNIVERSAL CORNERS – COMBINATION  
INSIDE & OUTSIDE CORNERS  
MAXIMUM WARRANTY: 30 YEARS



DETAIL NO.

U-15G

THERMOPLASTIC UNIVERSAL