

Approved  YES  NO


Approved By: \_\_\_\_\_

Date: \_\_\_\_\_

# MaxClean

## STANDARD SYSTEM INCLUDES

- DIRECT DRIVE MOTOR, UP TO 96ips OPENING SPEED
- PVC CURTAIN - BLUE
- ANTI-U.V. VISION PANEL: QTY.01
- INTEGRATED LIGHT CURTAIN
- 304 STAINLESS STEEL SLANTED EXTERIOR HOOD & MOTOR COVER
- 304 STAINLESS STEEL GUIDES
- VARIABLE FREQUENCY PROGRAMMABLE CONTROLLER
- LINTEL BRUSH SEAL

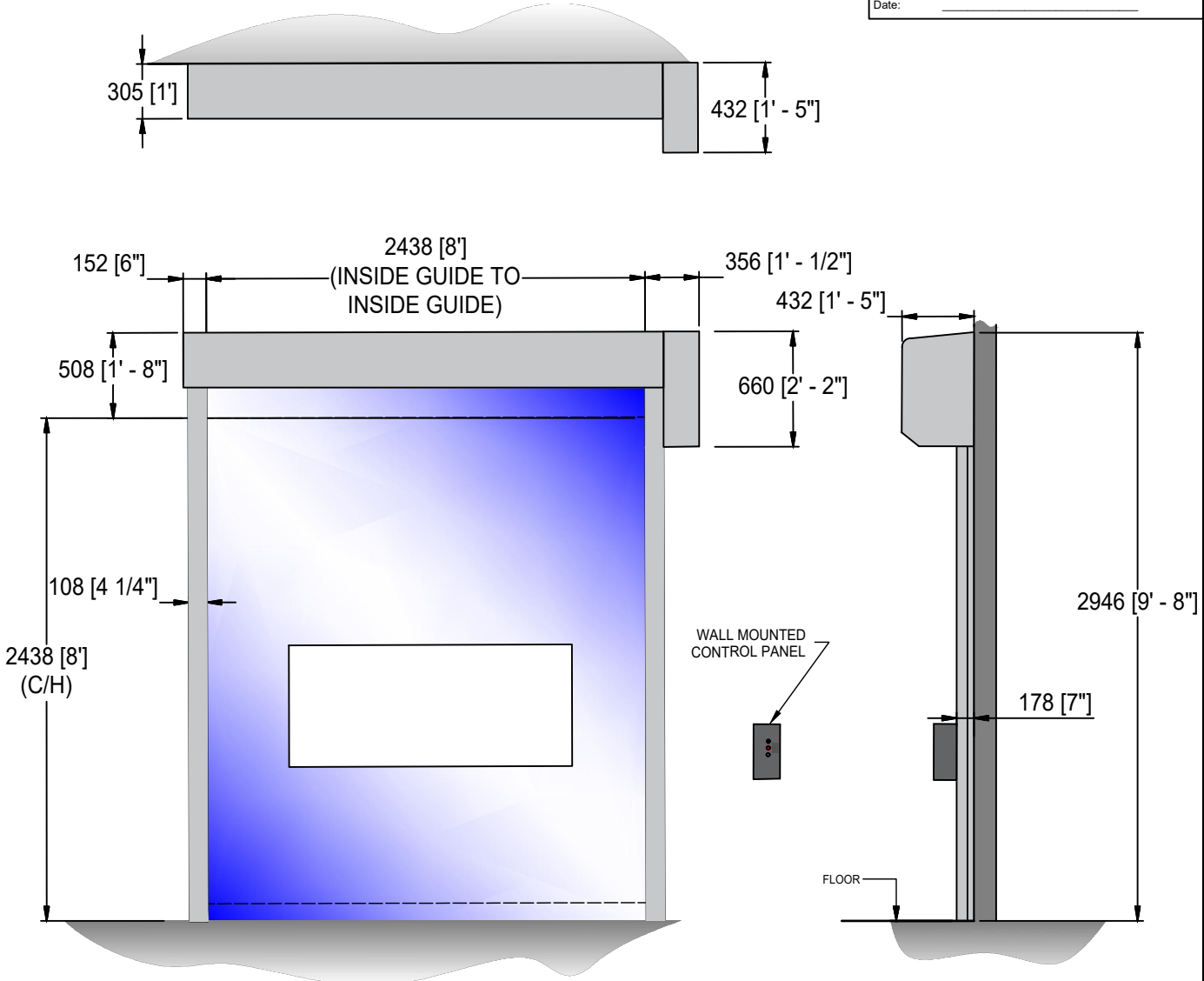

INSIDE GUIDE MEASUREMENT  
REFERENCES STEEL TO STEEL  
DO NOT MOUNT GUIDES FLUSH WITH  
JAM

MECHANICAL / ELECTRICAL OPTIONS  
OVERRIDES STANDARD SYSTEM

**ELECTRICAL CRITERIA:**  
CONTROL PANEL IP54 STD.  
PRIMARY POWER SUPPLY 230V, 3PHASE, 60HZ,  
10A FUSED DISCONNECT

NOTES:

PROJECT :

DEALER :

DRIVE:  
RIGHT HAND

MOUNT:  
INTERIOR



(484) 840 - 8500  
5 Crozerville Road | Aston, PA 19014

	DATE	NAME
DRAWN	07/17/2020	C.LATSIOS
CHECKED	07/17/2020	G.PRZYDZIAL

[QTY.01] MaxClean  
8 ft (W) x 8 ft (H)

PERFORMAX IS NOT RESPONSIBLE FOR CUSTOMER ADDED  
ACCESSORIES

COPYRIGHT: The design and engineering content shown on this drawing remains the property of PERFORMAX, and may not be copied in any way without prior written approval from the company.

Drawing Number  
MAXCLEAN - MC250 - 96X96

Rev.  
0