



Exterior Elevation

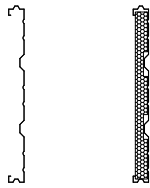


non-insulated section side view
insulated section side view

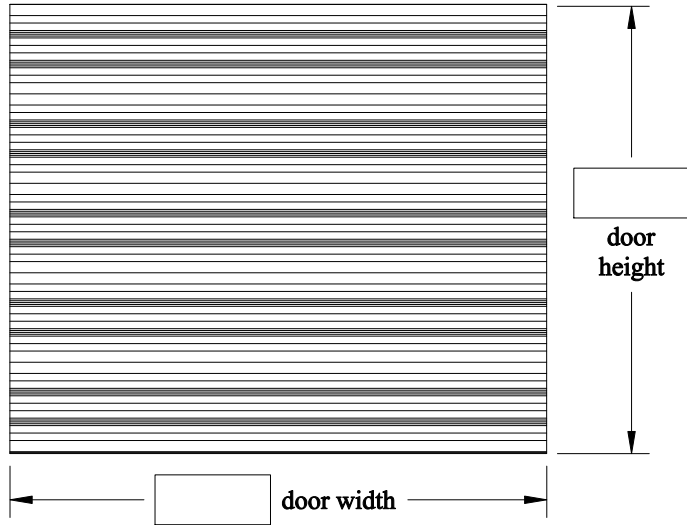

Interior Elevation

height	sections
6'-3" to 8'-0"	4
8'-3" to 10'-0"	5
10'-3" to 12'-0"	6
12'-3" to 14'-0"	7

width	panels
8'-0" to 9'-5"	2
9'-6" to 12'-11"	3
13'-0" to 16'-5"	4
16'-6" to 18'-2"	5

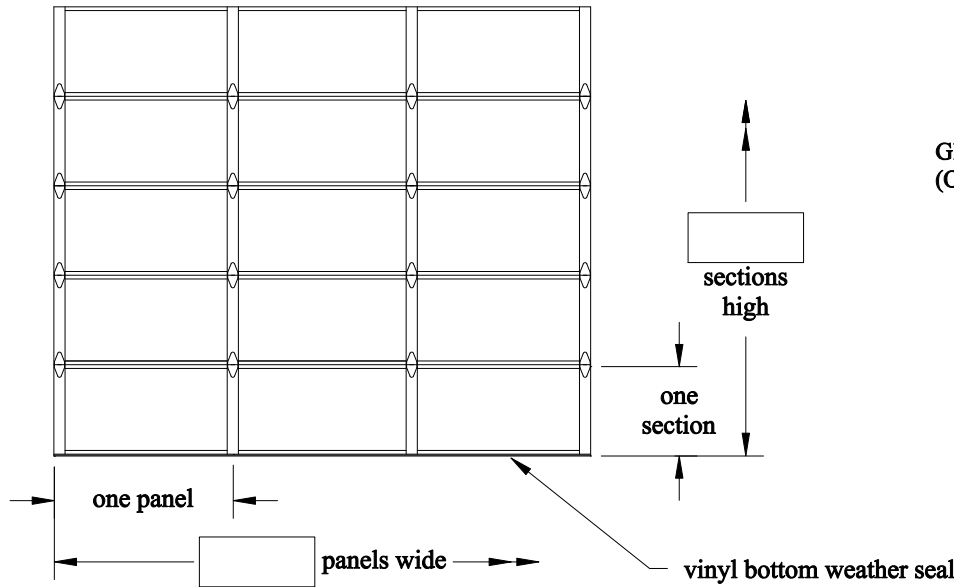

Panel Material: 25 gauge commercial quality steel, hot dipped G60 galvanized.

Color: Exterior: White polyester top coat over primer.
Interior: Gray polyester primer coat.

Section Thickness: 2"

Panel Profile: Two horizontal ribs with alternating 'v' grooves.

Joint Design: Tongue and groove rails.

Stiles: Box style, 18 gauge galvanized steel, full height of section. Riveted to inside rails and face of door.

Insulation: (3250) None
(3251) CFC-free polystyrene with laminated vinyl backer. Average R-Value of 6.81; U-Value of 0.15
(3252) CFC-free polystyrene with steel backer. Average R-Value of 6.81; U-Value of 0.15

Glazing (Optional): (3250) 24" x 6" x 1/8" DSB or Lexan
24" x 12" x 1/8" DSB or Lexan
Aluminum Full View White or Clear Anodized
1/8" DSB glass, 1/8" Lexan, 1/4" Tempered glass
(3251/52) 24" x 6" x 3/4" Insulated glass
24" x 12" x 3/4" Insulated glass
34" x 16" x 3/4" Insulated glass
(34" x 16" Not Available in End Panels on 10' and 14' Wide Doors)
Aluminum Full View White or Clear Anodized
1/8" DSB glass, 1/8" Lexan, 1/4" Tempered glass
7/16" Insulated glass

05/2006 Copyright 2001 C.H.I. Overhead Doors

Door Qty.	Door Width	Door Height	Jamb Type	Model	Exterior Color

Miscellaneous Notes

C.H.I. OVERHEAD DOORS
1485 Sunrise Drive, Arthur, IL 61911
TOLL FREE: 800-677-2650 FAX: 217-543-3087

C.H.I. 25 Gauge Commercial Ribbed Door

ARCHITECT:	
CONTRACTOR:	
PROJECT NAME:	
DOOR COMPANY:	
QUOTE NUMBER:	DOOR NUMBER:
PREPARED BY:	DATE: