
 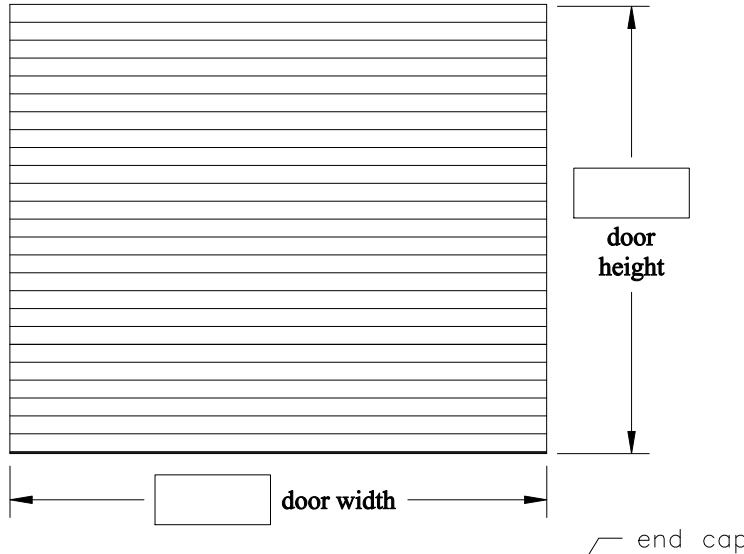



Exterior Elevation



Interior Elevation

height	sections
6'-3" to 8'-0"	4
8'-3" to 10'-0"	5
10'-3" to 12'-0"	6
12'-3" to 14'-0"	7
14'-3" to 16'-0"	8
16'-3" to 18'-0"	9
18'-3" to 20'-0"	10

width	panels
8'-0" to 9'-5"	2
9'-6" to 12'-11"	3
13'-0" to 16'-5"	4
16'-6" to 20'-2"	5
20'-3" to 24'-2"	6

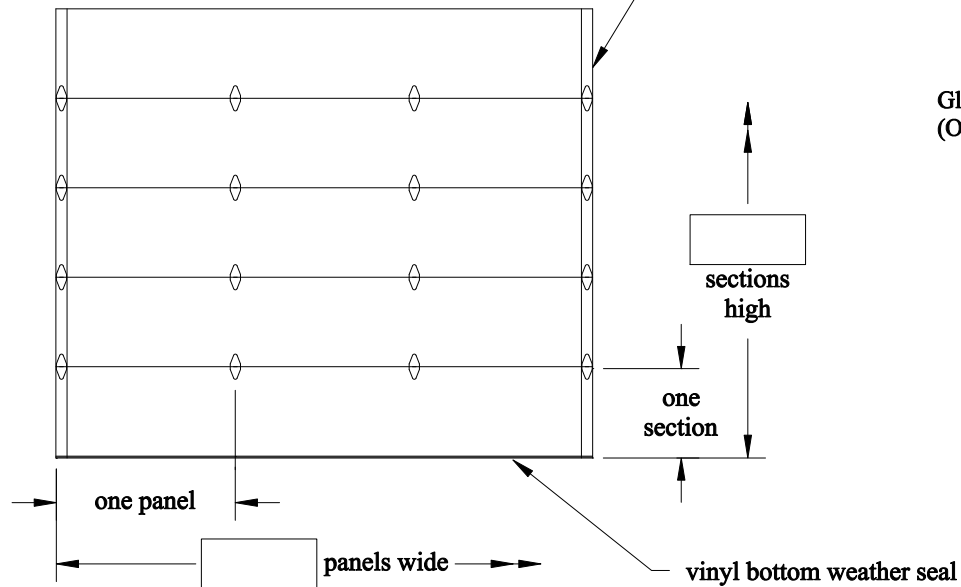

Panel Material: 26 gauge exterior / 27 gauge interior, hot dipped G40 galvanized steel.

Color: Exterior: polyester top coat over primer.
☐ White ☐ Brown ☐ Sandstone
 Interior: White polyester primer coat.

Section Thickness: 2"

Panel Profile: Wood grain embossed exterior with four micro-grooves; wood grain flush interior.

Joint Design: Tongue and groove rails.

End Cap: 20 gauge white painted galvanized steel, full height of section.

Insulation: CFC-free polystyrene laminated to exterior and interior panels. Average R-Value of 8.72; U-Value of 0.115

Glazing (Optional): 24" x 6" x 3/4" Insulated glass
 24" x 12" x 3/4" Insulated glass
 34" x 16" x 3/4" Insulated glass
 (34" x 16" Not Available in End Panels on 10', 14', 18', 22' and 24' Wide Doors)
 Aluminum Full View White or Clear Anodized
 1/8" DSB glass, 1/8" Lexan, 1/4" Tempered glass
 7/16" Insulated glass

05/2006 Copyright 2001 C.H.I. Overhead Doors

Door Qty.	Door Width	Door Height	Jamb Type	Model	Exterior Color
Miscellaneous Notes					



C.H.I. (3285) Micro Grooved Commercial Sandwich Door

ARCHITECT:	
CONTRACTOR:	
PROJECT NAME:	
DOOR COMPANY:	
QUOTE NUMBER:	DOOR NUMBER:
PREPARED BY:	DATE: