


# “Vertarib” Standard Details

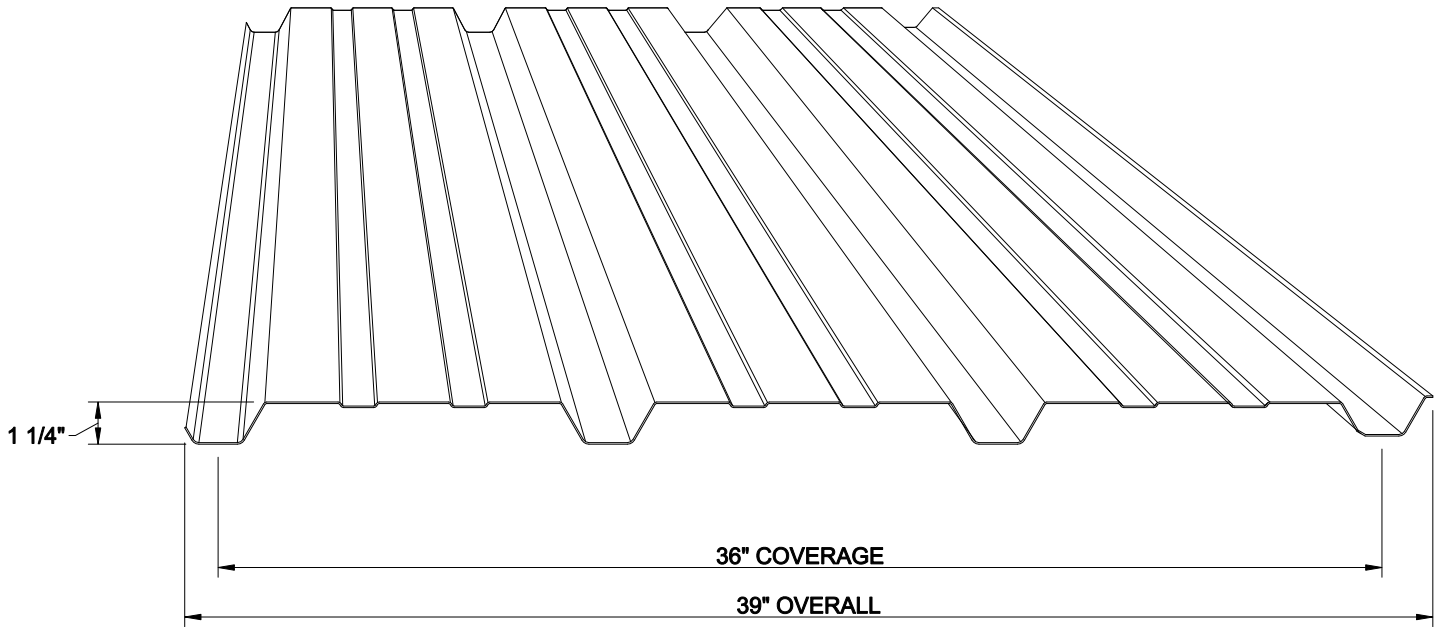

## Vertarib Load Table

### Span Length

Thickness	# Spans	3'	3' 6"	4'	4' 6"	5'	5' 6"	6'	6' 6"	7'	7' 6"	8'	8' 6"	9'	9' 6"	10'
18 Ga STL.	1	288	211	162	128	103	85	72	61	52	46	40	35	32	28	25
	3	337	247	189	150	121	100	84	71	62	54	47	42	37	33	30
20 Ga STL.	1	213	156	119	94	76	63	53	45	39	34	30	26	23	21	19
	3	245	180	137	108	88	72	61	52	45	39	34	30	27	24	22
22 Ga STL.	1	213	156	120	94	76	63	53	45	39	34	30	26	23	21	19
	3	258	189	145	114	92	76	64	55	47	41	36	32	28	25	23
24 Ga STL.	1	156	115	88	69	56	46	39	33	28	25	22	19	17	15	14
	3	183	134	103	81	65	54	45	39	33	29	25	22	20	18	16
26 Ga STL.	1	100	73	56	44	36	29	25	21	18	16	14	12	-	-	-
	3	119	87	67	53	43	35	29	25	21	19	16	14	13	-	-

Stress governing, 37 ksi yield for 18, 20 Ga; 50 ksi for 22, 24 and 26 Ga. (PSF)  
1/3 increase for wind load included, outward pressure shown; Vertarib is for wall use only

FLEXOSPAN RESERVES THE RIGHT TO REVISE, ADD, OR DELETE ANY DETAIL OR INFORMATION HEREIN WITHOUT PRIOR NOTICE.

**FLEXOSPAN**  
BOX 515 RAILROAD STREET  
SANDY LAKE, PENNSYLVANIA 16145-0515  
PHONE: 800-245-0396 ° FAX: 724-376-3864

“Vertarib” Standard  
Details

COVER

DRAWN BY: D.UREY

DATE: 9/20/05

DRAWING NO.

CHECKED BY:

DATE:

Vertarib - C