 



START WITH ANNEALED GLASS
 CLEAR
 WATER WHITE
 TINTED
 FROSTED
 PATTERNED or
 PATTERN REVERSED




COLORSPAN™



 ADD COATING - TOTALLY or in COMBINATION
 TRANSLUCENT
 SILVER for MIRROR
 SOLID COLOR
 METALLIC
 PEARLSECENT




ADD INNERLAYER LAMINATION TO MAKE
 COLORSPAN I - SAFETY GLASS

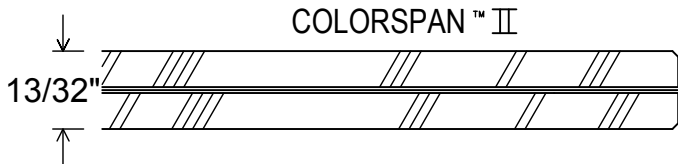


LAMINATE COLORSPAN I TO:
 COLORSPAN TO MAKE COLORSPAN II

OR

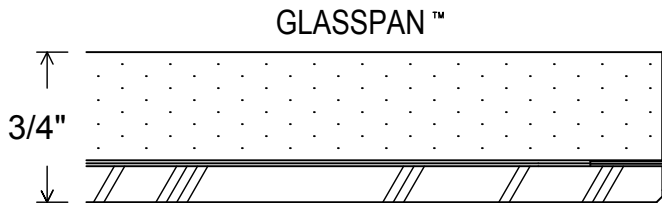

LAMINATE COLORSPAN I TO:
 COMPOSITE BACKER TO MAKE GLASSPAN

OR

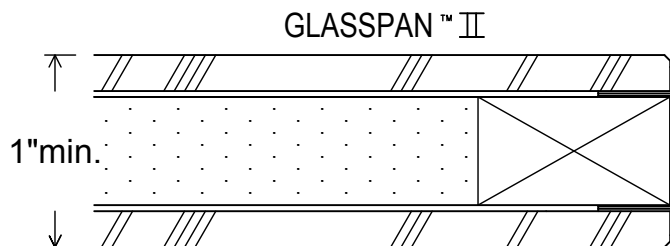

LAMINATE COLORSPAN I TO:
 GLASSPAN TO MAKE GLASSPAN II

STANDARD - FACTORY APPLIED
 VINYL PROTECTIVE EDGE ANGLE

FULLER PHOENIX ARCHITECTURAL PRODUCTS

PRODUCT PROFILE

COLORSPAN

Back painted glass for adhesive application.

- Uses:** Walls
Counter Fronts
Table Tops
Signage
- Finishes:** Solid Colors, metallics and pearls
Translucent areas and graphics
Standard and custom colors
Annealed or tempered glass
- Sizes:** Maximum size 72 X 130
48 X 84 Maximum in metallic and pearls
1/8" to 3/4" thick
Tolerance: +0" – 1/32"
- Edges:** Ground and painted with a 1mm arris
- Advantages:** Available in any color
Cleanable and easily maintained
Simple to install, can be field-cut
Economical for renovation or new construction
Color is protected by glass for the life of the job

COLORSPAN I

COLORSPAN or mirror with factory-applied safety glass backer on the back for adhesive application.
Meets ANSI Z97.1, Category I or II; approved for elevators.

- Uses:** Walls
Elevators
Signage, Counter Fronts, Specialties
Any application requiring safety glass
- Finishes:** Colors: See COLORSPAN
Mirror: clear, bronze, gray, black, green, blue and peach
- Sizes:** Mirror Maximum 72 X 130
3/16" (2.5 lbs per sq ft) and 1/4" (3.25 lbs per sq ft) thickness
Tolerances: +0" – 1/32"
- Advantages:** Same as COLORSPAN, plus
Stronger than standard 1/4" laminated glass
Lighter than standard laminated glass
Can sometimes be repaired on-site

COLORSPAN II

COLORSPAN laminated to COLORSPAN I – Surfaces may be the same color or different.
Meets ANSI Z97.1, Category II.

- Uses:** Surfaces installed in glazing channels where color and graphics are visible from
Both sides.
Banners and dividers.
- Finishes:** See COLORSPAN I
- Sizes:** Maximum 48 X 72
1/4", 3/8" and 1/2" thickness
Tolerance: +/- 1/16"
- Advantages:** Total Opacity
Graphics not visible from back side

GLASSPAN

Glass laminated to composite backer for strength and impact resistance. Adhesive application. Internal wood framing may be integrated for mechanical fasteners and/or metal trim. Meets ANSI Z97.1, Category I or II; ASTM E-84, Class I(A). Weight: 2.5 – 2.8 lbs per sq ft.

Uses: Walls
Ceilings
Elevators
Trim Details: Series 060, 125/125EX, 250/250EX, 500/500EX
1000/1000EX

Finishes: See COLORSPAN I

Sizes: Per design requirements; See COLORSPAN
7/8" to 1" thickness

Advantages: Excellent impact resistance
Installed by any interior finish trade
Factory fabricated panels and metal trim
System eliminates costly field fabrication
Can sometimes be repaired in place

GLASSPAN-TR

Glass laminated to composite backer that has been successfully tested and approved for use in New York City per Gas/Fire Toxicity requirements, MEA No. 279-89-M. Weight: 3.5 – 3.9 lbs per sq ft.

All other features – See GLASSPAN

GLASSPAN II

Glasspan panel finished on both sides. Meets ANSI Z97.1; ASTM E-84 Class I(A).

Uses: Partitions

Finishes: See COLORSPAN II

Sizes: Maximum 48 X 108, 1" minimum thickness

Finishes: Color and/or graphics may be different on each side

TRIM DETAILS:

SERIES 060	1/16" Metal Trim
SERIES 125	1/8" Metal Trim, flush
SERIES 125EX	1/8" Metal Trim, extended
SERIES 250	1/4" Metal Trim, flush
SERIES 250EX	1/4" Metal Trim, extended
SERIES 500	1/2" Metal Trim, flush
SERIES 500EX	1/2" Metal Trim, extended
SERIES 1000	1" Metal Trim, flush
SERIES 1000EX	1" Metal Trim, extended
FINISHES:	Stainless Steel, painted or anodized aluminum, brass, oxidized brass, and copper
TEXTURES:	Satin or polished