


Pos-I-Tie® KeyBolt Stone Anchor Systems - for Steel-Stud, CMU, Concrete or Wood-Stud #75KB

75-KB Split-Bend Stone Anchor

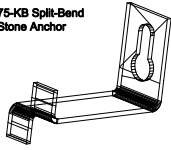

75-KB Z-Type Stone Anchor




75-KB Welded Plate Stone Anchor






75-KB Pin-Type Stone Anchor





75-KB U-Type Stone Anchor

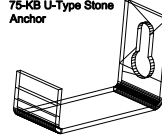

Pos-I-Tie® KeyBolt Standard Sizes

  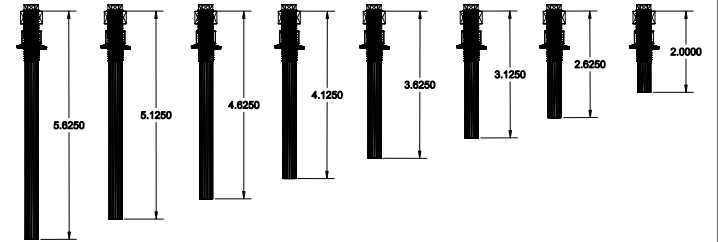

All bends, plate lengths, anchor thickness, and non KeyBolt-slot dimensions must be specified

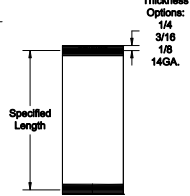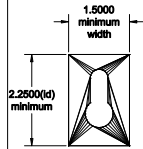


75-KB Split-Bend Stone Anchor



75-KB Z-Type Stone Anchor



 
75-KB Welded Plate Stone Anchor




75-KB Pin-Type Stone Anchor




75-KB U-Type Stone Anchor

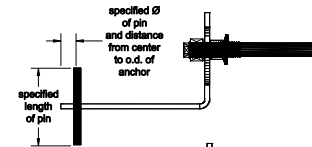


75-KB Pin-Type Stone Anchor

 


75-KB U-Type Stone Anchor

 

75-KB Z-Type Stone Anchor

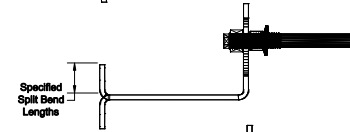

75-KB Split-Bend Stone Anchor

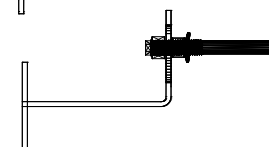

75-KB Welded Plate Stone Anchor

