

helo

COMMERCIAL

DRAWING #
136489D

 
INVOICE # R

COMPANY: Private Residence
JOB NAME: 108 x 129 Sauna

WOOD TYPE: CEDAR


T&G DIRECTION: VERTICAL

ROOM HEIGHT: 84"

JOIST DIRECTION: Left to Right


SQ. FOOTAGE: 93.3

Door Size/Style DF 24X80
 Door Jamb Width 4-1/2"
 Interior Upgrade SEE NOTES
 Htr. Size/Model LAAVA 14.4
 Control Type SC-60
 Voltage/Phase 240V/1P
 Lighting Option WALL, SEE NOTES

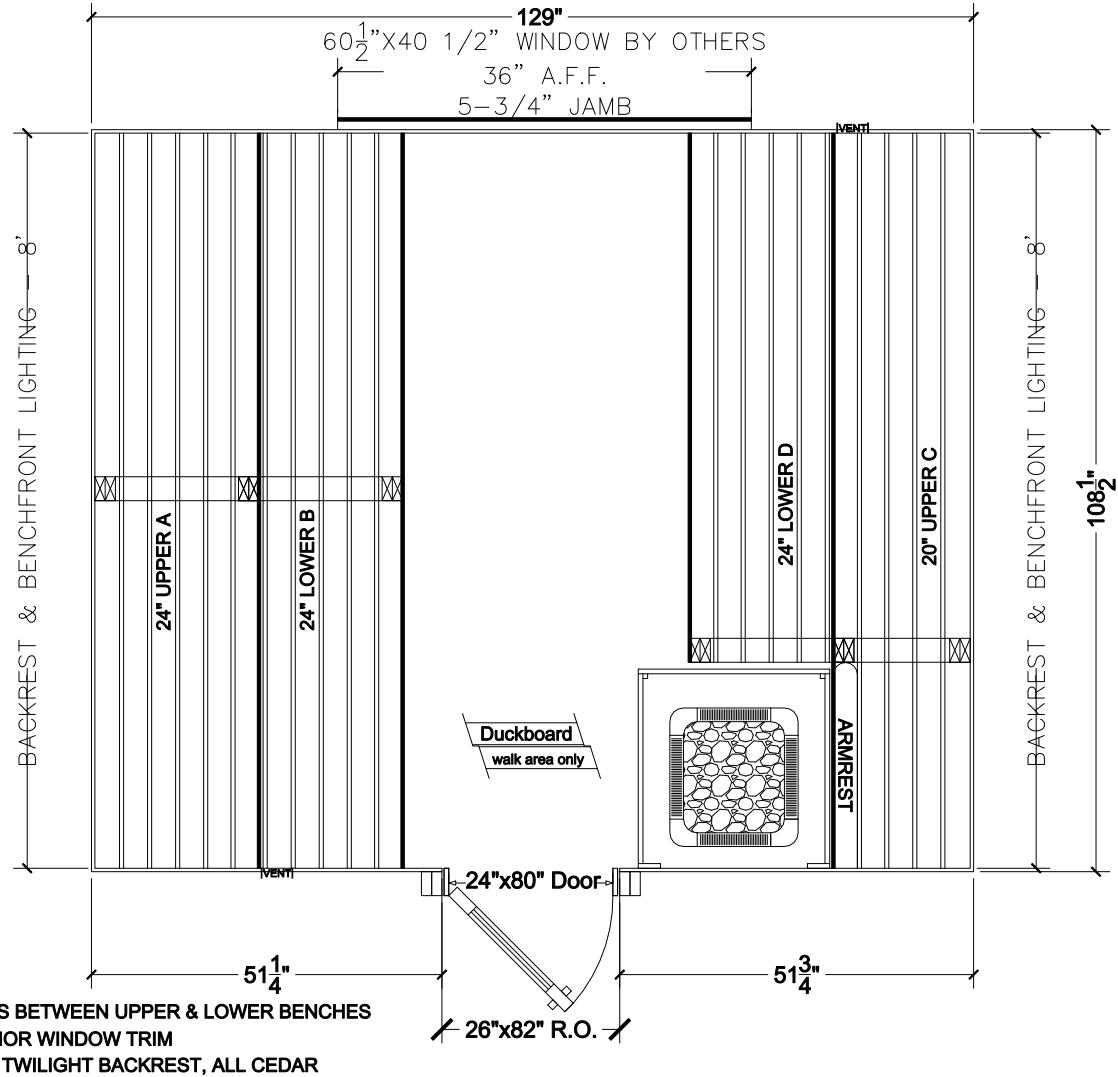

| Item No. | Item description | QTY | control |
|----------|--|-----|-------------|
| 8801-231 | LIGHT,INSTALL,PRIMARY SURFACE,WHT LED,STRIP,W/O CNTRL | 8' | SAUNACHROME |
| 8801-232 | LIGHT,INSTALL,ADDITIONAL SURFACE,WHT LED,STRIP,W/O CNTRL | 8' | SAUNACHROME |
| 8801-232 | LIGHT,INSTALL,ADDITIONAL SURFACE,WHT LED,STRIP,W/O CNTRL | 8' | SAUNACHROME |
| 8801-232 | LIGHT,INSTALL,ADDITIONAL SURFACE,WHT LED,STRIP,W/O CNTRL | 8' | SAUNACHROME |
| 9227-349 | CNTRL,KIT,SAUNACHROME,WHITE LIGHT,LED | 1 | |

Customer Approval:

Dimensions are stud to stud, unless otherwise noted

custom cut sauna