

560 SERIES BOTTOM 90° STAGGERED STACKING SLIDER

PANEL RAIL OPTIONS:

4" or 6" EXTRUDED ALUMINUM RAIL
or VARIABLE HEIGHT COMPOSITE
ALUMINUM RAIL (clad only)



FINISHES:

See Page 02

* AVAILABLE IN 1 TYPE OF BOTTOM
ROILING TRACK CONFIGURATIONS.

NOT TO EXCEED 181 Kg (400 lbs.)

STACKING ROOM with DOOR
BY OTHERS

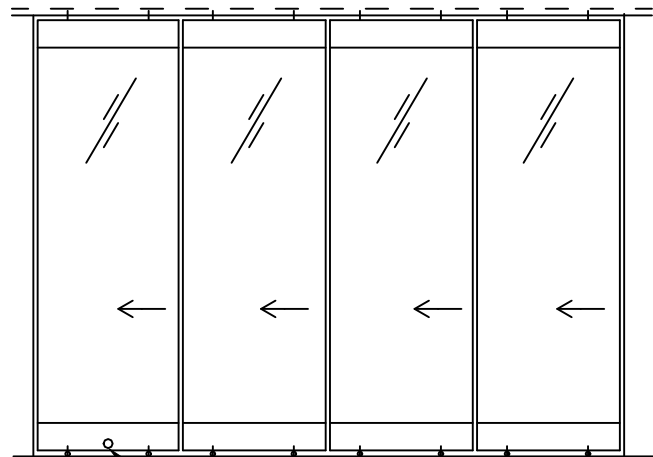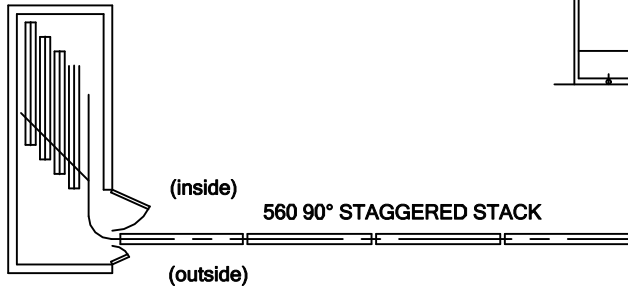

AR1861 LOCK with CYLINDERS
OUTSIDE. See Page 33