

610 SERIES**BI-FOLD DOOR****BI-FOLD DOORS:**

EACH DOOR CONSISTS of TWO PANELS

- * MAXIMUM PANEL WIDTH: 32" (813mm)
- * MINIMUM PANEL WIDTH: 24" (610mm)
- * MAXIMUM PANEL HEIGHT: 84" (2134mm)


Bi-fold arms can be mounted in rails or patch fittings - see Page 06.

IMPORTANT NOTE:

FLOOR UNDER DOOR SWING MUST BE HORIZONTAL TO PREVENT CANTILEVERED PANELS FROM MAKING CONTACT.

Standard bottom clearance is 1/2" (12.7mm)

* Please contact us for advice on your requirements for CUSTOM DOORS exceeding these sizes.

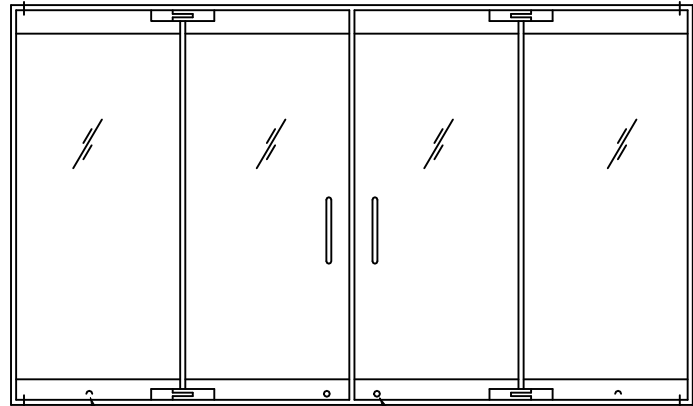

LOCK with
THUMBTURN INSIDE

LOCK with
CYLINDERS OUTSIDE,
THUMBTURN INSIDE