


## V CONTROL JOINT

PRODUCT NUMBER	GROUND	DIMENSION DESCRIPTION	PIECES PER BOX
2038	3/8"	"V" CONTROL JOINT 4 1/8" OVERALL WIDTH WITH PERFORATED FLANGES	35
2050	1/2"		35
2058	5/8"		35
2075	3/4"		30
2078	7/8"		25
2100	1"		20

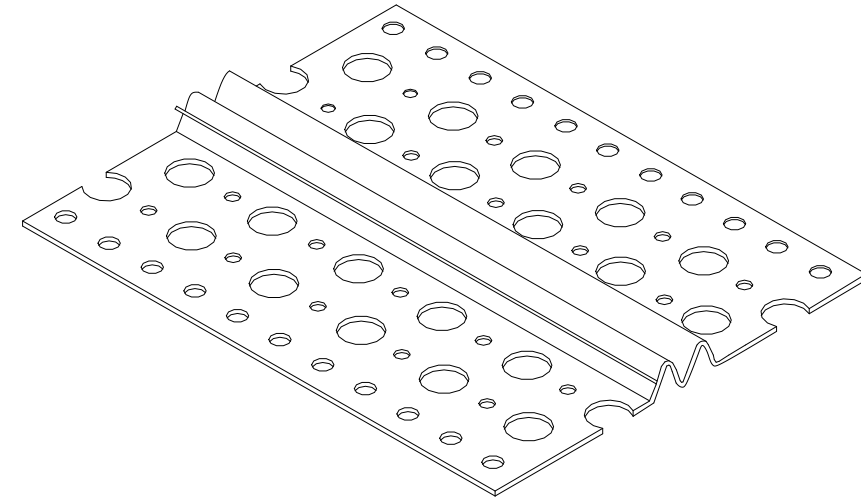

**APPLICATION:**  
SHOULD BE USED IN ANY APPLICATION WHERE A SURFACE AREA IS MORE THAN 144 SQUARE FEET. THE WIDE FLANGE ALLOWS FOR MORE "KAYING" OF THE STUCCO. THE "EYEBROWS" ALLOW FOR THE STUCCO TO KEY TO THE "V". VERTICAL JOINTS SHOULD BE ATTACHED TO A STUD WHERE NECESSARY.

**SPECIFICATION:**  
CONTROL JOINTS SHALL BE PLASTIC COMPONENTS, INC. # \_\_\_\_\_ . ALL EXTERIOR ACCESSORIES SHALL BE OF PVC MATERIAL CONFORMING TO ASTM STANDARDS D1784-97 AND C1063-99 AND D4216-99. THEY SHALL BE USED WHERE SPECIFIED BY THE ARCHITECT AND INSTALLED PER INDUSTRY STANDARDS AND MANUFACTURER'S INSTRUCTIONS.

