


## OBSTRUCTION LIGHT OL01

- FAA L-810 DOUBLE LIGHT
- FIXED MOUNT
- STEELWORK MOUNTED
- EXPOSED CABLE ENTRY


INCANDESCENT:  
POL-20000-R-116-34B-DJ-CF[C]  
  
LED:  
POL-21005-xF-R-34B-D-CF[C]  
POL-22001-xF-R-34B-D-CF[C]

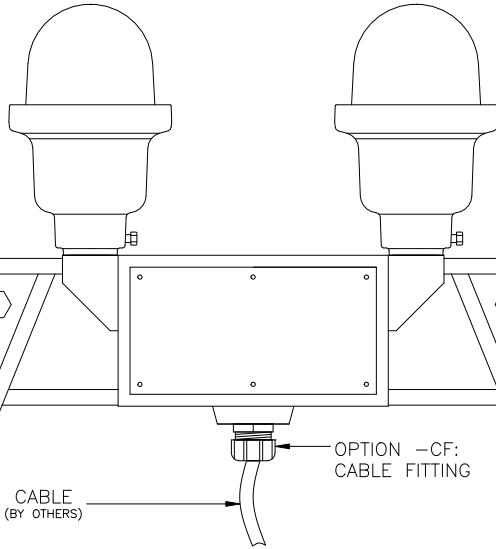

## OBSTRUCTION LIGHT OL02 WITH OPTION -P

- FAA L-810 DOUBLE LIGHT
- FIXED MOUNT
- CONDUIT MOUNTED
- RIGID CONDUIT ENTRY

INCANDESCENT:  
POL-20000-R-116-34B-DJ-P  
  
LED:  
POL-21005-xF-R-34B-D-P  
POL-22001-xF-R-34B-D-P

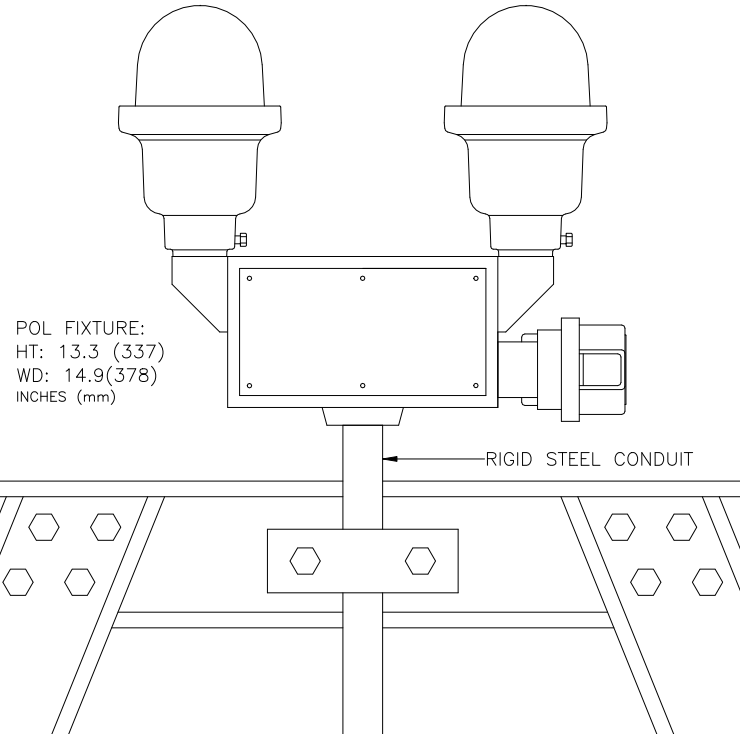

## OL03


### OBSTRUCTION LIGHT

- STANDARD FAA POL
- RIGID MOUNT
- EXTENDED HEIGHT
- EXPOSED CABLE OR RIGID CONDUIT ENTRY

INCANDESCENT:  
POL-20000 SINGLE

LED:  
POL-21005 SINGLE  
POL-22001 SINGLE

JUNCTION BOX:  
PJB-40092-34(3)

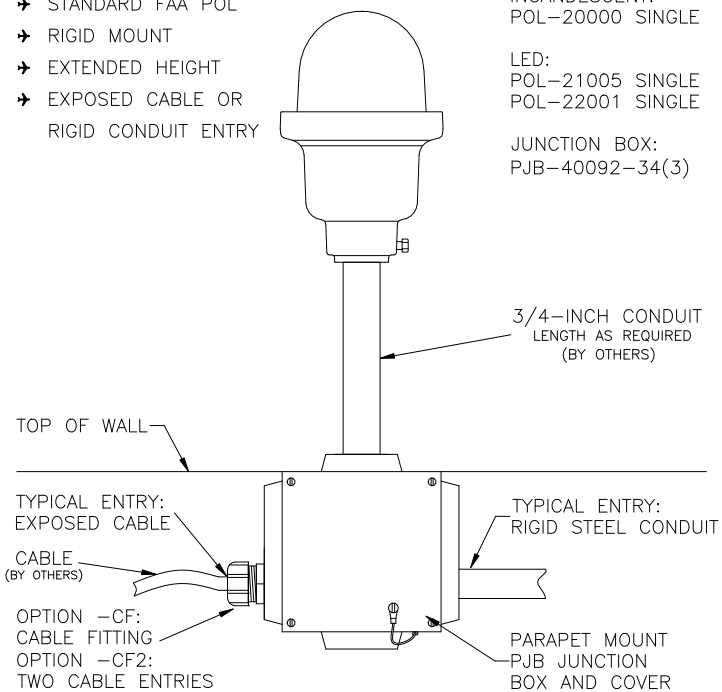

## OL04

### OBSTRUCTION LIGHT

- STANDARD FAA POL
- RIGID MOUNT
- RIGID CONDUIT ENTRY

INCANDESCENT:  
POL-20000 SINGLE

LED:  
POL-21005 SINGLE  
POL-22001 SINGLE

LED POL FIXTURE:  
HT: 8.6 (217)  
WD: 5.0 (127)

INCANDESCENT POL:  
HT: 8.4 (214)  
WD: 5.0 (127)

INCHES (mm)

