

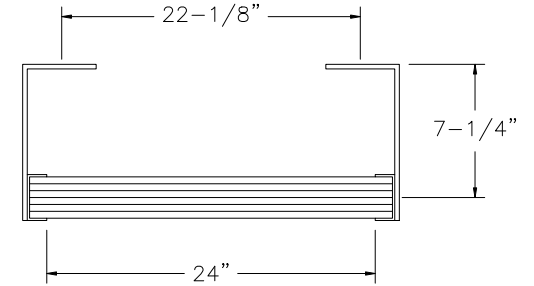
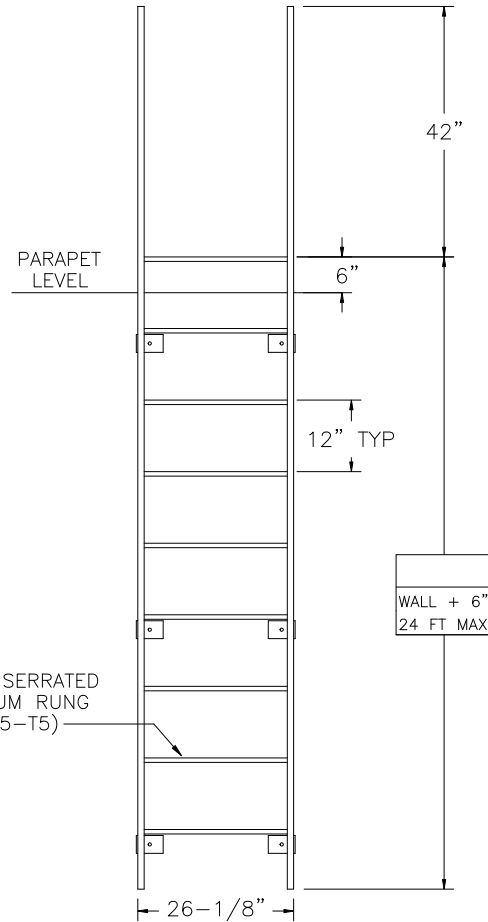


FIXED LADDER WITH PARAPET PLATFORM & ROOFSIDE RETURN

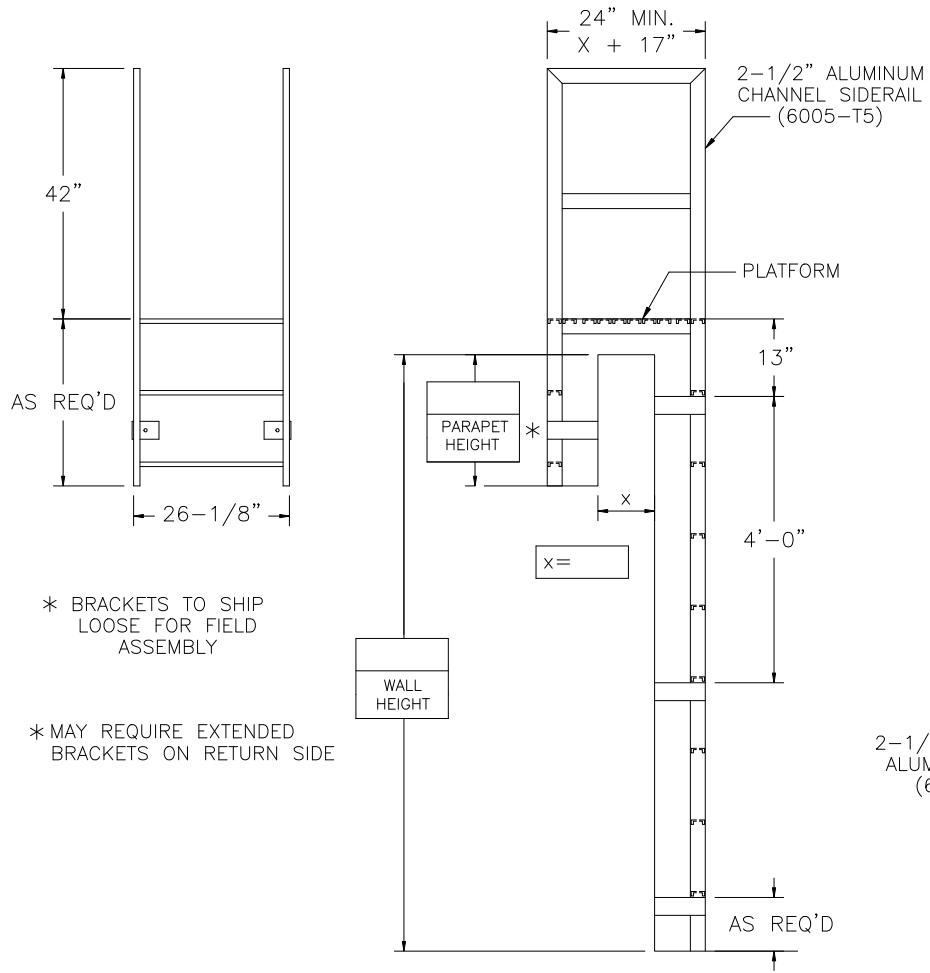

PLAN
(PARAPET PLATFORM & RETURN LADDER ARE OMITTED FOR CLARITY)

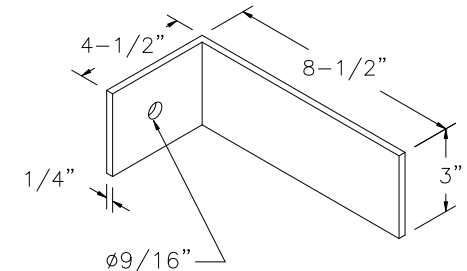

BRACKET DETAIL

NOTE:
ALL BOLTS/FASTENERS
NECESSARY TO ANCHOR
LADDER ARE BY OTHERS.

NOTE: FALL ARREST SYSTEM REQUIRED ON LADDERS EXCEEDING 24'-0" (SEE DETAIL FLH-09-FAS)

FACTORY FINISH
ALUMINUM-MILL FINISH

FL-06

LADDERS MANUFACTURED BY PRECISION LADDERS, LLC
COMPLY WITH OSHA 1910 SUBPART D AND ANSI 14.3

LADDER RATED AT 1,500 LBS



Precision Ladders, LLC

P.O. BOX 2279 Morristown, TN 37816-2279
Ph: (423) 586-2265 Fax: (423) 586-2091
www.PrecisionLadders.com

WORK ORDER: ()

DWG. CHECK

BUILT BY:

CHECKED BY:

ARCH'T OR ENG'R.

PURCHASE ORDER

DRAWN BY:

DNH

PROJECT

REVISION

DATE

4/4/19

PURCHASER

MODEL#

FL-

QTY.

PRECISION REP

SERIAL#