


# DELMAR SERIES. ADJUSTABLE LENGTH LINEAR DRAIN PERFORATED. 3" HIGH FLOW OUTLET. 2D SET


Note:

- For indoor and outdoor use.
- Modify length of grate and channel on-site to exact specifications.
  - Place outlet anywhere along channel run.
- Select the drain equal to or longer than final desired length.
- For lengths longer than 96", connect multiple drains to build desired length.
- Corner accessory available when connecting two drains in a 90 degree angle.



36" MIST, ONE OUTLET

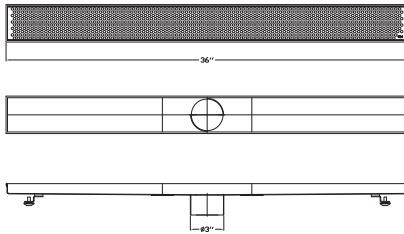

48" MIST, ONE OUTLET

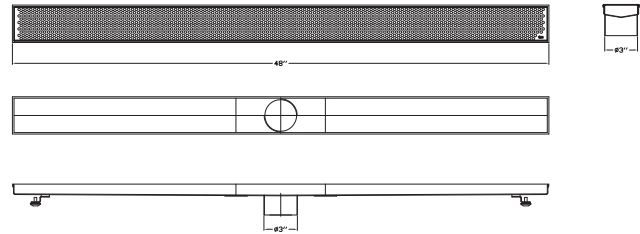



60" MIST, ONE OUTLET

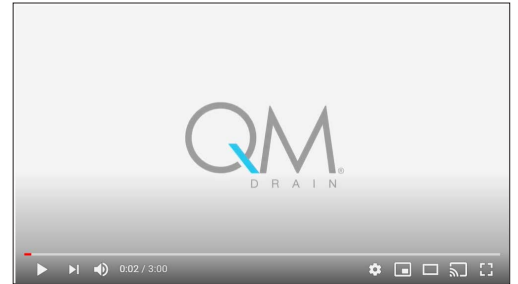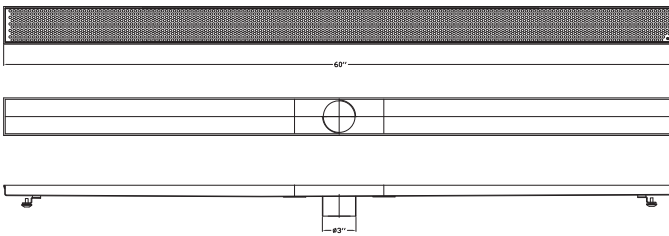

For spec., installation instructions, installation videos, pictures and more information visit:

<https://qmdrain.com/product/perforated-adjustable-delmar-linear-drain/>

 72" MIST, TWO OUTLETS

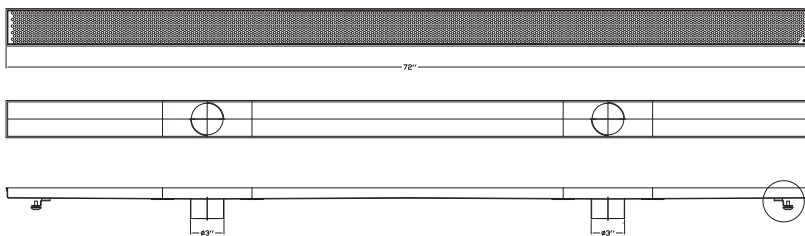


Leveling Feet.  
(Optional use during  
installation)

Corner.  
Needed when  
connecting two  
bases in a 90  
degree angle.

Full length drain can be built using either one or both included outlets.

96" MIST, TWO OUTLETS

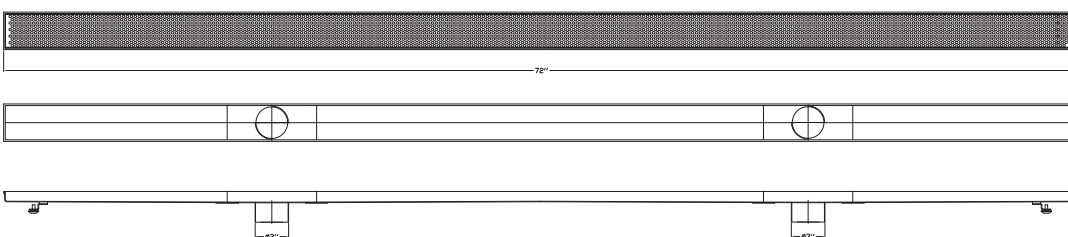

Full length drain can be built using either one or both included outlets.