 



537 Rubber Hinge Mat with Diamond Peak Vinyl Inserts

Frame Options:


548 aluminum recessed



 
545 vinyl surface mounted




551 aluminum recessed

 


544 aluminum surface mounted

 

540 aluminum recessed

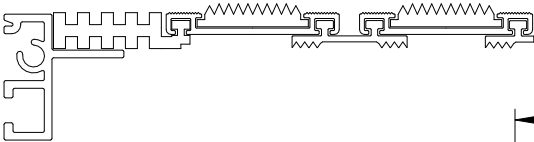

2"

 

Vinyl filler (up to 2" per side)

3"
8

Features:

- 6063 T-5 extruded aluminum rails
- Flexible PVC hinges/ footpads
- Diamond peak vinyl insert, designed specifically for high-traffic applications
- 1" x 3/16" slotted holes for maximum drainage
- 400 lbs./wheel rolling load weight capacity
- Roll-up function to ease cleaning process

Finishes:

- Aluminum rails and frames available in mill (standard), clear anodized, dark bronze anodized, and black anodized
- Vinyl hinges: Black
- Vinyl inserts: Gray, black, blue, beige, and brown (samples available on request)



Project:

Customer:

Architect: