 



532 Rubber Hinge Mat with Serrated Aluminum Inserts

Frame Options:

548 aluminum recessed



 
545 vinyl surface mounted




551 aluminum recessed



 544 aluminum surface mounted




540 aluminum recessed

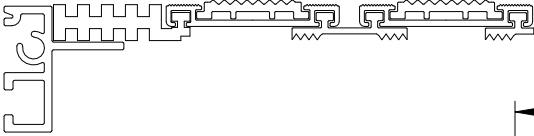

Features:

- 6063 T-5 extruded aluminum rails
- Flexible PVC hinges/ footpads
- 1" x 3/16" slotted holes for maximum drainage
- Serrated aluminum inserts, ideal for removing caked-on mud and grime from foot traffic
- 400 lbs./wheel rolling load weight capacity
- Roll-up function to ease cleaning process

 ← 2" →



3"
8

← Vinyl filler (up to 2" per side)

Finishes:

- Aluminum rails and frames available in mill (standard), clear anodized, dark bronze anodized, and black anodized
- Vinyl hinges: Black
- Serrated aluminum inserts available in mill, clear anodized, dark bronze anodized, and black anodized



Project:

Customer:

Architect: