


## 1a BLOCKING PANELS

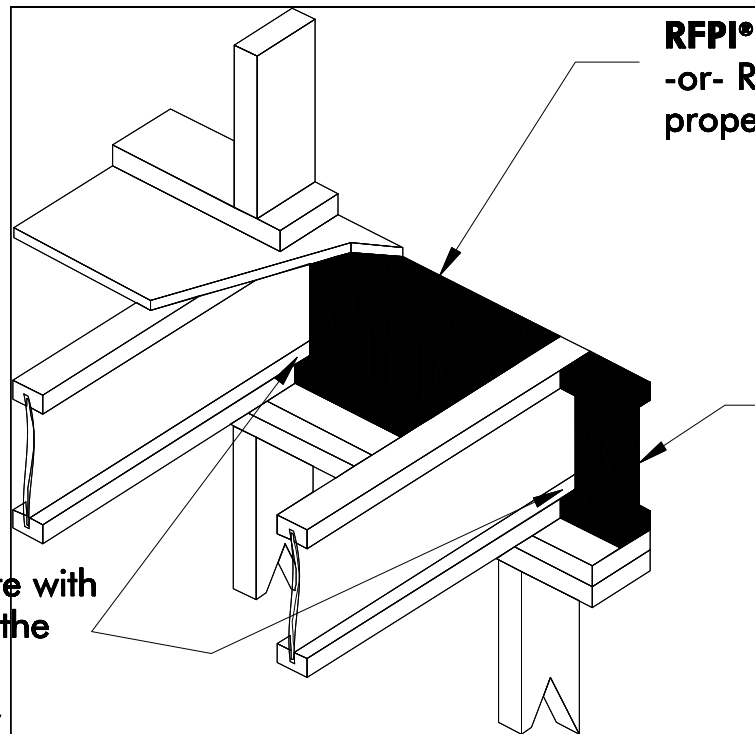

**RFPI® blocking panel** vertical load transfer = 2000 plf maximum  
-or- RigidRim Rimboard (see Roseburg EWP Design Guide for design properties)

**Attach blocking panel (or Rimboard)** to top plate with 8d nails @ 6" o.c.  
(when used for lateral shear transfer, nail to bearing plate with same nailing as required for decking)

Attach RFPI-Joist to top plate with **one 8d nail each side** of the flange at bearing.  
**To avoid splitting flange,** install nails a minimum of 1½" from end of I-joist. Nails may be driven at an angle to avoid splitting of bearing plate.