



HOSE STREAM 120 HEADBOX BOTTOM COVER EXPOSED CONFIGURATION


**SINGLE ROLLER
LESS THAN 11' IN WIDTH OPENING**

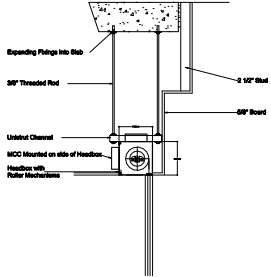

**MULTIPLE (OVER-UNDER) ROLLER
MORE THAN 11' IN WIDTH OPENING**

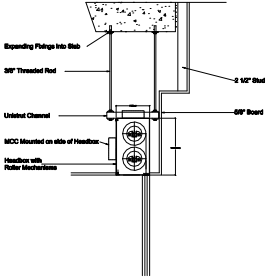


**MULTIPLE (SIDE BY SIDE) ROLLER
MORE THAN 11' IN WIDTH OPENING**

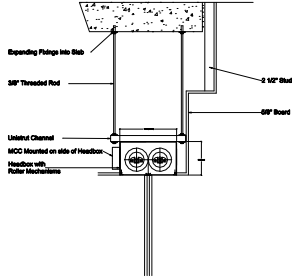


HEADBOX SIZES SHOWN ARE FOR CURTAIN DROPS LESS THAN 10 FEET IN HEIGHT.


**SINGLE ROLLER
LESS THAN 11' IN WIDTH OPENING**

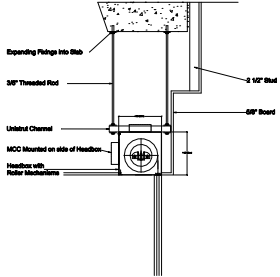

**MULTIPLE (OVER-UNDER) ROLLER
MORE THAN 11' IN WIDTH OPENING**

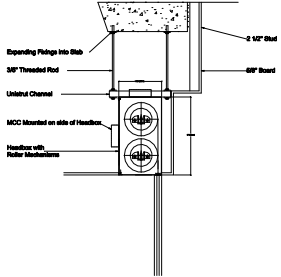

**MULTIPLE (SIDE BY SIDE) ROLLER
MORE THAN 11' IN WIDTH OPENING**

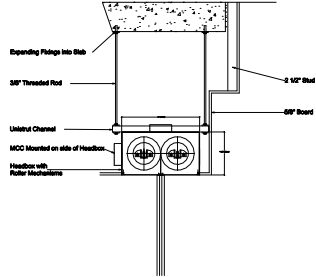

HEADBOX SIZES SHOWN ARE FOR CURTAIN DROPS BETWEEN 10 AND 20 FEET IN HEIGHT

SIDE GUIDE PLAN VIEW
(SIDE GUIDE CANNOT BE RECESSED MORE THAN 2 1/2" INSIDE FINISHED OPENING)

