




60-MIL (1.27mm) THICK  
PVC/TPO, UNIVERSAL  
CORNERS CAN BE USED  
FOR 3 DIFFERENT CORNER  
CONDITIONS AS SHOWN  
BELOW

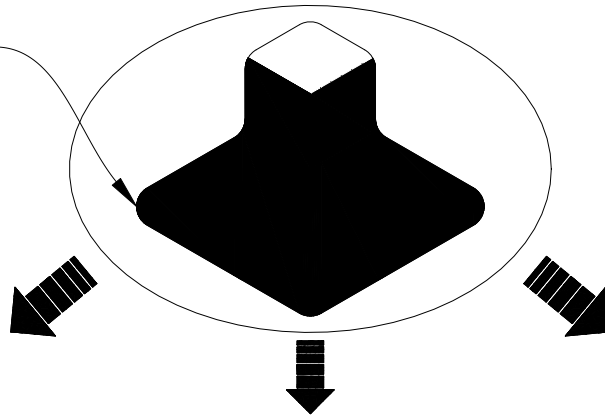


OPTION A

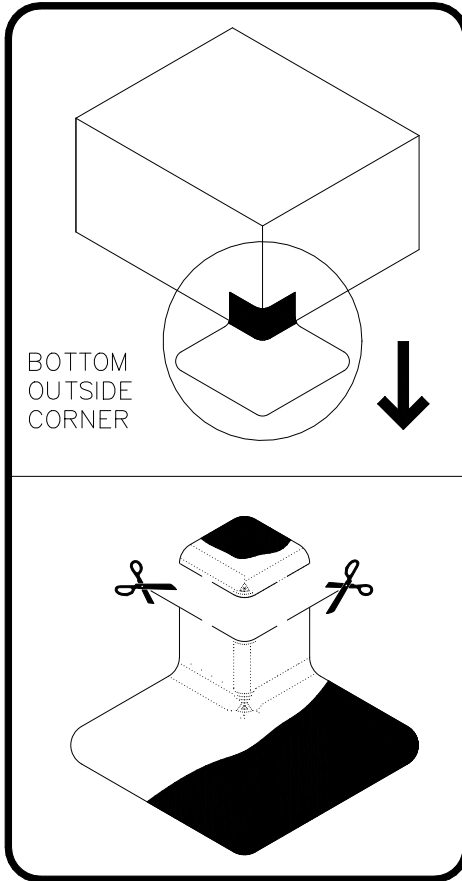

OPTION B


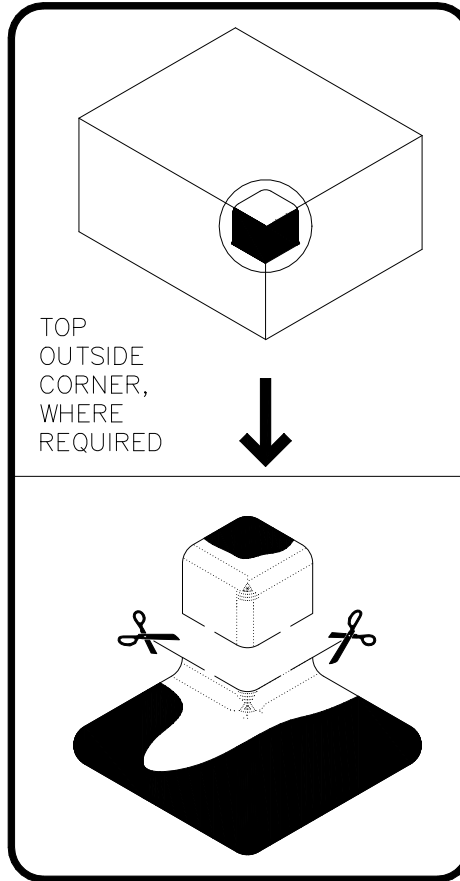


OPTION C

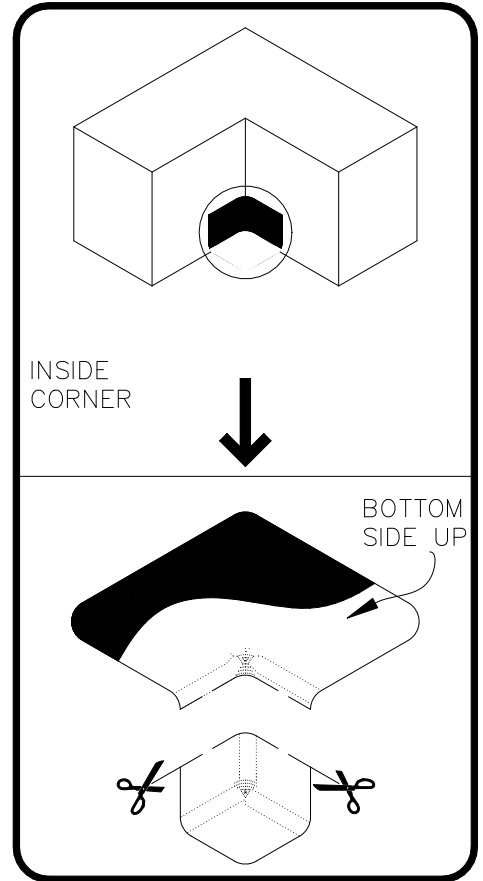

## NOTES:

1. ROOF SYSTEMS MUST NOT HAVE FIELD FABRICATED OR BUILT-IN CANT STRIP.
2. REFER TO TECHNICAL DATA BULLETINS FOR COLOR AVAILABILITY.

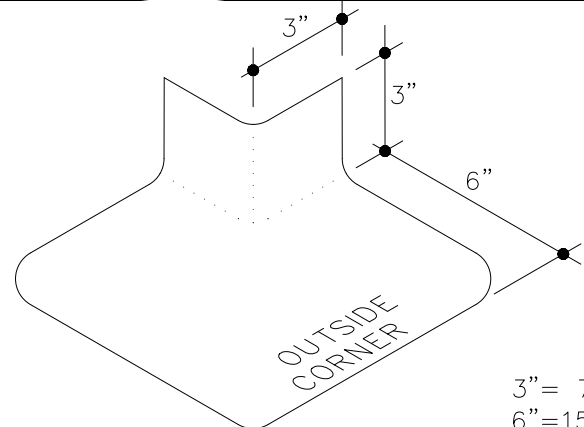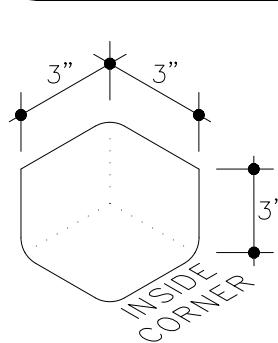


TYPICAL DIMENSIONS

3" = 7.5cm  
6" = 15cm



PVC OR TPO UNIVERSAL  
CORNERS – COMBINATION  
INSIDE & OUTSIDE  
CORNERS

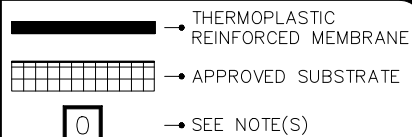

THERMOPLASTIC  
ROOFING SYSTEM

TPC-15.7