




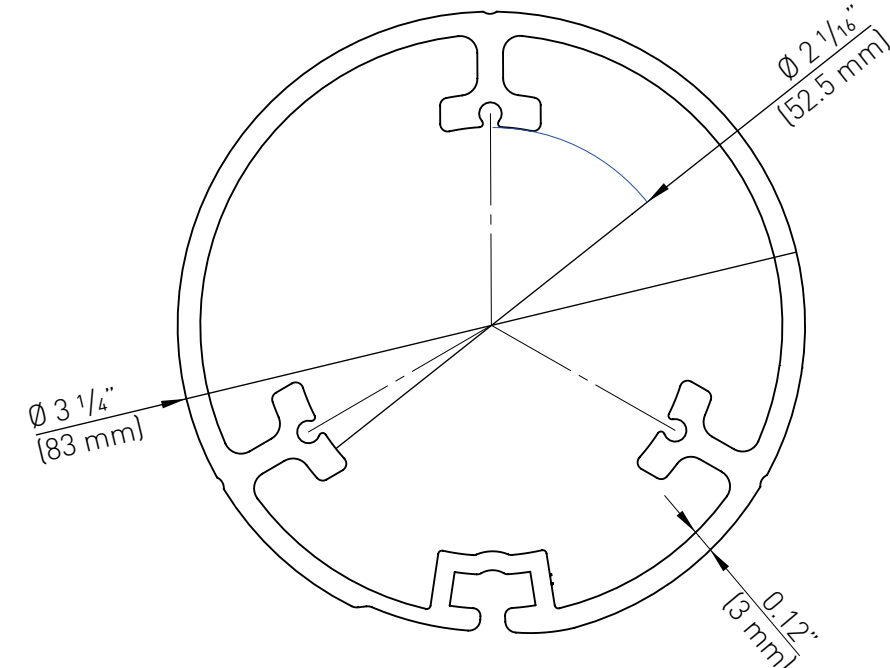


3 1/4" (83 mm) Structural Aluminum Tube
19' = 0-154-TU-83021

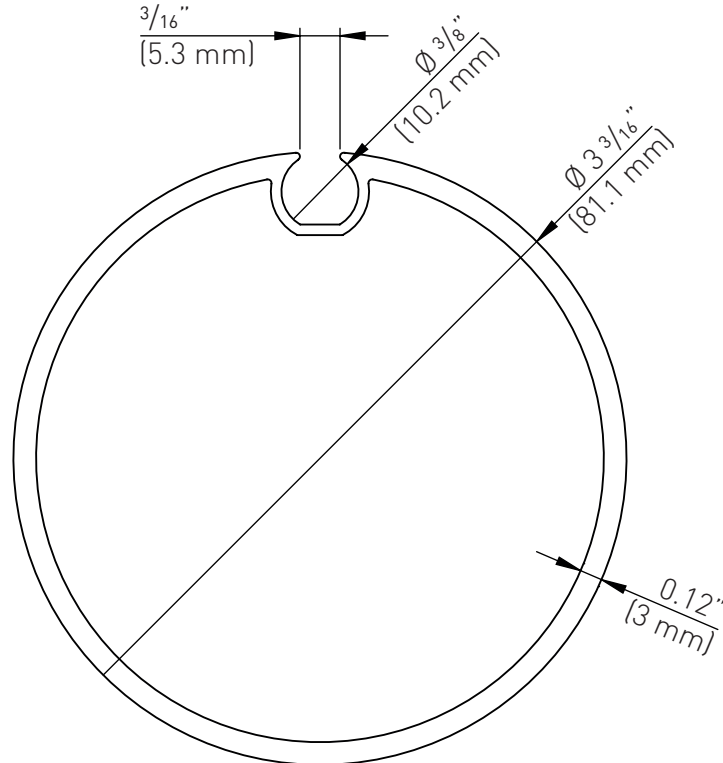


3 1/16" (78 mm) Aluminum Grooved Tube
19.5' = 0-154-TU-78022

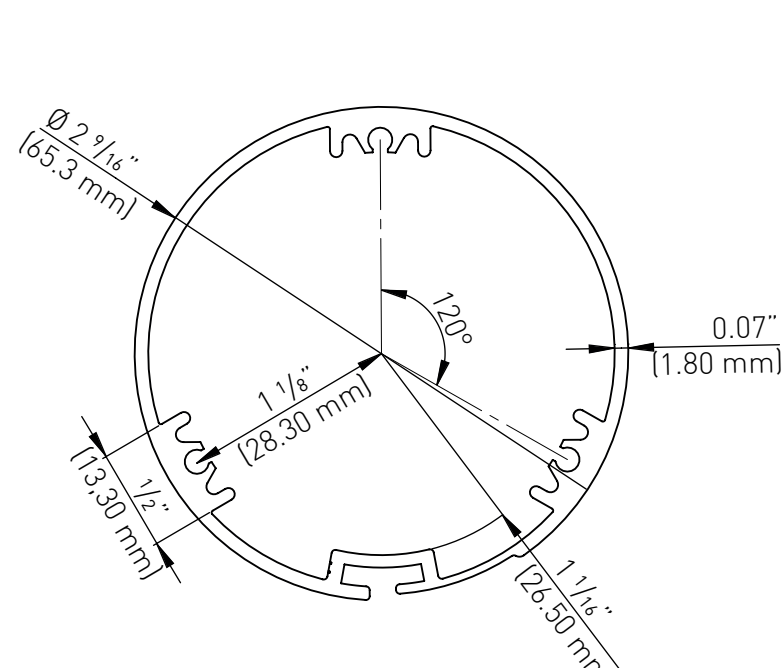


2 1/2" (63 mm) Aluminum Tube
19' with tape = 0-154-TU-63011

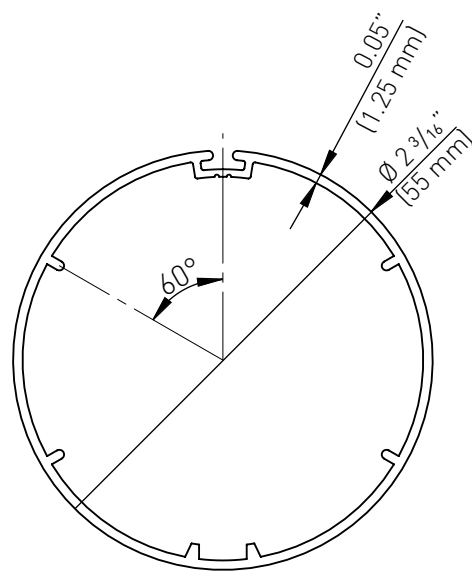


2 3/16" (55 mm) Aluminum Tube
with Flat Channel
19' = 0-154-TU-55021

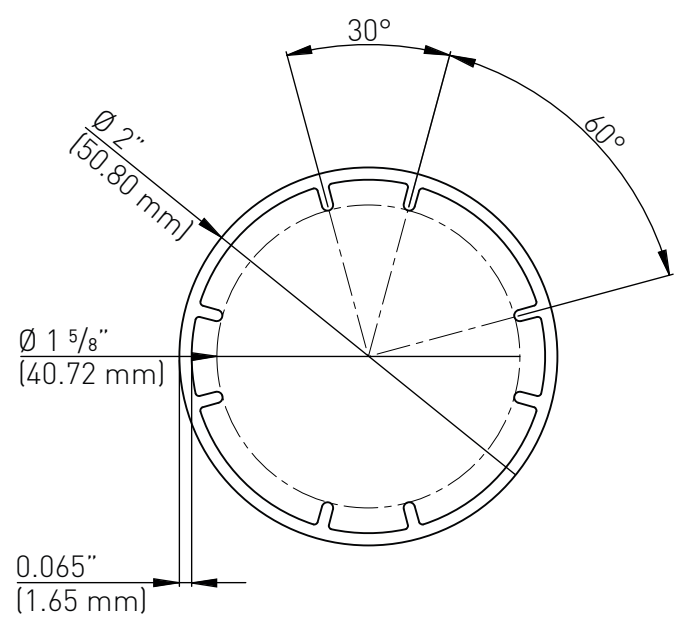


2" (50 mm) Grooved
Aluminum Tube
19' with tape = 0-154-TU-50101

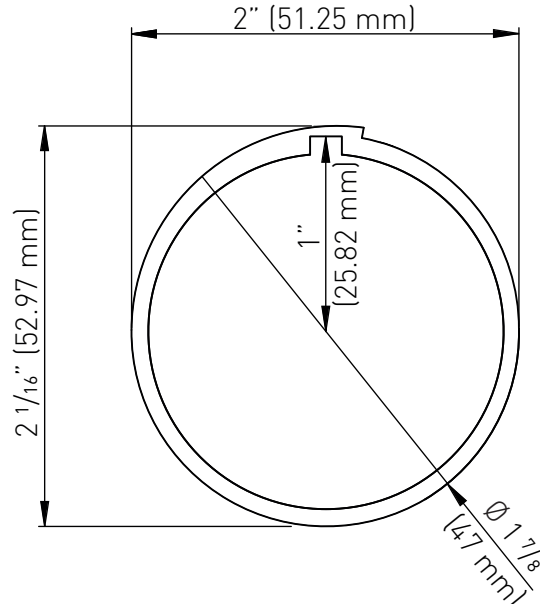


2" (50 mm) Recessed Keyed
Aluminum Tube
19' = 0-154-TU-50211

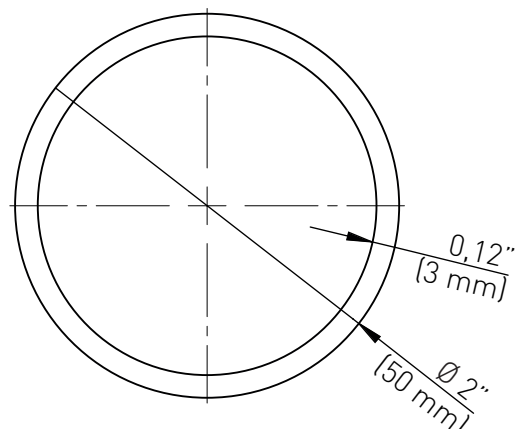


2" (50 mm) Heavy Duty Aluminum Tube
0-154-TU-50522

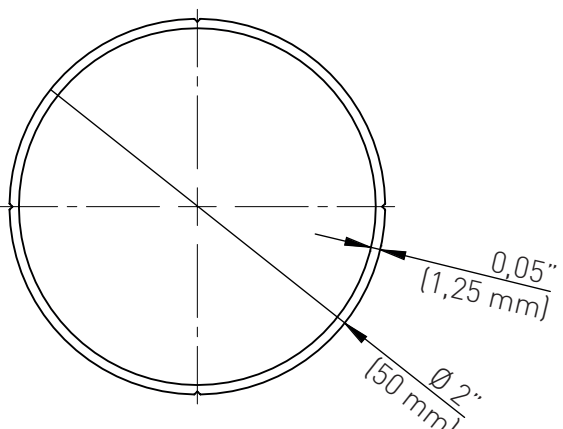


2" (50 mm) Aluminum Tube
19' with tape = 0-154-TU-50011

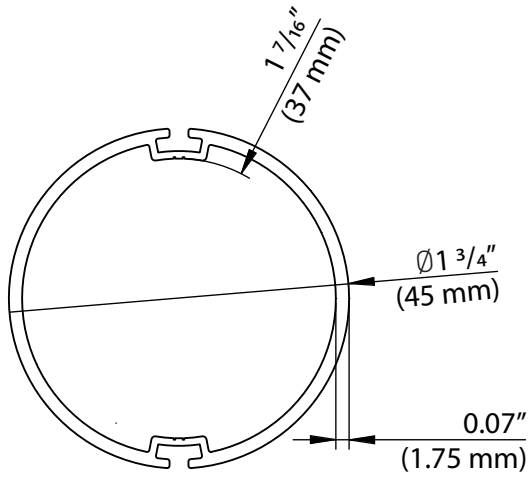


1 3/4" (45 mm) Tube (Two Channels)
19' with tape = 0-154-TU-45211

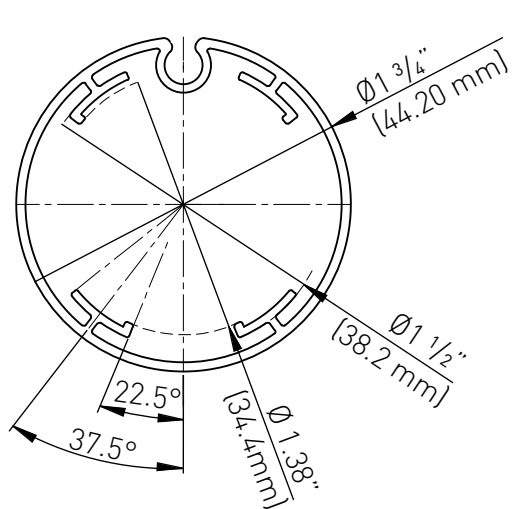


1 3/4" (45 mm) Heavy Duty Structural Tube
19' = 0-154-TU-46011

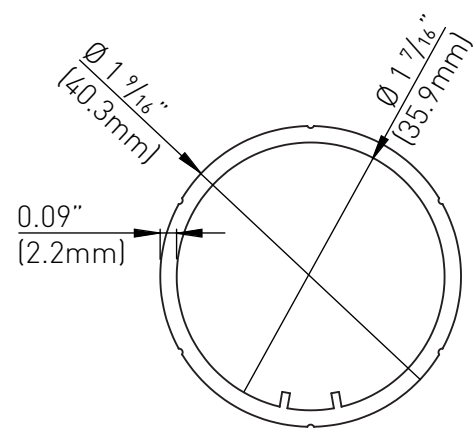


1 1/2" (38 mm) Smooth Aluminum
Motor Tube
19' = 0-154-TU-38511

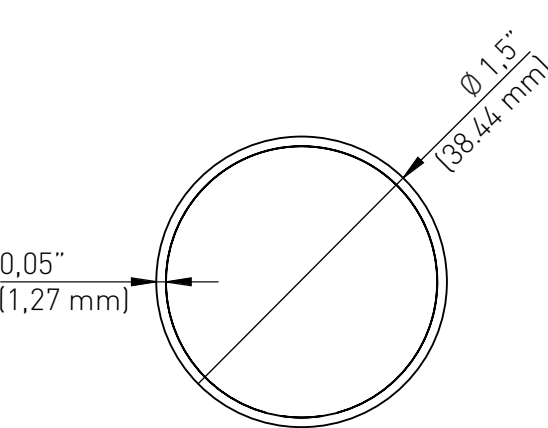


1 1/2" (38 mm) Smooth Aluminum
Motor Tube
19' = 0-154-TU-38421

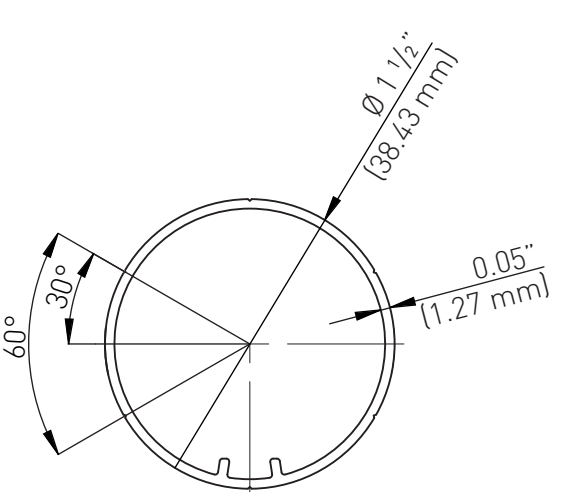

1 1/2" (38 mm) Aluminum Tube
19' with tape = 0-154-TU-38001

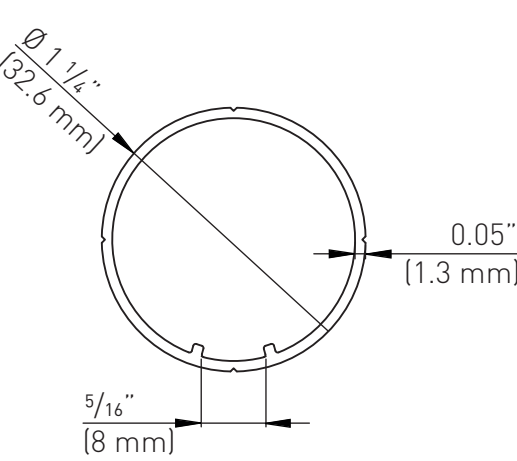

1 1/4" (32 mm) Aluminum Tube
19' with tape = 0-154-TU-32011

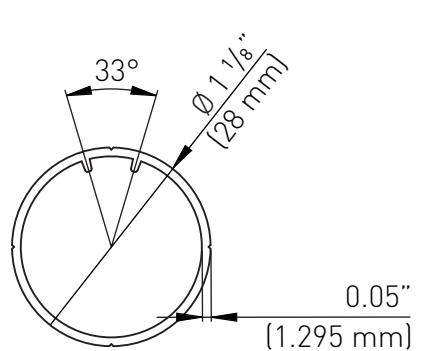


1 1/8" (28 mm) Aluminum Tube
19' with tape = 0-154-TU-28011




TITLE:


ALUMINUM TUBES

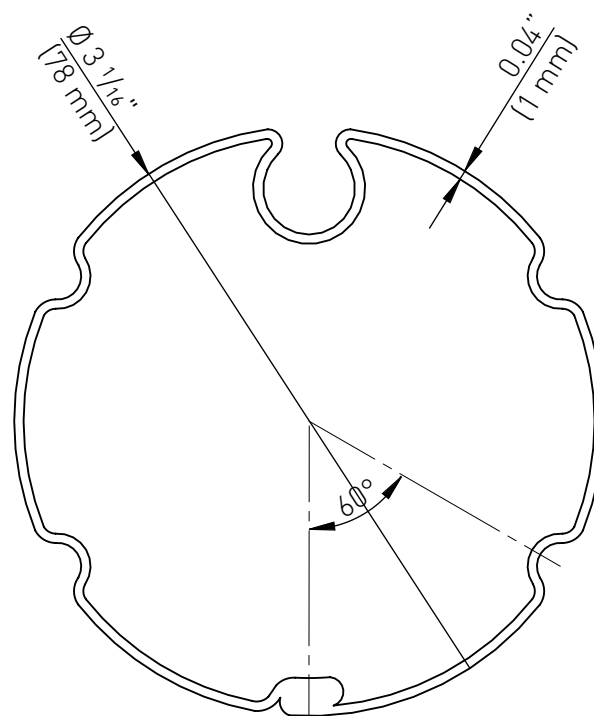

3 1/16" (78mm) Galvanized Grooved Tube 20'
0-154-TU-G7821

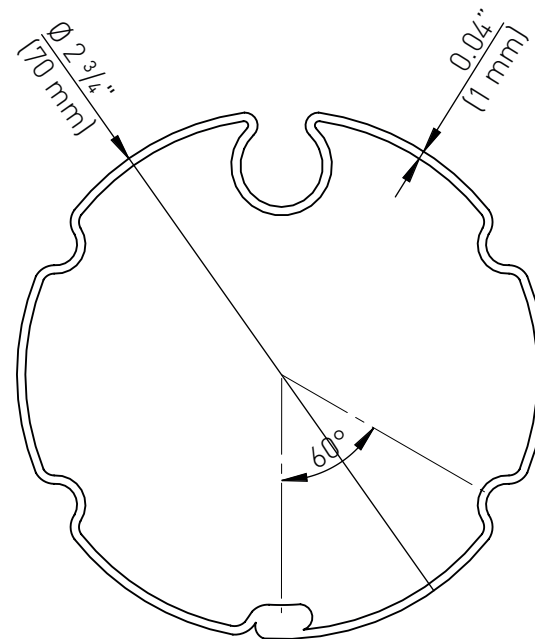

2 3/4" (70mm) Atos Galvanized Grooved Tube 19'
0-154-TU-G7021

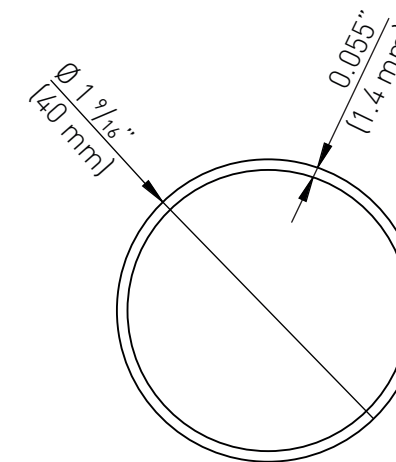

1 9/16" (40mm) Galvanized Bottomrail 19.5'
0-154-TU-G4022



TITLE:

GALVANIZED TUBES