

PA-3000

FLUSH NON-RATED - *Plastic Access Door*

Application

- Easy access to walls and ceilings
- Economical and attractive

Product Features

- High impact styrene plastic with U.V. stabilizers
- Hinged with a removable feature

PA-3000 Access Door Specifications:

Door / Door Frame: 1/8" high impact styrene plastic with U.V. stabilizers

Flush to frame — rounded safety corners, one piece outside flange with 3/4" deep mounting frame

Standard Latch: Snap latches allow door to fit tightly within frame

Door Hinge: Concealed

Finish: White, with textured exposed surfaces


PA-3000 STANDARD SIZES

Nominal Door Size W&H		Weight per Door	
Inches	(mm)	lbs.	(kg.)
4 X 6	102 X 152	0.30	0.14
6 X 9	152 X 229	0.55	0.25
8 X 8	203 X 203	0.65	0.29
12 X 12	305 X 305	1.20	0.54
14 X 14	356 X 356	1.60	0.73
14 X 29	356 X 737	3.30	1.50
18 X 18	457 X 457	2.50	1.13
22 X 22*	559 X 559	3.80	1.72
24 x 24*	610 X 610	4.50	2.04

Wall or ceiling opening is W + 3/8" (9 mm)

For detailed specifications see submittal sheet

*22 x 22 and 24 x 24 sizes are designed for wall installation only.

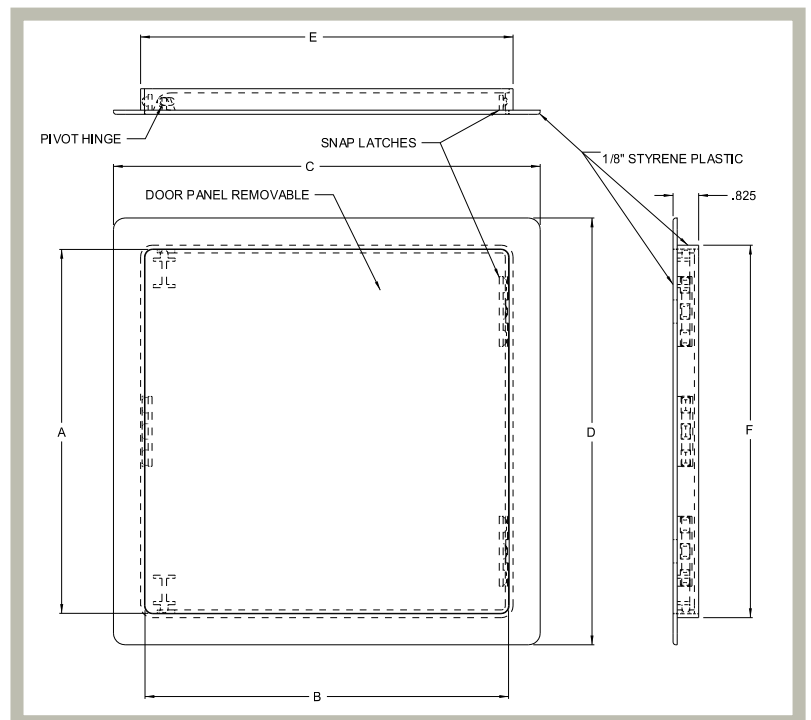

PA-3000 View of door back