


ADA Mesh grating - Stainless steel

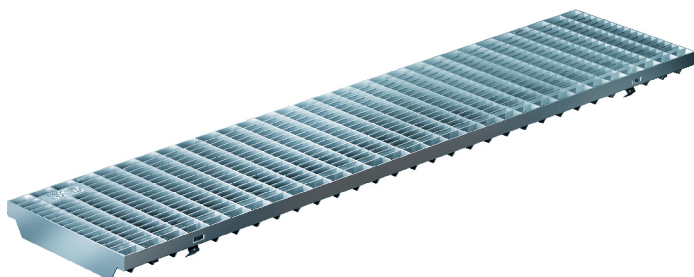

Product Features:

- Certified to EN 1433 Load Class C 250 kN - 56,200 lbs
- Uses fiX self-locking system
- Suitable to use with NW200 channels
- Manufactured from Grade 304 (1.4301) stainless steel
- Complies with ADA - American Disabilities Act.

Installation:

- The trench drain system and grates shall be installed in accordance with the manufacturer's installation instructions and recommendations

Gratings FILCOTEN® pro – E 200 (8") with fiX self-locking system.

	Item no.	Gratings	Material	Dimension	Load class as per EN- standard	Slot-/Mesh width	Weight Lbs Kg		Inlet cross- section sq.inches	Inlet cross- section cm2/m
○	17020322	ADA Mesh grating	stainless steel	39.40"/8.74"/0.78" 1000/222/20	C 250 kN	MW 1.18" x 0.39" (MW30x10mm)	19.4	8.8	255.75	1,650
○	17020323	ADA Mesh grating	stainless steel	19.70"/8.74"/0.78" 500/222/20	C 250 kN	MW 1.18" x 0.39" (MW30x10mm)	9.92	4.5	247.23	1,595

Specification: FILCOTEN pro-E NW200, heavy duty, (Load Class C 250 kN), stainless steel (Type 304), reinforced grate is 8.74" (222mm) wide, 39.40" (1000mm) long, 0.78" (20mm) high, weighing 19.40 lbs (8.8 kg). The grate has 0.39" (10mm) wide, 1.18" (30mm) long mesh and is ADA compliant and Class C load rated - commercial applications. The grate is secured to the body with four point fiX self-locking (snap-on) system. Stainless steel manufactured and tested according to EN1433 - CE certified.

C250kN MW30/10: E 17020322 (17020323)

