




MODERCO


Signature 800 Series

Technical Data Sheet Signature 800 Double Pass Doors

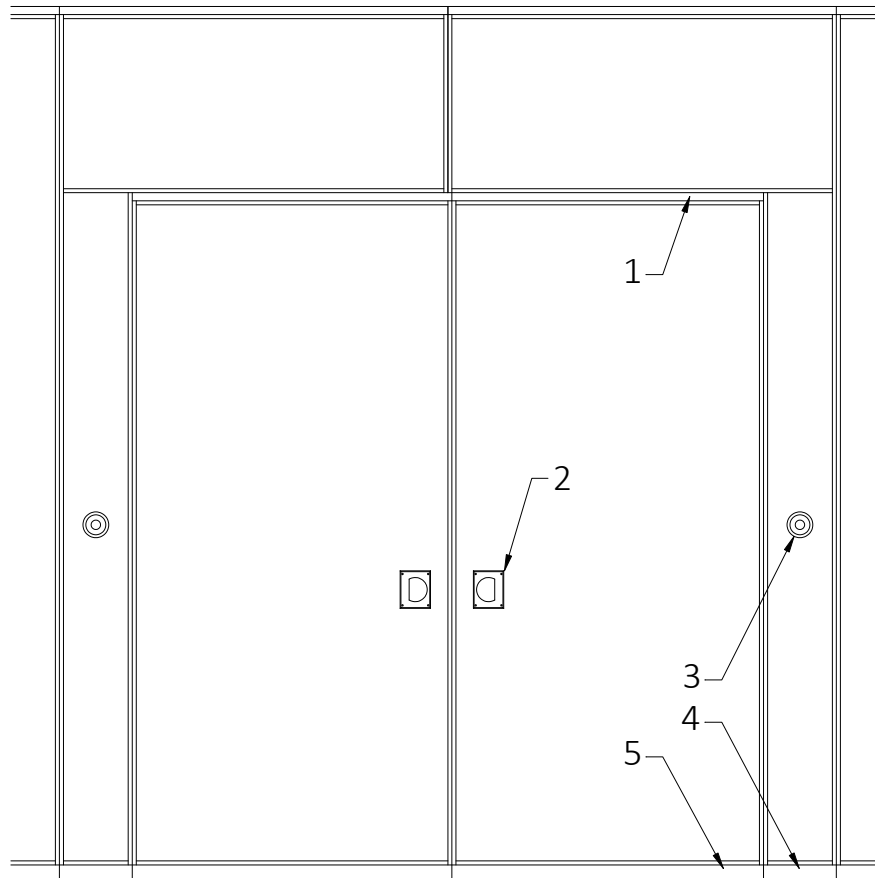


- Same core construction as movable partition panels
 - Same surface finish as movable partition / optional custom finish / unfinished
 - Low profile hinges
 - Flush pulls and roller latch
 - 2553 mm [8'-4 1/2"] underside of track MIN for 2134 mm [7'-0"] door
 - 2452 mm [8'-0 1/2"] underside of track MIN for 2032 mm [6'-8"] door
- 1- Sweep seals
 - 2- Flush pull
 - 3- Retractable seal activator
 - 4- Manually-activated bottom seals
 - 5- Sweep seals


Horizontal Section

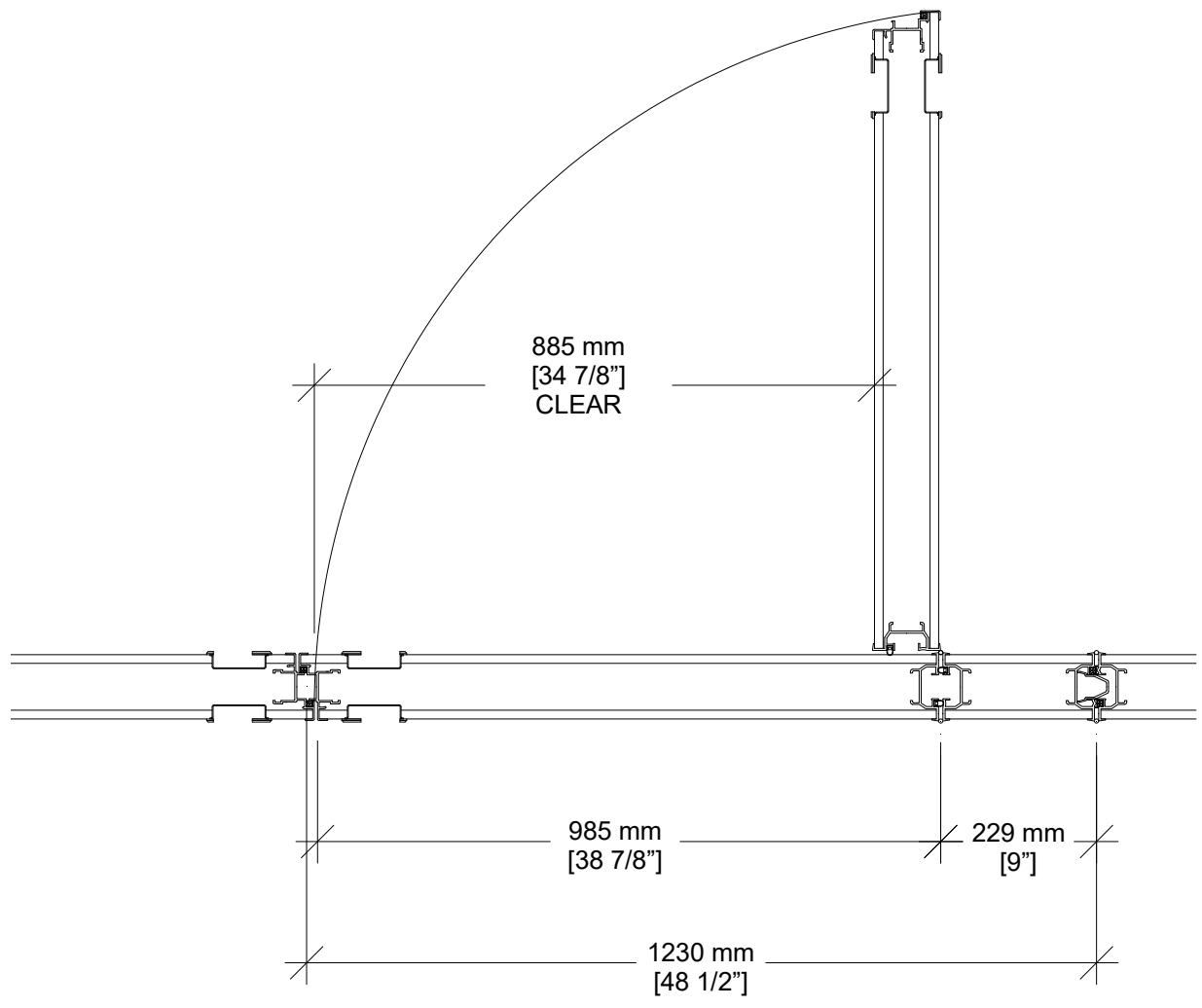

Unless otherwise specified, the right-side door on the push side is the active leaf



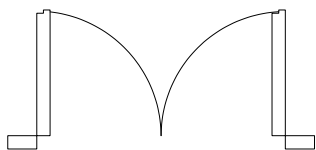


Active

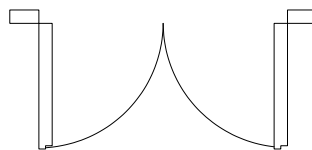

Active

Optional Hardware

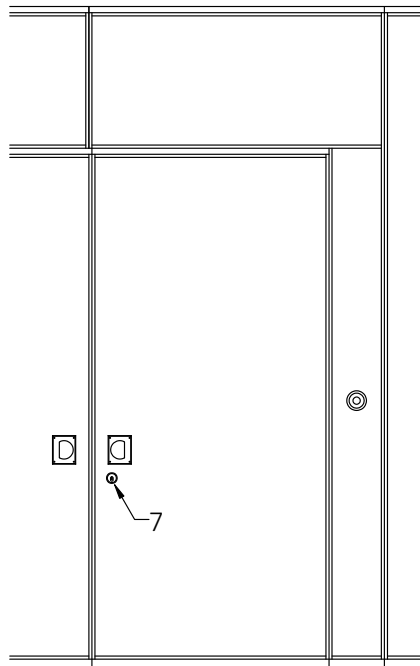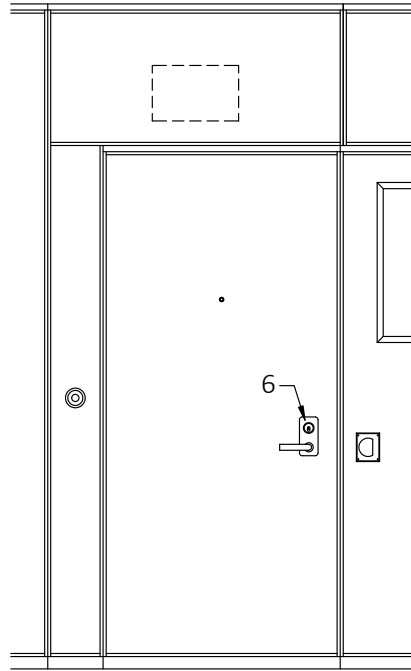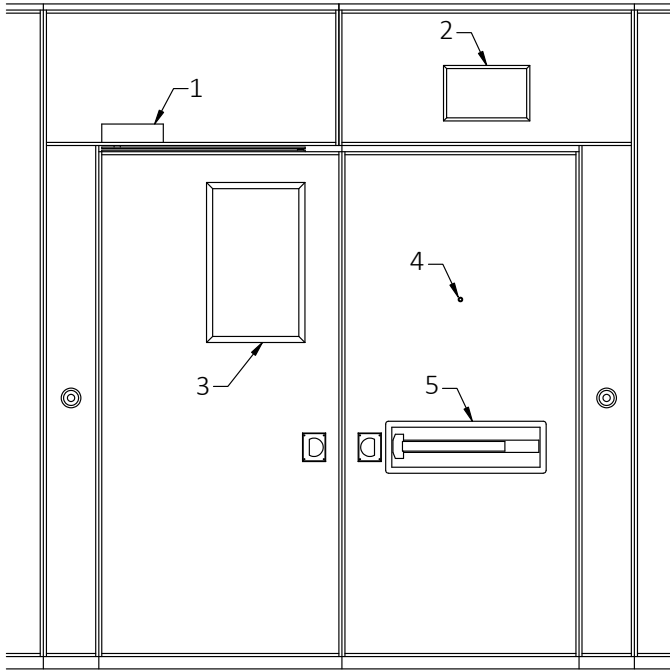

1- Concealed Door Closer

2- Self-luminescent Exit Sign ¹

- standard red faceplate
- optional green faceplate
- optional "Running Man" with green faceplate

3- Window Frame

- 355 mm X 610 mm [14" X 24"]
- Glazing by others

4- Door Viewer

5- Panic Bar ^{1/2}

6- Panic bar Lever (with optional lock)

7- Deadbolt lock ³

¹ Exit sign and panic bar available on active leaf only

² Add 102 mm [4"] to stack depth for each panic bar

³ Not available with panic bar or exit sign