


MAX

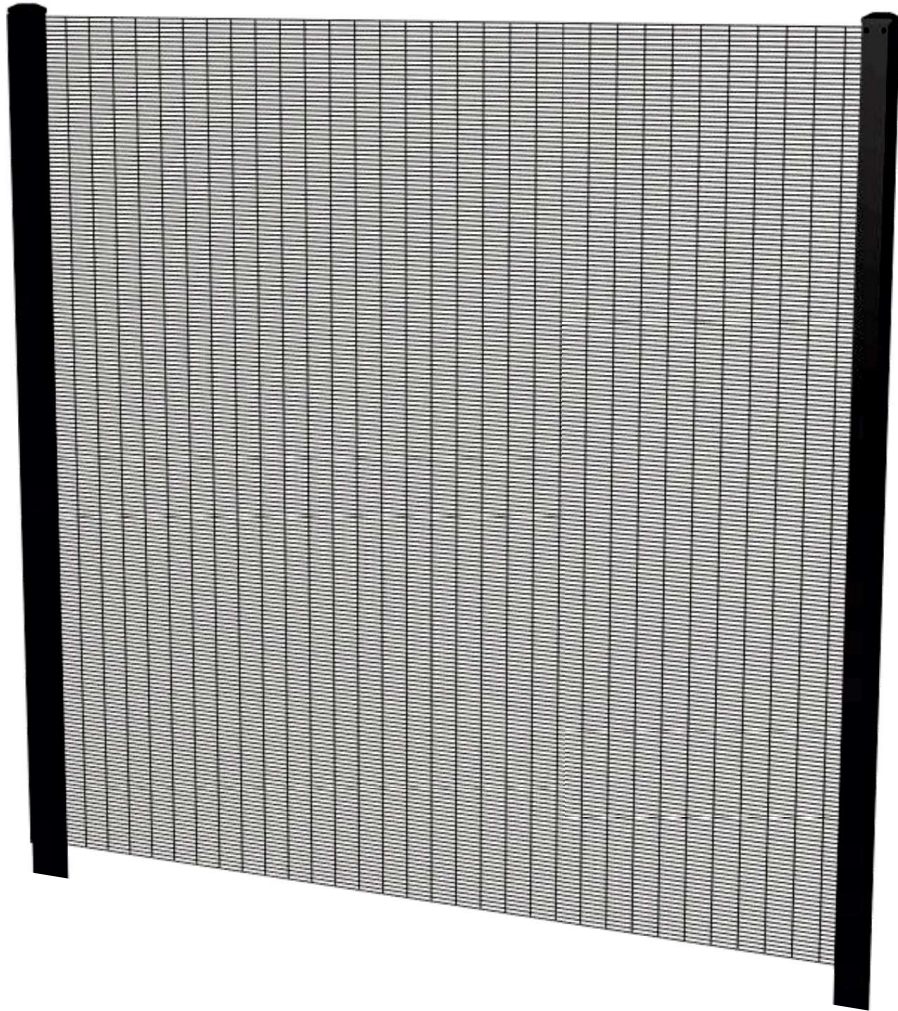

MAX

Panel	Single Wire
Horizontal wire	8 GA
Vertical wire	8 GA
Mesh opening	$\frac{1}{2}'' \times 3''$ – C/C Nominal .340'' x 2.80'' – Inside wires
Standard height	4', 6', 8'
Standard length	8' 3''
Square post	3" x 3" or 4" x 4"
Caps	Aluminum Square
Special Panel Fitting	Single bracket Complete flat bar
Opacity/Openness	37% / 63%

