


VERTICAL GRATING OMEGA 10

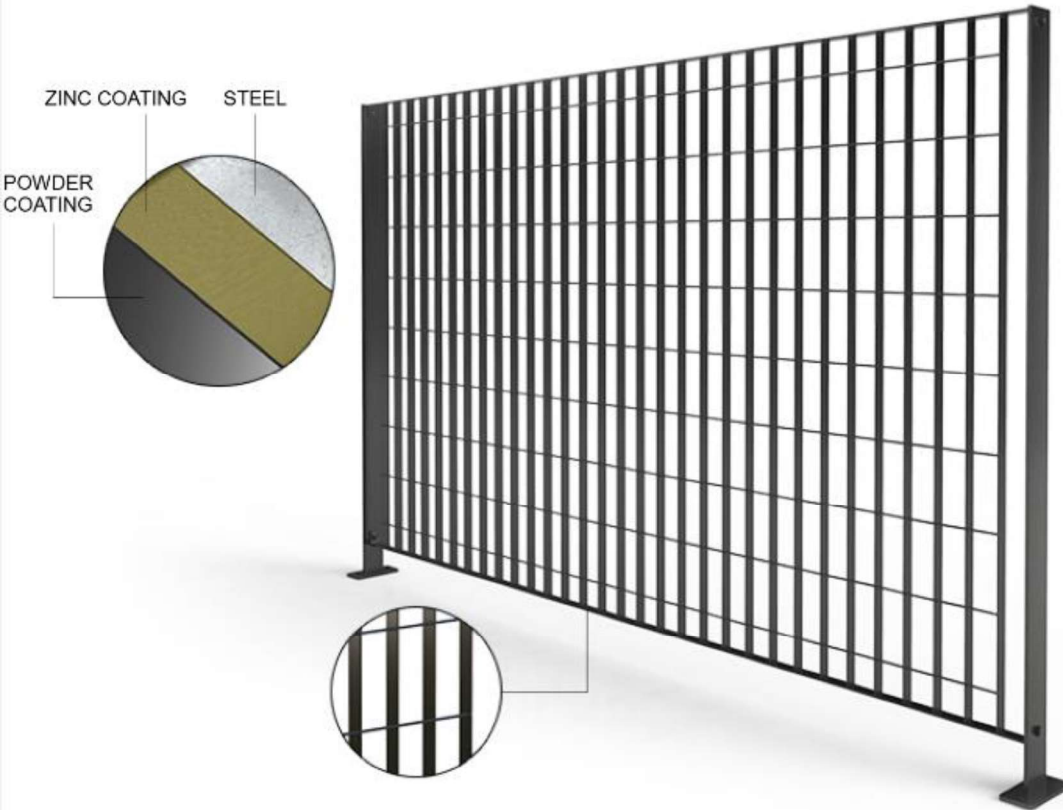

OMEGA 10

Design	Rectangular
Horizontal wires	Round, 7 GA (Diameter 4.5 mm)
Vertical bars	1" x 14GA (25mm x 2 mm) Flat
Openings	2 7/16" x 5 3/16" (62mm x 132 mm)
Standard Heights	47" - 78" - 99" (1200 – 2000 – 2500 mm)
Standard Length	78" (2000 mm)
Gap Bottom panel/Ground	3 7/8" (98 mm)
Bolting	Carriage Bolt 5/16" (8 mm) - Standard nuts or Tamper Proof
Posts	Flat / Flanged - Square / Flanged
Caps	Flat post = no cap, Square post = Square cap
Handrail	Custom, on demand
SPF (Special Panel Fitting)	Versatile brackets adapt to many applications.
Opacity/Openness	9.5% / 90.5%

