

The 275 Low Profile window is a variation of the popular 275 model. It is the same overall frame size, but features a smaller header for more glass and less metal. The self-closing operating system is located in the header for a track-free service area.

This unit is ideal for use as a sliding reception window, interior pharmacy window, or office pass-through window.

Choose your mode of operation

◇ **MANUAL OPEN / SELF CLOSE**

Manual open, with patented hands-free gravity fed self-close. Economical and easy to maintain. Adjustable to manual open/manual close if preferred.

◇ **MANUAL OPEN / ELECTRONIC RELEASE (MOER)**

Electromagnetic “hold open” feature paired with a presence sensor offers the control of manual open with a gravity-fed close that won’t release while interacting with customers. Hands free interaction that is easy to maintain.



**STANDARD SIZES**

- ◇ 47-1/2"W x 43-1/2"H (19"W x 39"H service opening)
- ◇ 47-1/2"W x 35-3/4"H (19"W x 31-1/4"H service opening)
- ◇ 35-3/4"W x 35-3/4"H (13-1/2"W x 31-1/4"H service opening)\*


\* Meets CA restricted opening requirement—under 432 square inches

**STANDARD FEATURES:**

- ◇ Anodized aluminum extrusions and stainless steel combine to give you an attractive window that will not rust, pit or weather
- ◇ Fully assembled, pre-glazed and ready to install
- ◇ 1/4" Clear Tempered Glass
- ◇ Dark Bronze or Clear Anodized Aluminum
- ◇ Self latches every time it closes. Also includes a thumb turn lock, and night locking bar
- ◇ Track free bottom sill provides for a contaminant free surface. Angled toward outside for drainage toward exterior
- ◇ One year parts & labor limited warranty
- ◇ On-staff tech support / stocked parts / nationwide network of service providers.

**OPTIONAL FEATURES**

- ◇ Powder Coat Paint—Tiger Drylac
- ◇ Custom Size
- ◇ Tinted Glazing
- ◇ Low E Glass
- ◇ 5/16" Safety Glass
- ◇ Stainless Steel Shelf to extend sill inside or out (13 ga.)
- ◇ Telescoping Night Time Security Bar Set for additional security
- ◇ Solid Glass Transom
- ◇ Split Transom for AA100 Fly Fan
- ◇ AA300 Heated Air Curtain
- ◇ Restriction Panel or Screen

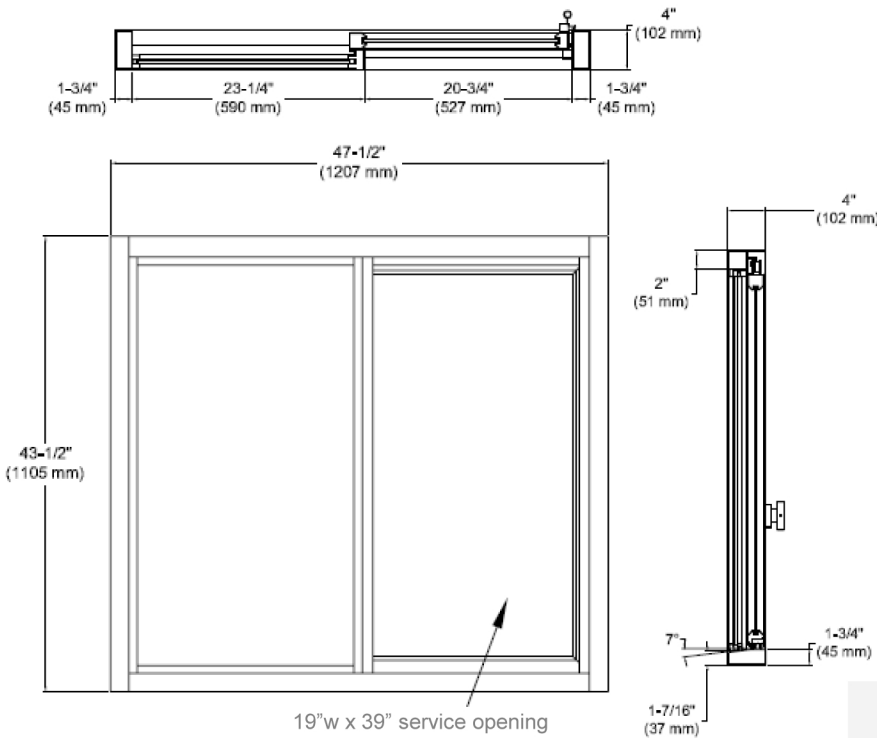

Specify R/L or L/R from exterior view

### ROUGH OPENING

#### 47-1/2" W x 43-1/2" H


- ◇ Masonry Rough Opening –48"W (1219 mm) x 44"H (1118 mm)
- ◇ Glazing Rough Opening - 47-3/4"W (1213 mm) x 43 3/4"H (1111 mm)

#### 47-1/2" W x 35-3/4" H

- ◇ Masonry Rough Opening –48"W (1219 mm) x 36 1/4"H (921mm)
- ◇ Glazing Rough Opening - 47-3/4" W (1213 mm) x 36"H (914 mm)

#### 35-3/4" W x 35-3/4" H

- ◇ Masonry Rough Opening –36-1/4"H (921mm) x 36-1/4"H (921mm)
- ◇ Glazing Rough Opening - 36"H (914 mm) x 36"H (914 mm)

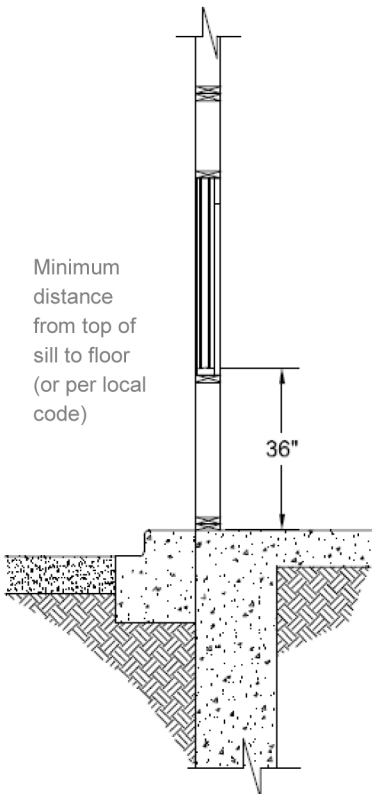

All windows are shipped completely pre-assembled, fully glazed and ready to install.

Installation / Owners manual can be retrieved online:

[www.ready-access.com](http://www.ready-access.com)

- ◇ Installation illustrations are for reference only. Construction conditions and local codes prevail.
- ◇ Must be installed level, square and plumb.

### ELECTRIC REQUIREMENTS

Run power to header on fixed panel side

#### Manual Open / Self Close Window:

No Power Required

#### Manual Open / Electronic Release:

115 vac—60Hz with a 15 amp dedicated circuit

Window must be on a dedicated circuit

