




PRODUCT DESCRIPTION

Safe Haven Defense SW440RC- Riot Control laminate film offers protection for glass breakage due to forced entry such as burglaries, hurricanes, and blast. **SW440RC incorporates an extraordinary capability in protection by hindering entry into your property. Keeping valuables and loved ones safe.**

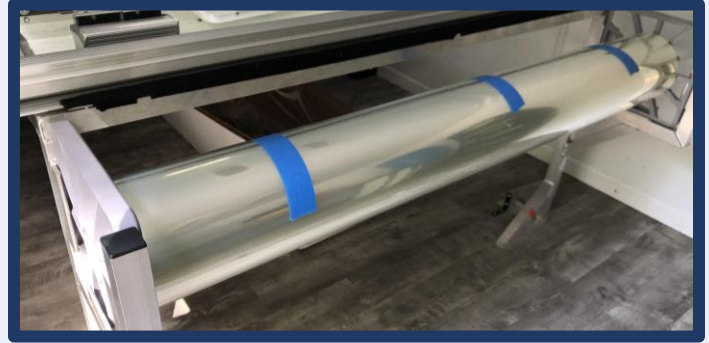

TECHNICAL DATA

PROTECTION LEVEL	Exigent Protection
THICKNESS (1 layer)	30 mil
NUMBER PLIES	2
BREAK STRENGTH	900 psi
TENSILE STRENGTH	32,500psi
PEEL STRENGTH	6psi
TOTAL SOLAR ENERGY REJECTION	20%
IR REJECTION	59%
UV REJECTION	99%

CERTIFICATIONS & STANDARDS


ANSI Z97.1 – Bldg Glaze Materials

CPSC 16 CFR 1201 – Impact Test

GSA EXPLOSIVE TEST: GSA TS01-2003

UL972 – Burglary Protection

FLAME SPREAD – ASTM E-84

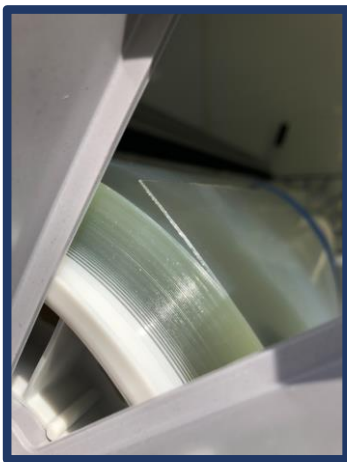

USES/APPLICATION

Safe Haven Defense SW440RC laminate is applied onsite, to the **INTERIOR** of existing windows in commercial, municipal and residential buildings. Unlike traditional Riot Control glass, no special modifications or retrofitting to existing structure needs to be done. Because our laminate can be applied over **existing glass as thin as ¼ inch**, customers achieve the end goal of hardening their structure at a significant cost savings to traditional RC glass.

*existing window must be inspected to be structurally sound. Window must be free from debris and thoroughly cleaned prior to application.

Visit WWW.SAFEHAVENDEFENSE.COM to watch demos of 1 Directional Bullet Resistance